


In-Line Heater Inside-the-Pipe Heating Cable

**Maintain Water supply
throughout the winter in
your home, cottage or barn.**

The EASY HEAT IN-LINE HEATER provides economical, effective in-pipe freeze protection for water supply lines. The cable consists of dual conductor resistance wire with PVC insulation, continuous ground braid, and clear food-grade outer PVC jacket. A 12 Amp energy saving thermostat c/w Ground Fault Circuit Interrupter (G.F.C.I.) receptacle is also included.

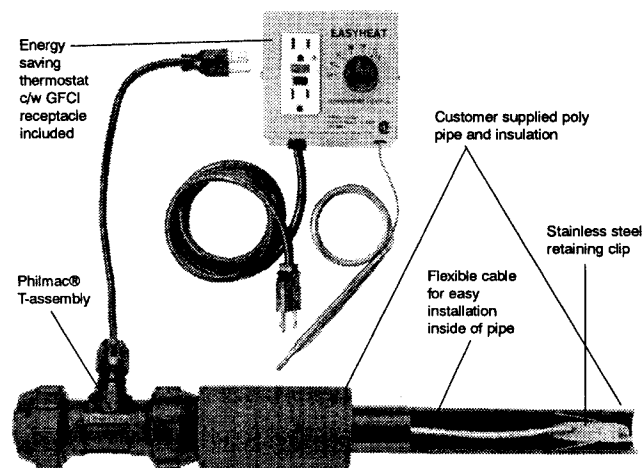

FEATURES

- User friendly plug-in installation
- Energy saving thermostat
- GFCI with test/reset and pilot light
- Flexible cable provides easy installation
- Effective and economical operation
- CSA approved for drinking water supply
- Comprehensive size selection from 10 ft to 270 ft
- Non-restrictive Tee assembly fitting (no 90° turn)
- Will not burn through pipe if dryout occurs (*see instructions*)
- 120 Volt operation (5W/ft)
- Designed for standard CSA approved, 1 1/4" PE pipes. Adaptor kits (Part No. 10561-001) available for 1" pipes.

Catalog No.	Watts	Length (ft)	Amps	Resistance (Ohms)
ILH4010	50	10	0.4	288
ILH4020	100	20	0.8	144
ILH4030	150	30	1.3	96
ILH4040	200	40	1.7	72
ILH4050	250	50	2.1	58
ILH4060	300	60	2.5	48
ILH4070	350	70	2.9	41
ILH4090	450	90	3.8	32
ILH4100	500	100	4.2	29
ILH4120	600	120	5.0	24
ILH4140	700	140	5.8	21
ILH4160	800	160	6.7	18
ILH4180	900	180	7.5	16
ILH4200	1000	200	8.3	14
ILH4225	1125	225	9.4	13
ILH4250	1250	250	10.4	12
ILH4270	1350	270	11.3	11

Easy Heat products are provided with a limited warranty: see owner's manual or contact Easy Heat for complete terms and conditions.



www.easyheat.com

40924-001 Rev. 4

USA
2 Connecticut South Drive
East Granby, CT 06026
TEL 800/537-4732
FAX 800/541-7451

Canada
99 Union Street
Elmira ON N3B 3L7
TEL 519/669-2444
FAX 519/669-6419

©2008 Easy Heat Inc.