



SimpleComfort® SC1800L/SC1800VL

Terminations

R W G S1 S2

NON-PROGRAMMABLE, HEAT ONLY

Non-Programmable

Simple control for year-round comfort. This easy-to-operate comfort command center allows you to match temperature to your family's lifestyle. Attractive, extra-rugged, highly reliable and accurate, this thermostat's elegant design will look and perform like new for years to come.



Also available in vertical design.
See Ordering Info. for details



- Heat only thermostat
- Simple operation
- ICM patented Thermal Intrusion Barrier
- Large backlit LCD display
- Battery operated
- Low battery indicator
- Millivolt compatible
- Freeze protection feature
- Remote sensor compatible
- Compatible with gas, oil and electric systems
- Vertical model available for easy J-box installations



SC1800L/VL

- Single-stage heat only
- For gas, oil and electric systems
- Millivolt compatible

Non-Programmable Single-Stage Heat Only Battery

Specifications

Electrical Rating:

- 24 VAC (18-30 VAC)
- 1 amp maximum per terminal
- 2 amp maximum total load
- Easy access terminal block

Temperature Control Ranges:

- 45°F to 90°F, Accuracy: ±1°F

System Configurations:


- Single-stage heat, gas, oil and electric

Terminations:





- SC1800L: R, W, G, S1, S2
- SC1800VL: R, W, G, S1, S2

Dimensions

Horizontal design

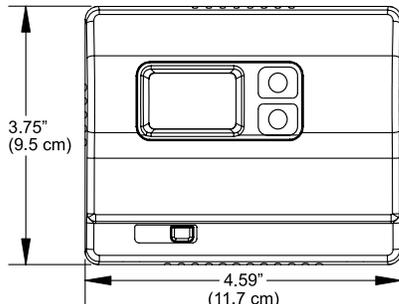


Vertical design

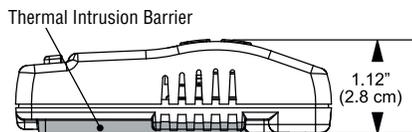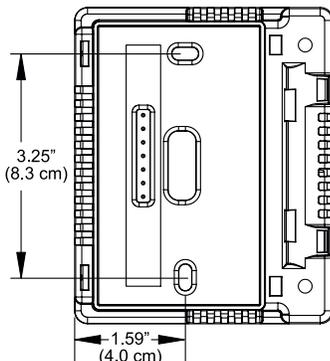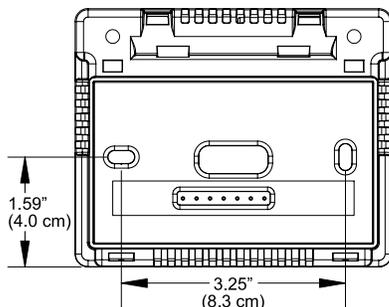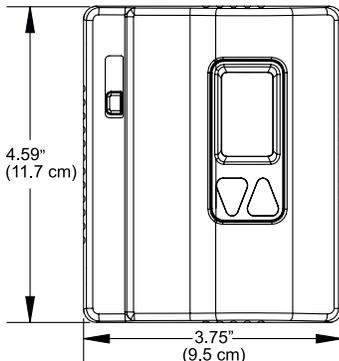

Specifications subject to change without notice.

NEW Thermal Intrusion Barrier

Exclusive, patented insulation technology eliminates thermal drift caused by wall effect.

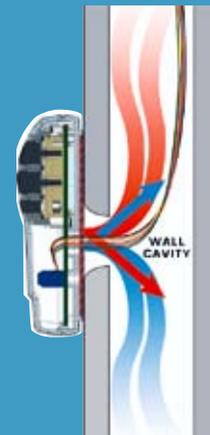

If you like this model, be sure to try out these other thermostats from ICM Controls!

SimpleComfort® PRO Series – Innovation and technology that simplifies installation and increases profitability!

- Flexible 7-day, 5-2-day and 5-1-1-day programming (programmable models)
- ICM's patented Thermal Intrusion Barrier
- ICM's patent-pending SimpleSet™ Target Programming technology
- Large display with backlight
- Permanent memory
- Auto or manual changeover
- Field adjustable calibration
- Configurable remote sensor compatible
- Keypad lockout
- Soft-touch controls

Programmable Thermostats

- SC5010 – One-stage heat/cool or heat pump, dual powered
- SC5011 – One-stage heat/cool or heat pump, hardwired
- SC5211 – Two stage heat pump, hardwired
- SC5811 – Two-stage heat/cool or heat pump, hardwired
- SC5812 – Three-stage heat/two-stage cool or heat pump, dual fuel compatible, hardwired
- SC5813 – Three-stage heat/ two-stage cool or single or dual compressor heat pump, hardwired

Non-Programmable Thermostats

- SC4010 – One-stage heat/cool or heat pump, dual powered
- SC4011 – One-stage heat/cool or heat pump, hardwired
- SC4211 – Two stage heat pump, hardwired
- SC4811 – Two-stage heat/cool or heat pump, hardwired
- SC4812 – Three-stage heat/two-stage cool or heat pump, dual fuel compatible, hardwired