



# SimpleComfort® SC2211L

Terminations

R C Y1 Y2 W2 W3 O B G E L

**FOR HEAT PUMP ONLY: 3-HEAT/2-COOL**

*Non-Programmable*

**Simple control for year-round comfort.** This easy-to-operate comfort command center allows you to match temperature to your family's lifestyle. Attractive, extra-rugged, highly reliable and accurate, this thermostat's elegant design will look and perform like new for years to come.



- 3-stage heat/2-stage cool heat pump
- New ICM patented Thermal Intrusion Barrier
- Large display with backlight
- Accuracy:  $\pm 1^{\circ}\text{F}$
- Adjustable temperature differentials
- Hardwired
- Manual changeover
- Easy access terminal block
- Field adjustable calibration
- Zoning system compatible
- Soft-touch controls
- Status LEDs






# SC2211L

- 3-stage heat/2-stage cool heat pump
- Manual changeover

**Non-Programmable  
For Heat Pump Only: 3-Heat/2-Cool  
Hardwired**

## Dimensions

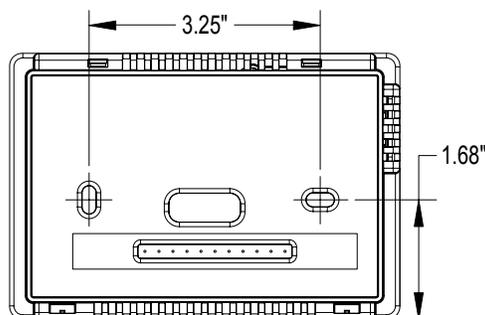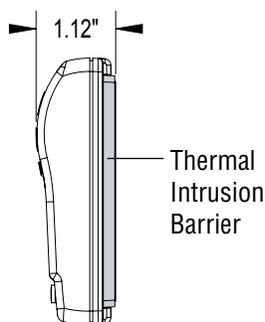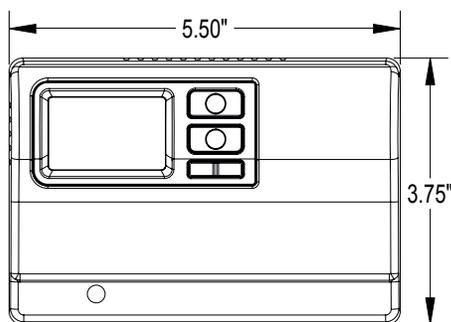

## Specifications

### Electrical Rating:

- 24 VAC (18-30 VAC)
- 1 amp maximum per terminal
- 4 amp maximum total load
- Easy access terminal block

### Temperature Control Ranges:

- 45°F to 90°F, Accuracy:  $\pm 1^\circ\text{F}$

### System Configurations:

- 2-stage heat pump, gas, oil, electric


### Terminations:

- SC2211L: **R, C, Y1, Y2, W2, W3, O, B, G, E, L**

*Specifications subject to change without notice.*

## NEW Thermal Intrusion Barrier

Exclusive, patented insulation technology eliminates thermal drift caused by wall effect.

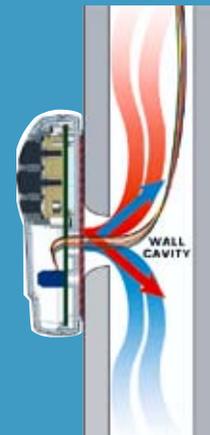

**If you like this model, be sure to try out these other thermostats from ICM Controls!**

**SimpleComfort® PRO Series – Innovation and technology that simplifies installation and increases profitability!**

- Flexible 7-day, 5-2-day and 5-1-1-day programming (programmable models)
- ICM's patented Thermal Intrusion Barrier
- ICM's patent-pending SimpleSet™ Target Programming technology
- Large display with backlight
- Permanent memory
- Auto or manual changeover
- Field adjustable calibration
- Configurable remote sensor compatible
- Keypad lockout
- Soft-touch controls

## Programmable Thermostats

- SC5010** – One-stage heat/cool or heat pump, dual powered
- SC5011** – One-stage heat/cool or heat pump, hardwired
- SC5211** – Two stage heat pump, hardwired
- SC5811** – Two-stage heat/cool or heat pump, hardwired
- SC5812** – Three-stage heat/two-stage cool or heat pump, dual fuel compatible, hardwired
- SC5813** – Three-stage heat/ two-stage cool or single or dual compressor heat pump, hardwired

## Non-Programmable Thermostats

- SC4010** – One-stage heat/cool or heat pump, dual powered
- SC4011** – One-stage heat/cool or heat pump, hardwired
- SC4211** – Two stage heat pump, hardwired
- SC4811** – Two-stage heat/cool or heat pump, hardwired
- SC4812** – Three-stage heat/two-stage cool or heat pump, dual fuel compatible, hardwired