

Hot Heads Handle It

Check out these popular accessories


All heads connect to any meter with a mVDC range through Fieldpiece deluxe leads. Handle all your superheat needs with the ASH3 combined with the ARH4.



ASH3

Superheat w/ K-type Tcouple


- Superheat (R22&R410A), temp (°C/°F), pressure
- Includes pipe clamp K-type thermocouple
- "STABLE" indicator
- Auto off for data logging (DL2)

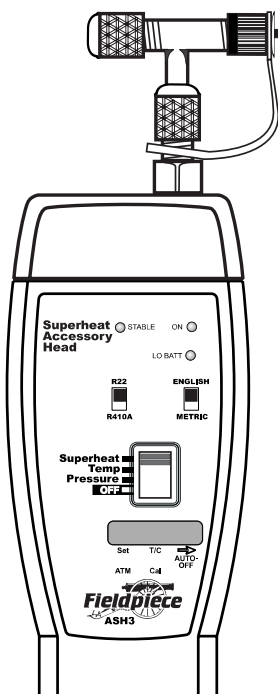

AVG2

Vacuum Gauge



- Includes inline "T"
- Range: 50-2000 microns Hg
- LED indicators show increasing and decreasing pressure
- "STABLE" indicator
- Auto off for data logging with the DL2

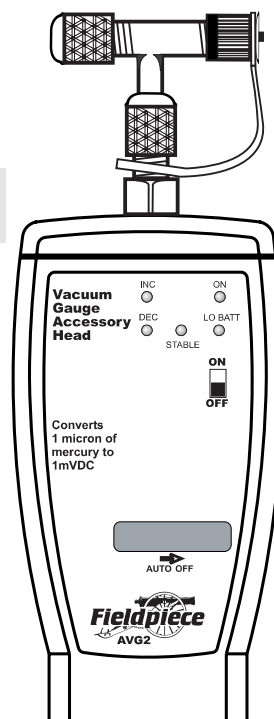

AAV3

Air Velocity & Temperature

- Use to estimate CFM
- Ft/min, meters/sec, MPH, KM/hr
- Range: 80-5900ft/min
- °F and °C
- Range: -4 to 140°F
- Auto-off

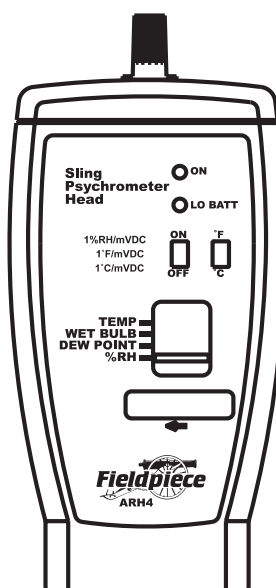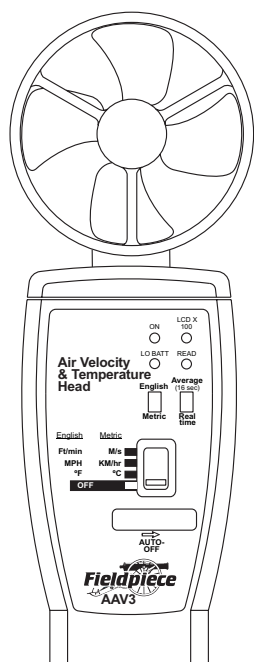

ARH4

Digital Psychrometer

- Wet bulb, temp, dew point %RH
- °C, °F switch
- Auto off for data logging (DL2)
- Use to find "target" superheat



580 West Central Avenue Suite A, Brea CA 92821 Phone: (714) 257-9060 Fax: (714) 257-9069

www.fieldpiece.com