


Venstar 1-Day Programmable Thermostat T1700

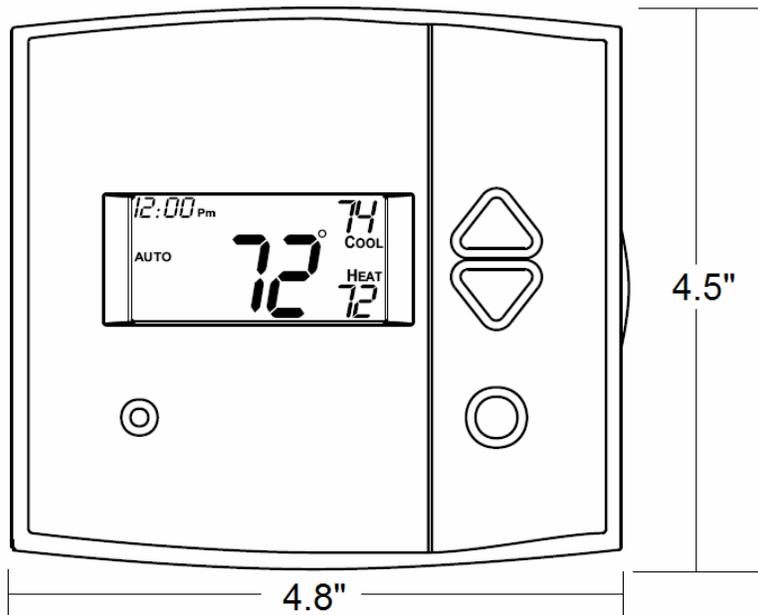

STANDARD FEATURES:

- 1-Day Programmable with up to 4 time periods
- Auto changeover, 2-stage heat, 1-stage cool for use with gas/electric, heat pump, electric & hydronic heat
- Configurable for manual changeover, also configurable programmable or non-programmable
- Display shows both heating and cooling setpoints and room temperature simultaneously
- All programming and setpoints stored in non-volatile memory, and are never lost in power failure
- Service UV lamp indicators
- Red/Green LED shows whether thermostat is calling for heating or cooling
- 5-minute compressor time guard and adjustable cycle limit, both defeatable for servicing equipment
- Outdoor sensor ready (wired or wireless)
- Thermoglow backlit electro-luminous display and backlit color coded keys and legends
- Accepts accessory IR Remote Control system (Venstar part number ACC0431)
- Accepts accessory EZ Programmer (Venstar part number ACC0432)
- For accessory locking cover use (Venstar part number ACC0620)

MODEL:	T1700	QUANTITY:		DATE:		
JOB NAME:						
LOCATION:						
BUYER:				BUYER P.O.#:		
ENGINEER:						