


Venstar Commercial Flat Stat T2300FS

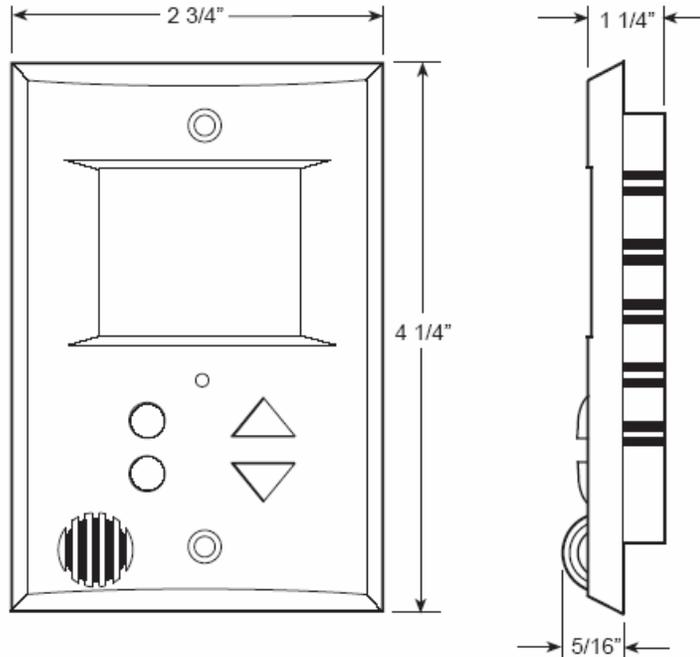

STANDARD FEATURES:

- Low profile design fits flat to wall for attractive, unobtrusive look. Bracket included for drywall installation.
- 7-Day programmable with up to 4 Time periods per day, with copy command
- Holiday programming (up to 99 days per year).
- 3 Security Levels with setpoint limiting.
- 4 Hour Setback Override Timer adjustable in 30 min. increments.
- Soft Start - up to 100 units can be started in sequence from a single remote contact closure with no two units starting up simultaneously
- Pre-Occupancy Purge - fan runs before programmed occupancy time, adjustable 0 to 3 hours.
- Energy Saving Smart Fan - With the fan on continuously, fan runs only in occupied periods or when the system calls for heating or cooling in unoccupied periods.
- Thermoglow Continuously Lit Electro-luminous Display.
- Display shows both heating and cooling setpoints and room temperature simultaneously.
- Maintains temperature to within 1° of setpoint.
- No batteries required, stat retains correct time for up to 48 hours in case of power failure.
- All programming and setpoints stored in non-volatile memory, and are never lost in power failure.
- Service filter indicator (adjustable 200 to 1950 hours).
- Red/Green LED shows whether thermostat is calling for Heating or Cooling.
- 5 minute compressor time guard and adjustable cycle limit, both overrideable for servicing equipment.
- On board dry contact closure available to force stat into occupied operation.
- Optional tamper-proof remote room sensor available with push-button override.
- Thermostat Locking - Set points can be adjusted only by authorized individuals if this feature is turned on.
- Meets California Commercial Title 24.

MODEL:	T2300FS	QUANTITY:		DATE:		
JOB NAME:						
LOCATION:						
BUYER:				BUYER P.O.#:		
ENGINEER:						