

## ProPEX® EP Swivel Faucet Adapter

Submittal Information  
Revision A: Feb. 14, 2008

### Project Information

Job Name:

Location:

Part No. Ordered:

Engineer:

Date Submitted:

Contractor:


Submitted By:

Manufacturer's Representative:

Approved By:

### Technical Data

Nut:	Brass/Plastic
PEX Barb:	UDEL Polysulfone, 20% glass-reinforced
Nose Cone:	Ethylene Propylene Dimonomer (EPDM)
Maximum Temperature (no pressure):	320°F (160°C)
Maximum Working Temperature/Pressure:	210°F (99°C) at 150 psi

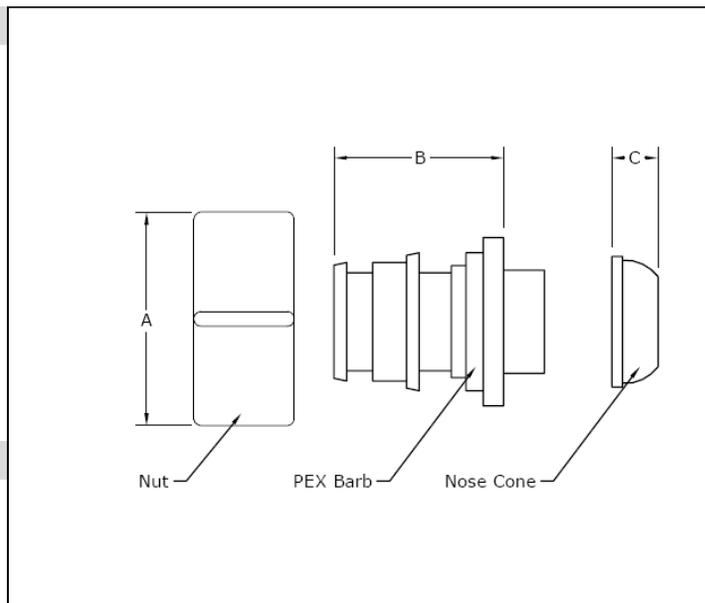

### Product Information and Application Use

The ProPEX® EP Swivel Faucet Adapter is available for use in hot and cold domestic potable water systems.<sup>1</sup> One end is manufactured with the Uponor ProPEX Fitting for swivel connections to Wirsbo AQUAPEX® tubing.

✓ Description	Part Number	A	B	C	NUT	Weight
ProPEX EP Swivel Faucet Adapter, ½" PEX x ½" NPSM	Q4360500	1.61"	1.01"	0.265"	½" NPSM	0.02 lbs.

### Installation

Use the appropriate Uponor ProPEX Ring for the tubing. For more information, refer to the AQUAPEX Professional Plumbing Installation Handbook.

### Standards

CAN/CSA B137.5; ASTM F877; ASTM F1960

### Codes

IPC; UPC; NSPC; NPC of Canada

### Listings

HUD MR 1269; ICC ESR 1099; ANSI/NSF 14- and 61-certified; IAPMO 3558

### Related Applications

PEX-a Plumbing Systems

### Contact Information

Uponor, Inc.  
5925 148<sup>th</sup> Street West  
Apple Valley, MN 55124 USA  
Phone: (800) 321-4739  
Fax: (952) 891-2008  
www.uponor-usa.com

Uponor Ltd.  
655 Park Street  
Regina, SK S4N 5N1 CANADA  
Phone: (888) 994-7726  
Fax: (800) 638-9517  
www.uponor.ca

<sup>1</sup>ProPEX® is a registered trademark of Uponor, Inc. ProPEX™ is a trademark of Uponor Ltd.