


PRODUCT SPECIFICATION DRAWING


HOLDRITE® #140 & #141 BRACKET

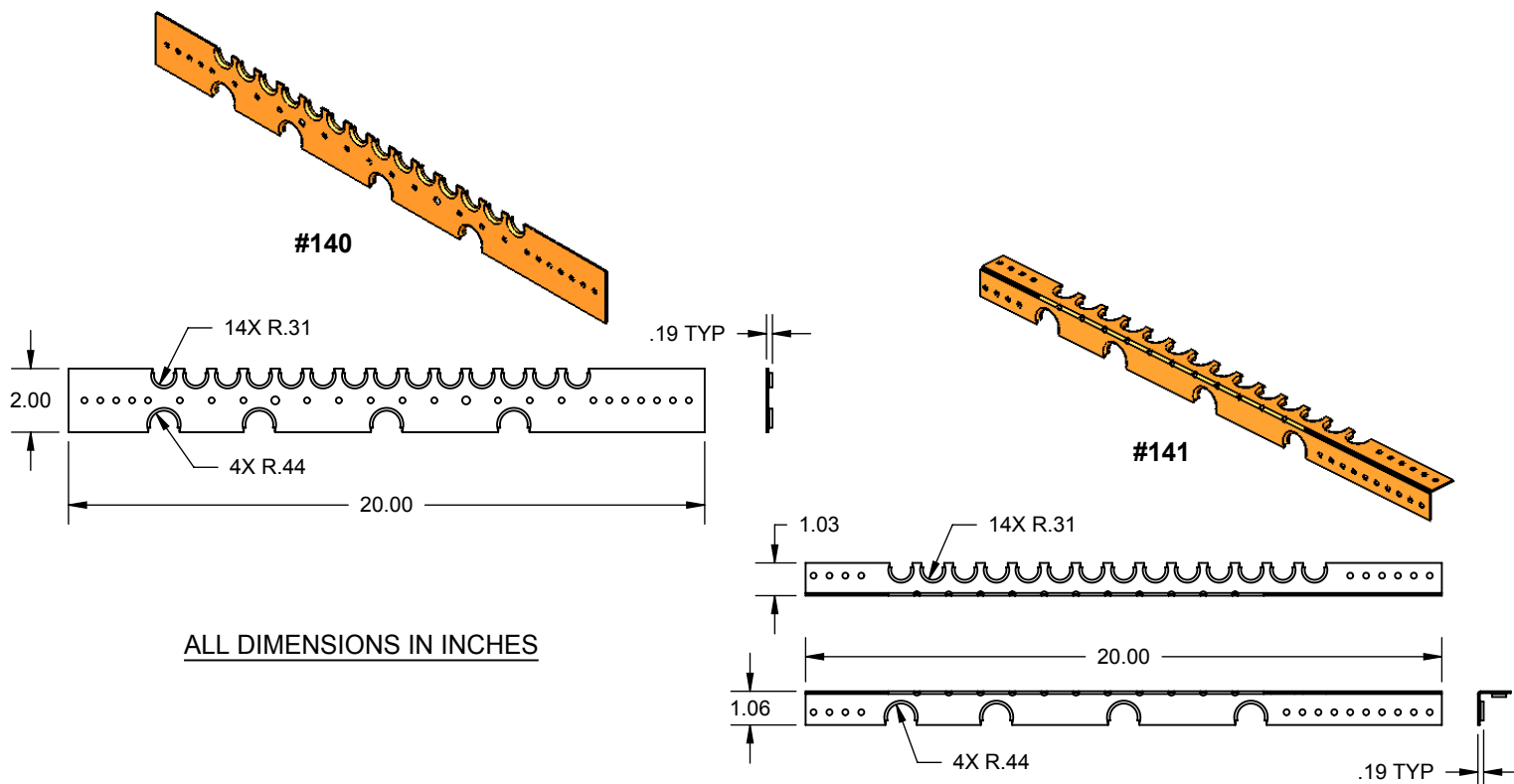

The HOLDRITE® #140 and #141 are Copper-Bonded™ steel brackets with 5/8" extruded notches on 1" centers and 7/8" extruded notches on 4" centers. #141 bracket is bent at 90° degrees in the middle for added strength. Solder copper tubing to the bracket.

Product Information:

- Material: 16 gage CRS, Copper-Bonded™
- Load rating: 25 pounds
- UPC / IPC / IAPMO listed

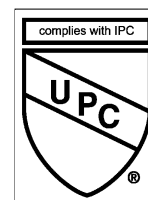

THIS INFORMATION IS PROPRIETARY TO HUBBARD ENTERPRISES AND IS SUBJECT TO CHANGE WITHOUT NOTICE. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF HUBBARD ENTERPRISES IS PROHIBITED.

••••HUBBARD ENTERPRISES••••
HOLDRITE®
 "Converting Makeshift Methods into Engineered Solutions"

| Product Submittal | |
|--------------------|------|
| Job Name: | |
| Date: | |
| Part Number: | Qty: |
| | |
| Architect / Owner: | |
| Contractor: | |
| Notes: | |
| | |
| | |