

tekmar® Submittal

24 V (ac) Transformer 009



Accessories


C 009

01/12

Replaces: 01/11

Job _____ Designer _____ Contact _____

The Transformer 009 is a 40 VA, 24 V (ac) transformer for use with products that require an external transformer. There is an in-line fuse that comes with the transformer for circuit protection.

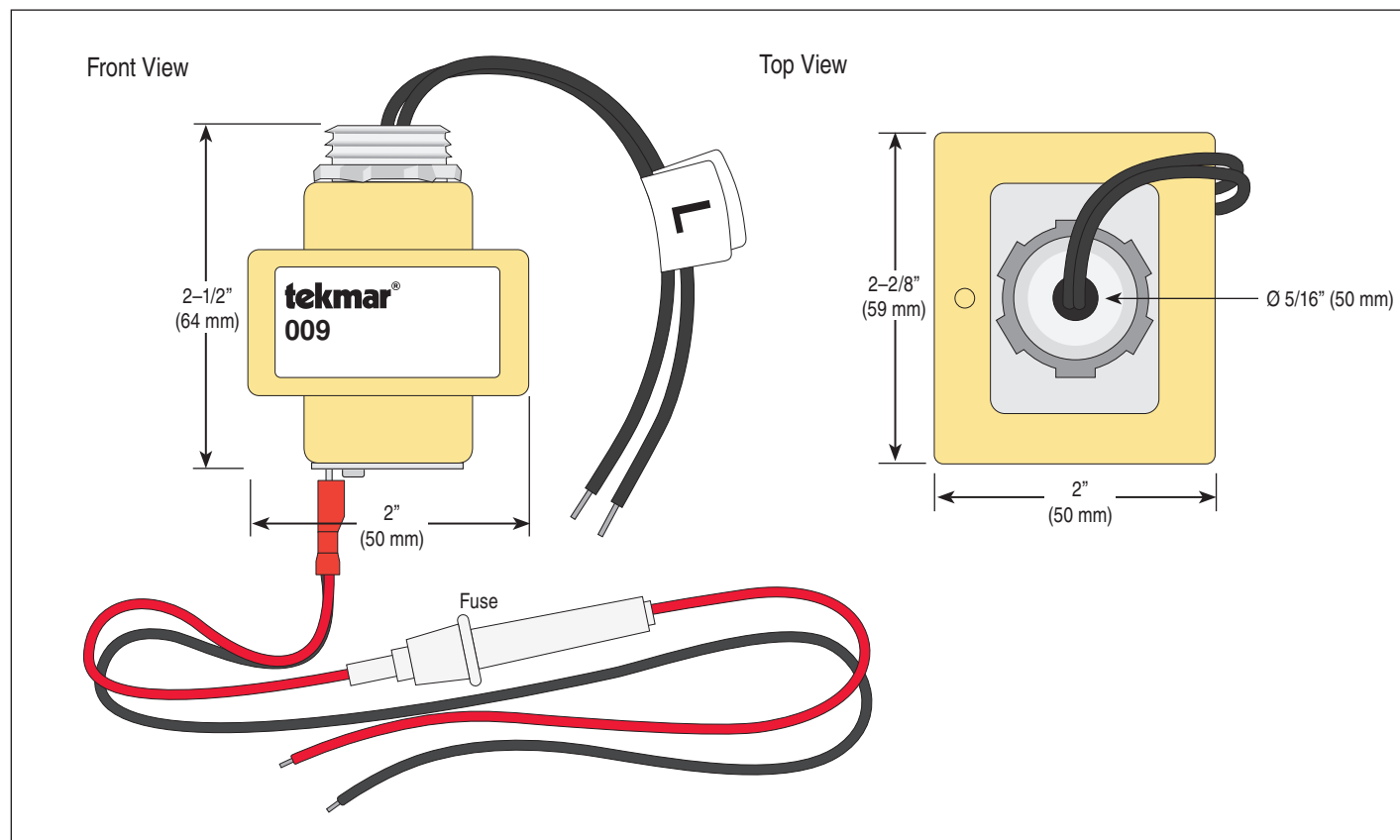

Specifications

24 V (ac) Transformer 009	
Literature	D009
Approvals	CSA standard C22.2 #66 part B & UL 5085
Ambient conditions	Indoor use only, 32 to 221°F (0 to 105°C)
Input power supply	120 V (ac) ± 10%, 60 Hz
Output power available	24 V (ac) ± 10% 60 Hz, 1.67A, 40 VA, Class 2
Supplied fuse rating	250 V (ac), 2.0A
Warranty	Limited 3 Year (See D009 for full warranty)

Features

- 24 V (ac), 40 VA transformer
- Color coded wiring for easy in-phase wiring
- Replaceable in-line fuse included

SPECIAL REQUIREMENTS

N / A



tekmar Control Systems Ltd., Canada, tekmar Control Systems, Inc., U.S.A. **Head Office: 5100 Silver Star Road, Vernon, B.C. Canada V1B 3K4, 250-545-7749, Fax. 250-545-0650 Web Site: www.tekmarcontrols.com**

