



VALUE-WELL®


Value-Well pre-pressurized well tanks feature a deep-drawn steel dome design, butyl/EPDM diaphragm, 100% polypropylene liner, reliable hoop ring and groove construction and a 5-year limited warranty. Made in the USA at our ISO 9001:2008 registered facilities, Value-Well well tanks are an affordable solution.



Sizing

Pump Discharge Rate GPM (Approx.)	Pumps Up To 3/4 hp & 1 Minute Run Time			Pumps Over 3/4 hp & 2 Minute Run Time		
	30/50 PSI	40/60 PSI	50/70 PSI	30/50 PSI	40/60 PSI	50/70 PSI
5	VW-20	VW-20	VW-20	VW-34	VW-34	VW-44
7	VW-32	VW-32	VW-32	VW-44	VW-62	VW-62
10	VW-34	VW-34	VW-44	VW-62	VW-86	VW-86
12	VW-44	VW-44	VW-62	VW-86	VW-86	VW-119
15	VW-44	VW-62	VW-62	VW-86	VW-119	VW-119
20	VW-62	VW-86	VW-86	VW-119	VW-86 (2)	VW-86 (2)
25	VW-86	VW-86	VW-119	VW-86 (2)	VW-86 (2)	VW-119 (2)
30	VW-86	VW-119	VW-119	VW-86 (2)	VW-119(2)	VW-86 (3)
35	VW-119	VW-119	VW-86 (2)	VW-119 (2)	VW-119(2)	VW-119 (3)
40	VW-119	VW-86 (2)	VW-86 (2)	VW-119 (2)	VW-86 (3)	VW-119 (3)

Larger Tank = Fewer Tank Cycles for Longer Tank and Pump Life

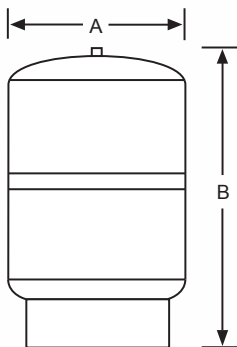

Specifications

Model Number	Tank Volume (Gallons)	Max. Accept. Volume (Gallons)	A Diameter (Inches)	B Height (Inches)	System Connection NPTF (Inches)	System Drawdown (Gallons)			Shipping Weight (lbs.)
						30/50 PSI	40/60 PSI	50/70 PSI	
VW-20	20	11.4	15	32	1	6.8	5.9	4.7	33
VW-32	32	11.2	15	47	1	10.9	9.4	7.6	43
VW-34	34	34.0	22	30	1¼	11.6	10.0	8.0	61
VW-44	44	33.9	22	36	1¼	15.0	12.9	10.4	69
VW-62	62	34.1	22	47	1¼	21.1	18.2	14.6	92
VW-86	86	46.4	26	47	1¼	29.2	25.3	20.3	123
VW-119	119	46.4	26	62	1¼	40.5	35.0	28.1	166

Malleable Iron System Connection.

Maximum Operating Temperature: 200°F. Factory Pre-Charge: 38 PSI. Maximum Working Pressure: 90 PSI.



1400 Division Road, West Warwick, RI 02893 USA
T: 800.426.8765 F: 800.293.1519
www.amtrol.com