


Pneumatic Actuated

Series PFC  
Liquid Level Controls

Components

| Item Number | Part Number | Model Number | Description             | Weight lbs. (kg) |
|-------------|-------------|--------------|-------------------------|------------------|
| 1           | 310471      | SWA-PFC-D    | Valve assembly-DA       | 2.0 (0.9)        |
| 2           | 310472      | SWA-PFC-R    | Valve assembly-RA       | 2.0 (0.9)        |
| 3           | 354411      | G-PFC-S      | Supply gauge            | 0.3 (.14)        |
| 4           | 354412      | G-PFC-O      | Output gauge            | 0.3 (.14)        |
| 5           | 354320      | FLT-PFC      | Float (includes item 6) | 0.5 (.23)        |
| 6           | 354310      | GSKT-PFC     | Gasket                  | 0.2 (.09)        |

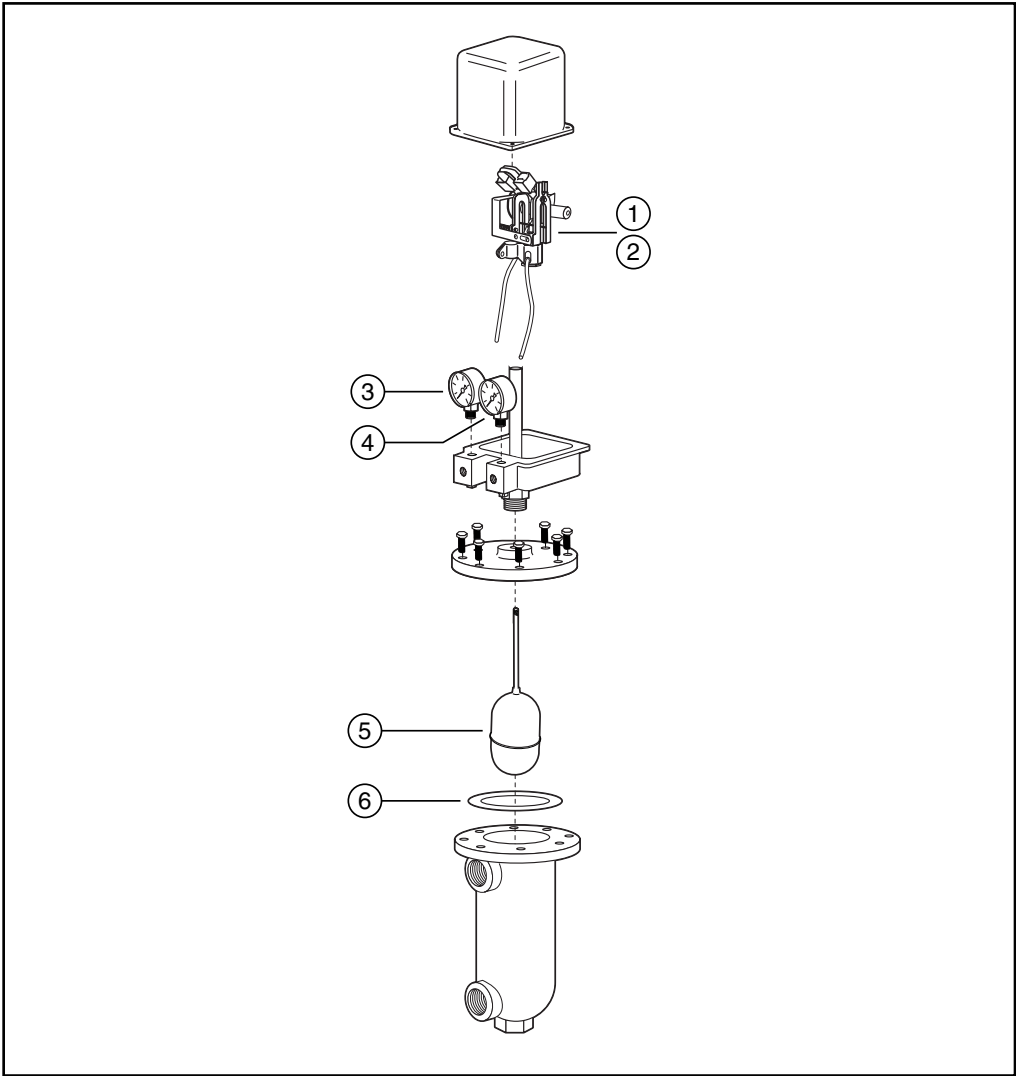

LIQUID LEVEL CONTROLS