



**Lochinvar®**  
High Efficiency Water Heaters, Boilers and Pool Heaters

**STAINLESS STEEL  
HYDRONIC BUFFER TANKS**

**Submittal Sheet**

**SBT-Sub-02b**

**STAINLESS STEEL HYDRONIC BUFFER TANKS**

**JOB NAME** \_\_\_\_\_

**LOCATION** \_\_\_\_\_

**ARCH./ENGR.** \_\_\_\_\_

**WHOLESALE** \_\_\_\_\_

**MECH. CONTRACTOR** \_\_\_\_\_

**MODEL NO.** \_\_\_\_\_

**GALLON CAPACITY** \_\_\_\_\_


**NOTES**

---

**STANDARD FEATURES**

- › R-13.4 insulation for minimal heat loss
- › Textured, impact resistant polymer jacket
- › Light-weight 316L stainless steel tank construction
- › Bulbwell
- › Drain and air vent connections
- › 5 year tank warranty

# Stainless Steel Hydronic Buffer Tank Dimensions and Specifications

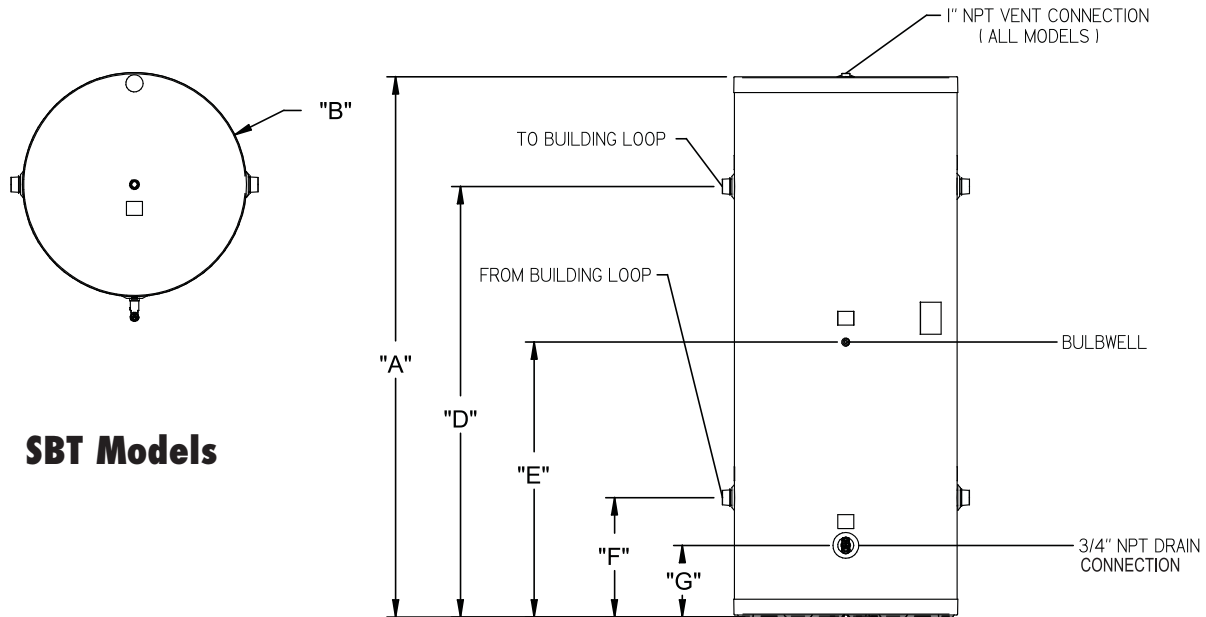

Model Number	Gallon Capacity	A	B	D	E	F	G	Supply/Return Connections	Shipping Wt. (lbs.)
SBT030	30	39-1/2"	20	28-3/4"	20-1/4"	11-3/4"	7-3/4"	1-1/2" NPT	70
SBT050	50	47	24	33-3/4"	24-1/4"	14-3/4"	8-3/4"	1-1/2" NPT	120
SBT080	80	69-1/2"	24	55-3/4"	35-1/4"	14-3/4"	8-3/4"	2" NPT	153
SBT119	119	68-1/4"	28	54-3/4"	34-1/4"	15	9	2" NPT	198



Lochinvar, LLC • 300 Maddox Simpson Pkwy • Lebanon, TN 37090 • 615-889-8900 / Fax: 615-547-1000  
[www.lochinvar.com](http://www.lochinvar.com)