

Ox Box™

NEW
CHROME PLATING

Outlet Boxes

Patent #7,360,553 & 7,735,511



STRONG

- Over the stud application offers the industry's strongest installation

FAST

- Installation times are cut in half

FLEXIBLE

- Separate boxes offer endless configuration options

DURABLE

- ABS material stands up to job site abuse

APPROVED

- Ox Box kits are UPC listed. Fire-Rated Ox Box kits are Warnock Hersey certified. Valves comply with ASME A112.18.1



Supply • Access • Drainage • Testing • Support • Specialties • Tools

Sioux Chief
MANUFACTURING SINCE 1957

Ox Box Outlet Box

Washing Machine



Ice Maker



Lavatory



Toilet/Dishwasher



Solid Installations

Durable ABS boxes, a strong steel box clip and bracket stand up to job site abuse. Over-the-stud installation is the strongest in the industry. The box clip tab bends in for a secure installation over metal studs.




Separate Stud Bays

Over-the-stud installations allow for supply and drainage lines to be plumbed into separate stud bays, reducing solder joints, installation time, risk of leaks, and burned drain pipe.



Drain & Trap Together

Complete drain and vent line can be plumbed into a 16" on-center stud bay. No need to drill through the stud, saving time, structural strength, and money for pipe protection.

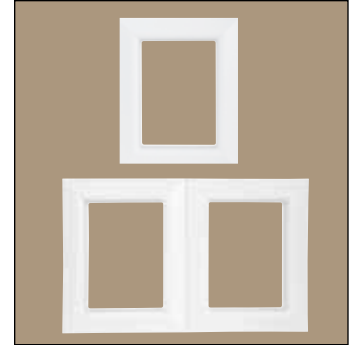

One Frame Size

All boxes share the same size frame. There will always be one frame in the warehouse, on the truck, and on the job. The frames are made from the same tough ABS material as the boxes, and the design appeals to today's demanding homeowner.

Options to Fit Every Job



Valve Options



The Ox Box is offered with or without arresters for laundry, ice maker, lavatory, and toilet applications.


Connection Options



1/2" Female Sweat



1/2" CPVC

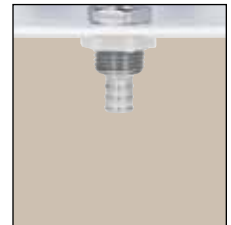


1/2" PEX F1807



1/2" PEX F1960



1/2" PEX F2080

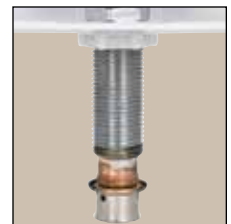

1/2" Viega® PEX Press

Multiple Installation Choices



◀ **RECOMMENDED**



Separate supply and drain boxes allow the most installation configurations of any outlet box. Eliminate the need to source and stock a different box for each application. The Ox Box is able to replace all left-drain,

center-drain, right-drain, and dual drain boxes. Box kits include box clip, support bracket, supply box, drain box, debris cover, and frame.

Unique Features

Debris Cover



Covers snap firmly into either box, protecting the valves from drywall mud or paint. Covers come standard with all boxes.

Integrated Grip Tip Test Nipple



Small tip twists off for easy testing.



Water tester conveniently connects 5/8" O.D. nipple to water supply valve.

Drain Knockout



The drain knockout removes in one piece and won't fall down the drain.

NEW



Products marked with this No Lead icon comply with the material requirements of the California Lead Plumbing Law and/or NSF-61 Annex G, which require the wetted surface of the product to contain no more than 0.25% lead. Additionally, Ox Box valves are made from C69300 (non-bismuth) brass, which is dezincification resistant and provides superior protection against aggressive water conditions.

Washing Machine Outlet Box

Standard Pack



Rough-In Pack†



Rough-In Pack with 26" Bar†



- Boxes mount securely to stud
- Separates supply and drainage systems into two stud bays
- Separate boxes offer flexible layout
- Durable ABS stands up to job site abuse
- Drain knockout is easy to remove with pliers
- Available with two Mini-Rester water hammer arresters
- Quarter-turn ball valves
- 3/4" hose outlet connections



Display Box



Ball Valves

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-2303MF	1/2" female sweat		B*	1	10	30.95 EA
696-2303CF	1/2" CPVC male		B*	1	10	31.55 EA
696-2303XF	1/2" PEX F1807		B*	1	10	32.05 EA
696-2303AF	1/2" PEX F2080		B*	1	10	42.45 EA
696-2303WF	1/2" PEX F1960		B*	1	10	34.45 EA
696-2303VF	1/2" Viega PEX Press		B*	1	10	37.25 EA
696-G2303MF	1/2" female sweat	✓	B*	1	10	54.95 EA
696-G2303CF	1/2" CPVC male	✓	B*	1	10	55.55 EA
696-G2303WF	1/2" PEX F1960	✓	B*	1	10	58.45 EA
696-G2303XF	1/2" PEX F1807	✓	B*	1	10	56.05 EA
ROUGH-IN PACK †						
696-2303MR	1/2" female sweat		B*	1	10	28.95 EA
696-2303CR	1/2" CPVC male		B*	1	10	29.55 EA
696-2303XR	1/2" PEX F1807		B*	1	10	30.05 EA
696-2303AR	1/2" PEX F2080		B*	1	10	40.45 EA
696-2303WR	1/2" PEX F1960		B*	1	10	32.45 EA
STANDARD PACK BAR-CODED IN DISPLAY BOX						
696-2303MFPK4	1/2" female sweat		B*	1	4	37.70 EA
696-2303CFPK4	1/2" CPVC male		B*	1	4	38.30 EA
696-2303XFPK4	1/2" PEX F1807		B*	1	4	38.80 EA
696-G2303MFPK4	1/2" female sweat	✓	B*	1	4	61.70 EA
696-G2303CFPK4	1/2" CPVC male	✓	B*	1	4	62.30 EA
696-G2303XFPK4	1/2" PEX F1807	✓	B*	1	4	62.80 EA
INTEGRAL SECONDARY STOP VALVES STANDARD PACK						
696-2323MF	1/2" female sweat		B*	1	10	68.25 EA

Ball Valves with Arresters


Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-2313MF	1/2" female sweat		B*	1	10	57.95 EA
696-2313CF	1/2" CPVC male		B*	1	10	58.55 EA
696-2313XF	1/2" PEX F1807		B*	1	10	59.05 EA
696-2313AF	1/2" PEX F2080		B*	1	10	69.45 EA
696-2313WF	1/2" PEX F1960		B*	1	10	61.45 EA
696-2313VF	1/2" Viega PEX Press		B*	1	10	64.25 EA
696-G2313MF	1/2" female sweat	✓	B*	1	10	83.95 EA
696-G2313CF	1/2" CPVC male	✓	B*	1	10	84.55 EA
696-G2313XF	1/2" PEX F1807	✓	B*	1	10	85.05 EA
696-G2313WF	1/2" PEX F1960	✓	B*	1	10	87.45 EA
ROUGH-IN PACK †						
696-2313MR	1/2" female sweat		B*	1	10	55.95 EA
696-2313CR	1/2" CPVC male		B*	1	10	56.55 EA
696-2313XR	1/2" PEX F1807		B*	1	10	57.05 EA
696-2313AR	1/2" PEX F2080		B*	1	10	67.45 EA
696-2313WR	1/2" PEX F1960		B*	1	10	59.45 EA
ROUGH-IN PACK WITH 26" BAR †						
696-2313MR26	1/2" female sweat		B*	1	10	56.45 EA
696-2313CR26	1/2" CPVC male		B*	1	10	57.05 EA
696-2313XR26	1/2" PEX F1807		B*	1	10	57.55 EA
STANDARD PACK BAR-CODED IN DISPLAY BOX						
696-2313MFPK4	1/2" female sweat		B*	1	4	64.70 EA
696-2313CFPK4	1/2" CPVC male		B*	1	4	65.30 EA
696-2313XFPK4	1/2" PEX F1807		B*	1	4	65.80 EA
696-G2313MFPK4	1/2" female sweat	✓	B*	1	4	90.70 EA
696-G2313CFPK4	1/2" CPVC male	✓	B*	1	4	91.30 EA
696-G2313XFPK4	1/2" PEX F1807	✓	B*	1	4	91.80 EA

†Purchase frames separately. See last page of brochure.

Ice Maker Outlet Box

- Boxes mount securely to stud
- Durable ABS stands up to job site abuse
- Available with Mini-Rester water hammer arrester
- High-quality quarter-turn ball valve
- 1/4" O.D. compression outlet connection


Standard Pack

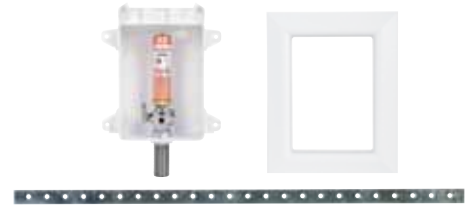

Rough-In Pack†



Standard Pack with Stainless Steel Hose

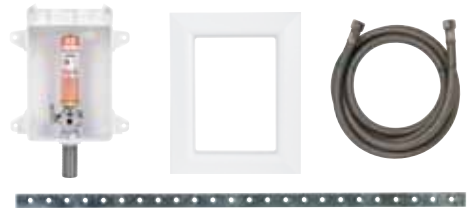

Display Box

Ball Valve

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-1000MF	1/2" female sweat		B*	1	10	17.90 EA
696-1000CF	1/2" CPVC male		B*	1	10	18.20 EA
696-1000XF	1/2" PEX F1807		B*	1	10	18.45 EA
696-1000AF	1/2" PEX F2080		B*	1	10	23.65 EA
696-1000WF	1/2" PEX F1960		B*	1	10	19.65 EA
696-1000VF	1/2" Viega PEX Press		B*	1	10	21.05 EA
696-G1000MF	1/2" female sweat	✓	B*	1	10	29.90 EA
696-G1000CF	1/2" CPVC male	✓	B*	1	10	30.20 EA
696-G1000XF	1/2" PEX F1807	✓	B*	1	10	30.45 EA
696-G1000WF	1/2" PEX F1960	✓	B*	1	10	31.65 EA
ROUGH-IN PACK †						
696-1000MR	1/2" female sweat		B*	1	10	16.40 EA
696-1000CR	1/2" CPVC male		B*	1	10	16.70 EA
696-1000XR	1/2" PEX F1807		B*	1	10	16.95 EA
696-1000AR	1/2" PEX F2080		B*	1	10	22.15 EA
696-1000WR	1/2" PEX F1960		B*	1	10	18.15 EA
STANDARD PACK WITH 72" STAINLESS STEEL HOSE						
696-1000MFS	1/2" female sweat		B*	1	10	24.90 EA
696-1000CFS	1/2" CPVC male		B*	1	10	25.20 EA
696-1000XFS	1/2" PEX F1807		B*	1	10	25.45 EA
INDIVIDUALLY BAR-CODED IN DISPLAY BOX						
696-1000MFPK4	1/2" female sweat		B*	1	5	24.40 EA
696-G1000MFPK4	1/2" female sweat	✓	B*	1	5	36.40 EA

Ball Valve with Arrester

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-1010MF	1/2" female sweat		B*	1	10	34.40 EA
696-1010CF	1/2" CPVC male		B*	1	10	34.70 EA
696-1010XF	1/2" PEX F1807		B*	1	10	34.95 EA
696-1010AF	1/2" PEX F2080		B*	1	10	40.15 EA
696-1010WF	1/2" PEX F1960		B*	1	10	36.15 EA
696-1010VF	1/2" Viega PEX Press		B*	1	10	37.55 EA
696-G1010MF	1/2" female sweat	✓	B*	1	10	47.40 EA
696-G1010CF	1/2" CPVC male	✓	B*	1	10	47.70 EA
696-G1010XF	1/2" PEX F1807	✓	B*	1	10	47.95 EA
696-G1010WF	1/2" PEX F1960	✓	B*	1	10	49.15 EA
ROUGH-IN PACK †						
696-1010MR	1/2" female sweat		B*	1	10	32.90 EA
696-1010CR	1/2" CPVC male		B*	1	10	33.20 EA
696-1010XR	1/2" PEX F1807		B*	1	10	33.45 EA
696-1010AR	1/2" PEX F2080		B*	1	10	38.65 EA
696-1010WR	1/2" PEX F1960		B*	1	10	34.65 EA
STANDARD PACK WITH 72" STAINLESS STEEL HOSE						
696-1010MFS	1/2" female sweat		B*	1	10	41.40 EA
696-1010CFS	1/2" CPVC male		B*	1	10	41.70 EA
696-1010XFS	1/2" PEX F1807		B*	1	10	41.95 EA
ROUGH-IN PACK WITH 26" BAR †						
696-1010MR26	1/2" female sweat		B*	1	10	33.40 EA
696-1010CR26	1/2" CPVC male		B*	1	10	33.70 EA
696-1010XR26	1/2" PEX F1807		B*	1	10	33.95 EA
INDIVIDUALLY BAR-CODED IN DISPLAY BOX						
696-1010MFPK4	1/2" female sweat		B*	1	5	40.90 EA
696-G1010MFPK4	1/2" female sweat	✓	B*	1	5	53.90 EA

†Purchase frames separately. See last page of brochure.


Packaging Codes || B: bulk C: cut-case box *: individually bar-coded

Lavatory Outlet Box



- Strong installation, mounting on stud
- Integral nail holes offer quick installation
- Bracket track allows for adjustment between studs
- Durable ABS stands up to job site abuse
- Flip box for top supply
- High-quality quarter-turn ball valve(s)
- 3/8" O.D. compression outlet connection(s)

Lavatory Standard Pack

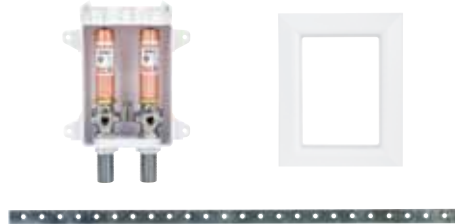

Lavatory Rough-In Pack†



Ball Valves

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-2001MF	1/2" female sweat		B*	1	10	28.70 EA
696-2001CF	1/2" CPVC male		B*	1	10	29.30 EA
696-2001XF	1/2" PEX F1807		B*	1	10	29.80 EA
696-2001WF	1/2" PEX F1960		B*	1	10	32.20 EA
696-2001AF	1/2" PEX F2080		B*	10	10	40.20 EA
696-G2001MF	1/2" female sweat	✓	B*	1	10	52.70 EA
696-G2001CF	1/2" CPVC male	✓	B*	1	10	53.30 EA
696-G2001XF	1/2" PEX F1807	✓	B*	1	10	53.80 EA
696-G2001WF	1/2" PEX F1960	✓	B*	1	10	56.20 EA
ROUGH-IN PACK †						
696-2001MR	1/2" female sweat		B*	1	10	27.20 EA
696-2001CR	1/2" CPVC male		B*	1	10	27.80 EA
696-2001XR	1/2" PEX F1807		B*	1	10	28.30 EA


Ball Valves with Arresters

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-2011MF	1/2" female sweat		B*	1	10	55.70 EA
696-2011CF	1/2" CPVC male		B*	1	10	56.30 EA
696-2011XF	1/2" PEX F1807		B*	1	10	56.80 EA
696-2011WF	1/2" PEX F1960		B*	1	10	59.20 EA
696-G2011MF	1/2" female sweat	✓	B*	1	10	81.70 EA
696-G2011CF	1/2" CPVC male	✓	B*	1	10	82.30 EA
696-G2011XF	1/2" PEX F1807	✓	B*	1	10	82.80 EA
696-G2011WF	1/2" PEX F1960	✓	B*	1	10	85.20 EA

Toilet/Dishwasher Outlet Box



Toilet/Dishwasher Standard Pack

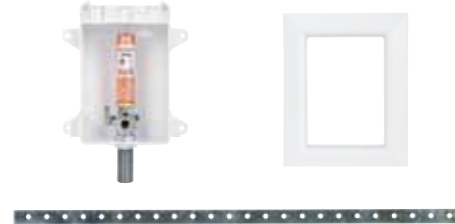

Ball Valve

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-1001MF	1/2" female sweat		B*	1	10	17.90 EA
696-1001CF	1/2" CPVC male		B*	1	10	18.20 EA
696-1001XF	1/2" PEX F1807		B*	1	10	18.45 EA
696-1001WF	1/2" PEX F1960		B*	1	10	19.65 EA
696-1001AF	1/2" PEX F2080		B*	1	10	23.65 EA
696-G1001MF	1/2" female sweat	✓	B*	1	10	29.90 EA
696-G1001CF	1/2" CPVC male	✓	B*	1	10	30.20 EA
696-G1001XF	1/2" PEX F1807	✓	B*	1	10	30.45 EA
696-G1001WF	1/2" PEX F1960	✓	B*	1	10	31.65 EA

Ball Valve with Arrester

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696-1011MF	1/2" female sweat		B*	1	10	34.40 EA
696-1011CF	1/2" CPVC male		B*	1	10	34.70 EA
696-1011WF	1/2" PEX F1960		B*	1	10	36.15 EA
696-1011XF	1/2" PEX F1807		B*	1	10	34.95 EA
696-1011AF	1/2" PEX F2080		B*	1	10	40.15 EA
696-G1011MF	1/2" female sweat	✓	B*	1	10	47.40 EA
696-G1011CF	1/2" CPVC male	✓	B*	1	10	47.70 EA
696-G1011WF	1/2" PEX F1960	✓	B*	1	10	49.15 EA
696-G1011XF	1/2" PEX F1807	✓	B*	1	10	47.95 EA

†Purchase frames separately. See last page of brochure.

Fire-Rated Outlet Box

- Available in washing machine, ice maker, lav and toilet/dishwasher outlet box
- Warnock Hersey certified
- Constructed using fire retardant plastic resin
- Only install over-the-stud or in separate stud bays for the quickest, easiest, strongest installation
- Carries the highest-rated fire certification in the industry



Fire-Rated Washing Machine Standard Pack




Ball Valves

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696R2303MF	1/2" female sweat		B*	1	10	72.95 EA
696R2303CF	1/2" CPVC male		B*	1	10	73.55 EA
696R2303XF	1/2" PEX F1807		B*	1	10	74.05 EA
696R2303AF	1/2" PEX F2080		B*	1	10	84.45 EA
696R2303WF	1/2" PEX F1960		B*	1	10	76.45 EA
696RG2303MF	1/2" female sweat	✓	B*	1	10	96.95 EA
696RG2303CF	1/2" CPVC male	✓	B*	1	10	97.55 EA
696RG2303XF	1/2" PEX F1807	✓	B*	1	10	98.05 EA
696RG2303WF	1/2" PEX F1960	✓	B*	1	10	100.45 EA

Ball Valves with Arresters

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696R2313MF	1/2" female sweat		B*	1	10	99.95 EA
696R2313CF	1/2" CPVC male		B*	1	10	100.55 EA
696R2313XF	1/2" PEX F1807		B*	1	10	101.05 EA
696R2313AF	1/2" PEX F2080		B*	1	10	111.45 EA
696R2313WF	1/2" PEX F1960		B*	1	10	103.45 EA
696R2313VF	1/2" Viega PEX Press		B*	10	10	106.25 EA
696RG2313MF	1/2" female sweat	✓	B*	1	10	125.95 EA
696RG2313CF	1/2" CPVC male	✓	B*	1	10	126.55 EA
696RG2313XF	1/2" PEX F1807	✓	B*	1	10	127.05 EA
696RG2313WF	1/2" PEX F1960	✓	B*	1	10	129.45 EA

Fire-Rated Ice Maker Standard Pack

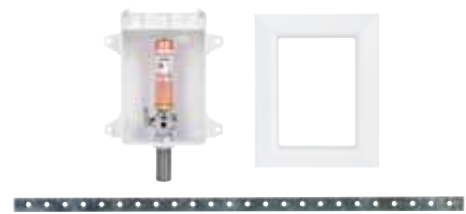



Ball Valve

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696R1000MF	1/2" female sweat		B*	1	10	59.90 EA
696R1000CF	1/2" CPVC male		B*	1	10	60.20 EA
696R1000XF	1/2" PEX F1807		B*	1	10	60.45 EA
696R1000AF	1/2" PEX F2080		B*	1	10	65.65 EA
696R1000WF	1/2" PEX F1960		B*	1	10	61.65 EA
696RG1000MF	1/2" female sweat	✓	B*	1	10	71.90 EA
696RG1000CF	1/2" CPVC male	✓	B*	1	10	72.20 EA
696RG1000XF	1/2" PEX F1807	✓	B*	1	10	72.45 EA
696RG1000WF	1/2" PEX F1960	✓	B*	1	10	73.65 EA

Ball Valve with Arrester

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696R1010MF	1/2" female sweat		B*	1	10	76.40 EA
696R1010CF	1/2" CPVC male		B*	1	10	76.70 EA
696R1010XF	1/2" PEX F1807		B*	1	10	76.95 EA
696R1010AF	1/2" PEX F2080		B*	1	10	82.15 EA
696R1010WF	1/2" PEX F1960		B*	1	10	78.15 EA
696R1010VF	1/2" Viega PEX Press		B*	10	10	79.55 EA
696RG1010MF	1/2" female sweat	✓	B*	1	10	89.40 EA
696RG1010CF	1/2" CPVC male	✓	B*	1	10	89.70 EA
696RG1010XF	1/2" PEX F1807	✓	B*	1	10	89.95 EA
696RG1010WF	1/2" PEX F1960	✓	B*	1	10	91.15 EA

Fire-Rated Outlet Box

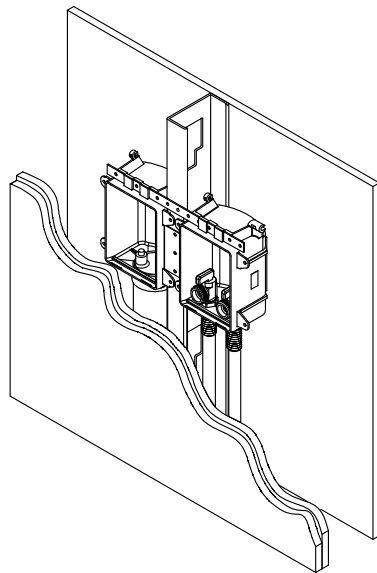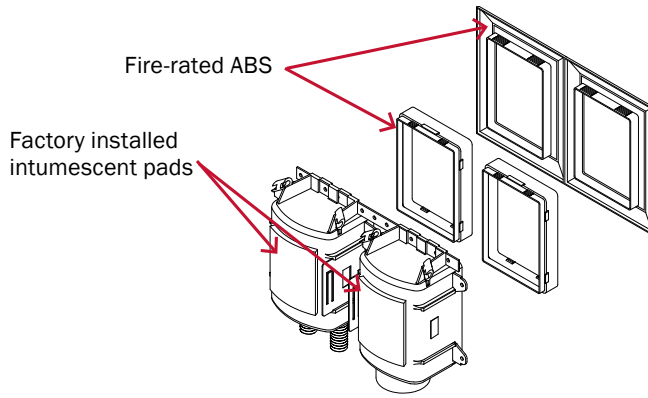

The Fire-Rated Ox Box is certified by Intertek/Warnock Hersey to the following Fire Rating Standards:

ASTM E-814

2 hours (F), 1½ hours (T)

for 2-hour design

1 hour (F), 31 min (T)

for 1-hour design

CAN/ULC S115

2 hours (F), 1½ hours (T)


for 2-hour design

1 hour (F), 31 min (T)

for 1-hour design

ASTM E119

UL 1479

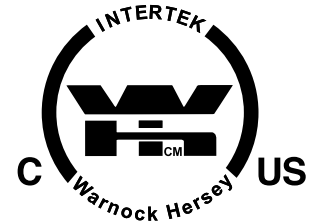

Lavatory Standard Pack



Ball Valve

Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696R1001MF	½" female sweat		B*	1	10	59.90 EA
696R1001CF	½" CPVC male		B*	1	10	60.20 EA
696R1001XF	½" PEX F1807		B*	1	10	60.45 EA
696RG1001MF	½" female sweat	✓	B*	1	10	71.90 EA
696RG1001CF	½" CPVC male	✓	B*	1	10	72.20 EA
696RG1001XF	½" PEX F1807	✓	B*	1	10	72.45 EA

Toilet/Dishwasher Standard Pack




Ball Valve


Item No.	Shank Connection	NO LEAD	Pkg	Min. Qty	Case Qty	List Price
STANDARD PACK						
696R2001MF	½" female sweat		B*	1	10	70.70 EA
696R2001CF	½" CPVC male		B*	1	10	71.30 EA
696R2001XF	½" PEX F1807		B*	1	10	71.80 EA
696R2001WF	½" PEX F1960		B*	1	10	74.20 EA
696RG2001MF	½" female sweat	✓	B*	1	10	94.70 EA
696RG2001CF	½" CPVC male	✓	B*	1	10	95.30 EA
696RG2001XF	½" PEX F1807	✓	B*	1	10	95.80 EA
696RG2001WF	½" PEX F1960	✓	B*	1	10	98.20 EA



Gas Valve Outlet Box

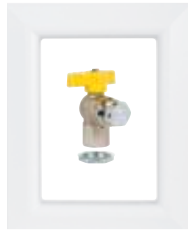

696-1020GF

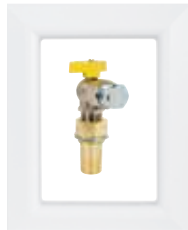

696-1021GF

- ¼-turn ball valve for easy, secure, accessible operation
- Box is available for ½" or ¾" iron-pipe applications or ½" CSST applications in both standard and fire-rated products
- Recessed box is made of high-impact ABS providing the strongest finished installation for all gas appliance needs
- Valve has CSA certification to ANSI Z21.15-1997 / CGA 9.1-M97



Item No.	Connection	Pkg	Min. Qty	Case Qty	List Price
GAS OX BOX					
696-1021GF	½" NPT valve and adapter for iron pipe, bagged	B*	1	6	28.99 EA
696-1031GF	¾" NPT valve and adapter for iron pipe, bagged	B*	1	6	32.40 EA
696-1020GF	½" FIP valve for CSST connection, bagged	B*	1	6	26.00 EA
FIRE-RATED GAS OX BOX					
696R1021GF	½" NPT valve and adapter for iron pipe, bagged	B*	1	10	70.99 EA
696R1031GF	¾" NPT valve and adapter for iron pipe, bagged	B*	1	10	74.40 EA
696R1020GF	½" FIP valve for CSST connection, bagged	B*	1	10	68.00 EA



Air Admittance Valve Outlet Box



696-11P

- ASSE listed to 1050 and 1051
- IAPMO classified listing
- Package includes:
 - TurboVent air admittance valve
 - Ox Box outlet box
 - DWV pipe adapter
 - Frame and louvered insert



PVC Item No.	ABS Item No.	Drainage Fixture Units		Thread/Hub Connection	Pkg	Min. Qty	Case Qty	List Price
		Stack	Branch					
696-11P	696-11A	8	24	1½"	C*	1	6	29.50 EA
696-12P	696-12A	20	160	2"	C*	1	6	30.50 EA



Accessories


Boxes



Frames, Extensions, and Inserts



Others

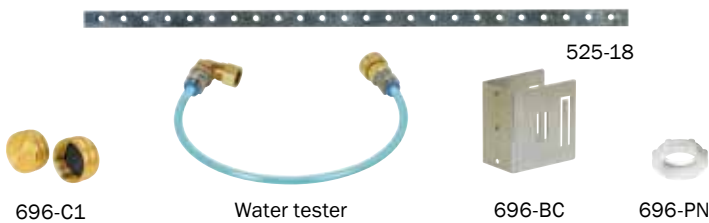

Item No.	Description	Pkg	Min. Qty	Case Qty	List Price
FRAME, EXTENSION, INSERT					
696-1F	Single frame	B	10	10	1.50 EA
696-2F	Double frame	B	10	10	2.00 EA
696-EX	Frame extension	B	10	10	3.25 EA
696-LC	Louvered frame insert	B	10	10	4.00 EA
696-SC	Solid frame insert	B	10	10	4.00 EA
OUTLET BOX					
696-1	One-hole supply box	B	10	10	5.00 EA
696-2	Two-hole supply box	B	10	10	5.00 EA
696-3	Drain box	B	10	10	5.00 EA
696R3	Drain box with fire pad and frame	B	10	10	47.00 EA
696-3F	Drain box with single frame	B	10	10	6.50 EA
696-5	1 ⁵ / ₁₆ " one-hole supply box for large shank valves	B	10	10	5.00 EA
696-6	1 ¹ / ₂ " one-hole box for DWV pipe	B	10	10	5.00 EA
696-7	2" one-hole box for DWV pipe	B	10	10	5.00 EA
OTHERS					
696-BC	Box clip	B	10	10	2.00 EA
525-18	18" support bracket	B	100	100	1.00 EA
525-26	26" support bracket	B	100	100	1.25 EA
881-23CH	Water tester	B	1	10	33.00 EA
696-PN	Shank nut	B	50	50	0.30 EA
696-C0	3/4" brass cap with gasket	B	10	10	0.80 EA
696-C1	3/8" brass cap with gasket, pair	B	10	10	1.60 EA
696-C3	3/4" brass cap with gasket, pair	B	10	10	4.20 EA

NEW Secondary Drainage Funnel

Patent Pending

- Ideal for adding condensate lines up to 1" PVC pipe
- Can be used with washing machine drain hose
- Drains 7 gpm safely
- Securely sets into drain box and locked in place with supplied clip
- Two-piece design installs quickly and is easily cleaned
- Fingers in top housing hold 1/2" CTS-1" DWV piping firmly in place



696-CF



Item No.	Description	Pkg	Min. Qty	Case Qty	List Price
SECONDARY DRAINAGE FUNNEL					
696-CF	Secondary drainage funnel	B*	10	10	6.00 EA

DISTRIBUTED BY

24110 South Peculiar Drive
Peculiar, Missouri 64078
tel: 1-800-821-3944
fax: 1-800-758-5950
www.siouxchief.com



MANUFACTURING SINCE 1957