




Designed around capacitive touch sensing technology, the new and innovative I3-Series Touch Thermostats from ICM Controls feature huge displays and a dynamic interface for intuitive programming that uses familiar icons that illuminate only when they are needed - all for an amazingly affordable price!

## Features:

- **Large Display:** Touch icons positioned off display for larger viewing area; keeps display clean of fingerprints
- **Buttonless/Switchless Front:** No mechanical buttons or switches to break or wear
- **Dynamic Interface:** Highly intuitive; Icons illuminate ONLY when they are needed
- **Customizable Printed Interface:** Color and plastic can be customized
- **Customizable Icons:** Can use branded icons, or those found on most cell phones, in any desired backlit color
- **Positioning:** Thin profile ideal for either “in control” or “wall mount” applications
- **Mounting Base:** Designed with sub base to make installation a “snap”
- **Removable Logo Plate:** Great for customers to promote their business
- **Wi-Fi:** Wi-Fi compatible model available with user friendly connectivity
- **Humidity Control:** Humidity Control model available
- **Thermal Safety:** Excessive heating bi-metal safety switch
- **User Coded Lockout:** Designed with renters and children in mind

## Dimensions

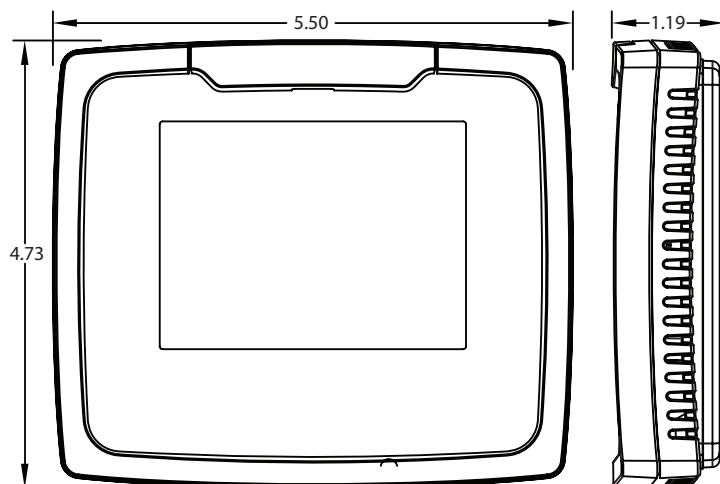

## Typical Applications:

- Temperature Controls
- Appliances
- Pool & Spa
- Test Equipment
- Security Locks
- Kiosks/POS Displays
- And lots more!

## Specifications:

- 6 (1A) relay outputs
- Dual Powered – 24 VAC, 2 AA batteries & power stealing (Wi-Fi models are hardwired)
- Remote temperature monitoring inputs (optional)
- Humidification/dehumidification (optional)
- Sub-base terminations
- 13 Maximum buttons

ICM P/N	TYPE	STAGES	HEAT PUMP	POWER	WI-FI	HUMIDITY
I1010	7-Day Programmable	1H/1C	Y	Dual	N	N
I2010	7-Day Programmable	2H/1C	Y	Dual	N	N
I2020	7-Day Programmable	2H/2C	Y	Dual	N	N
I3020	7-Day Programmable	3H/2C	Y	Dual	N	N
I3020-WF	7-Day Programmable	3H/2C	Y	Hardwired	Y	N
I3020-WFH	7-Day Programmable	3H/2C	Y	Hardwired	Y	Y

All features and specifications subject to change without notice.