




Fantech

SUBMITTAL DATA

FKD SERIES

Inline Mixed Flow Fans

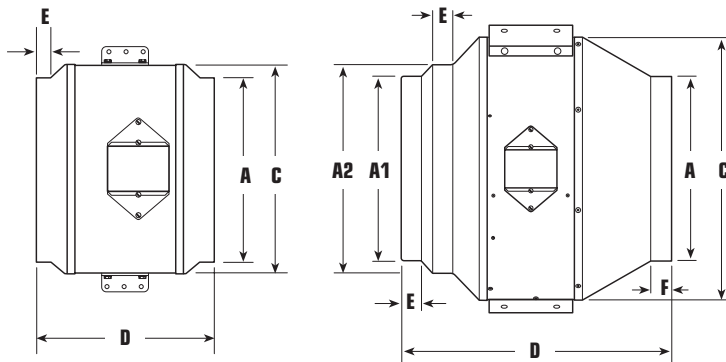

STANDARD FEATURES

- Galvanized steel housing
- Powered by external rotor motorized mixed flow impeller
- Permanently lubricated sealed ball bearings
- 100% speed controllable
- Automatic reset thermal overload protection
- Prewired electrical box
- Three-year factory warranty

Model	A	A1	A2	C	D	E	F	Metal Gauge	Avg Wt. (lbs)
FKD 8XL	7 7/8	-	-	12 1/2	15 1/2	3/4	-	18	20
FKD 10	9 7/8	-	-	12 1/2	12 1/2	3/4	-	18	19
FKD 10XL	9 7/8	-	-	14	15	3/4	-	18	25
FKD 12	11 7/8	-	-	14	12 1/2	3/4	-	18	24
FKD 12XL	11 7/8	11 7/8	14	17 7/8	18 7/8	7/8	1 5/8	18	22
FKD 14	13 7/8	11 7/8	14	17 7/8	17 1/4	1	1 5/8	18	44
FKD 14XL	13 7/8	13 7/8	16	19 3/4	20 1/4	1 1/2	1 4/8	18	54
FKD 16	15 7/8	13 7/8	16	19 3/4	18 3/4	1 1/2	1 5/8	18	54
FKD 16XL	15 7/8	15 7/8	18	22 1/8	23 1/4	1 1/4	1 5/8	18	84
FKD 18	17 7/8	15 7/8	18	22 1/8	21 3/4	1 1/4	1 5/8	18	85
FKD 18XL	17 7/8	17 7/8	20	28 1/4	29 1/4	2	1 3/4	18	108
FKD 20	19 7/8	17 7/8	20	28 1/4	27 1/4	2	1 3/4	18	109



All dimensions in inches.

Fan Specifications							Motor Specifications				
Line	Qty	Model No.	Tag	CFM	SP	Fan RPM	Watts	Volts	Phase	Hertz	Encl
1											
2											
3											
4											
5											

Accessory Items	1	2	3	4	5	Accessory Items	1	2	3	4	5
☐						☐					
☐						☐					
☐						☐					
☐						☐					
☐						☐					

Project: _____ Submitted: _____
 Customer: _____ Approved: _____
 Location: _____



Fantech

United States 10048 Industrial Blvd. • Lenexa, KS 66061 • 1.800.747.1762 • www.fantech.net
Canada 50 Kanafakt Way • Bouctouche, NB E4S 3M5 • 1.800.565.3548 • www.fantech.ca

Fantech, reserves the right to modify, at any time and without notice, any or all of its products' features, designs, components and specifications to maintain their technological leadership position.

Article #: 450368
 Rev Date: 051309