

SharkBite® Ball Valve

DESCRIPTION

The Cash Acme SharkBite® Ball Valves are high quality forged brass ball valves with SharkBite® connections. The SharkBite® connections allows the user to connect the ball valves to copper tubing, CPVC and Pex in seconds with relative ease.

FEATURES AND BENEFITS

Convenient single lever control:

Makes them easy to use and encourages shut-off of water supply.

Full Port Ball Valve:


Allows water to flow freely through valve.

Instant push-fit connections for increased ease of use:

No soldering, clamps, unions, or glue required.

Valve assembled to strict quality standards:

Measured thread engagement, measured torque.

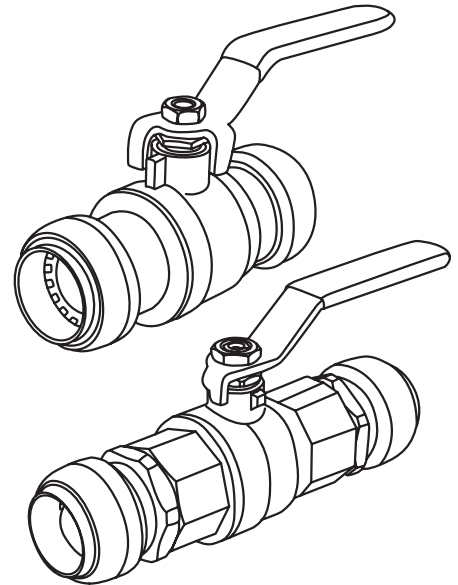

SPECIFICATION DATA

Performance:

Maximum pressure 200 psi

Maximum temperature 200°F (water)

Service Water

Ball Valve Materials:

Body Brass

Seat Ring PTFE

Ball Brass, chrome plated

Body End Retainer Brass

Stem Brass

O-ring NBR

Packing PTFE

Packing Nut Brass

Handle Zinc plated steel

Handle Nut Zinc plated steel


SharkBite® Materials:

Body DZR brass


O-ring EPDM

Grab Ring Stainless steel

Tube support liner Polysulfone

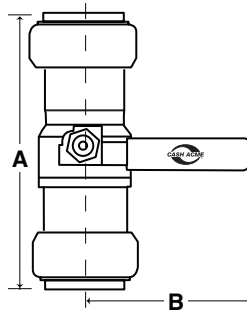

Dimensions	A	B
1/2" (22222-0000)	3.06"	3.70"
3/4" (22185-0000)	3.62"	3.70"
1" (22223-0000)	4.40"	4.66"

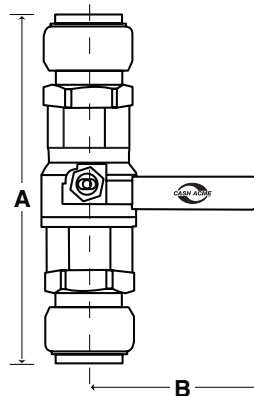

Dimensions	A	B
3/4" FNPT X 3/4" (22186-0000)	3.75"	4.5"

CONNECTIONS

SharkBite® 1/2" through 1"

CERTIFICATIONS

The SharkBite® Ball Valve 1/2", 3/4" and 1" are certified to IGC-157/NSF-61, and listed by IAPMO.

