



Dimensional Documentation


PEX Press Fittings with Attached Sleeves

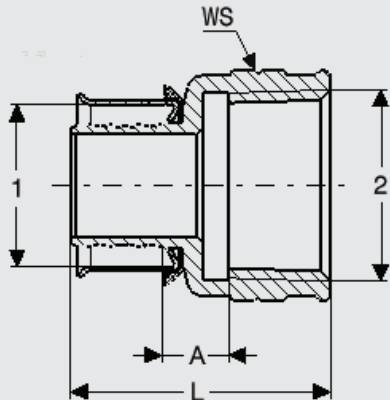

PEX Press Female NPT Adapters				
Stock Code	Dimensions 1 x 2	A (in)	L (in)	WS (in)
81520	1/2" x 1/2" F NPT	0.354	1.378	0.984
81525	1/2" x 3/4" F NPT	0.354	1.417	1.201
81541	3/4" x 1/2" F NPT	0.354	1.378	0.984
81540	3/4" x 3/4" F NPT	0.354	1.417	1.201
81545	1" x 3/4" F NPT	0.394	1.575	1.201
81560	1" x 1" F NPT	0.413	1.693	1.476

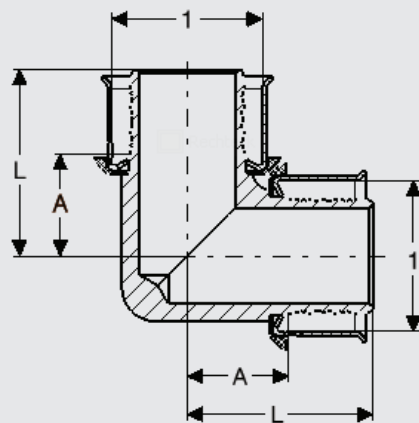

PEX Press Elbows			
Stock Code	Dimensions 1	A (in)	L (in)
83520	1/2"	0.472	0.965
83530	5/8"	0.591	1.102
83540	3/4"	0.591	1.102
83560	1"	0.886	1.496
83570	1-1/4"	0.945	1.811
83580	1-1/2"	1.083	1.949

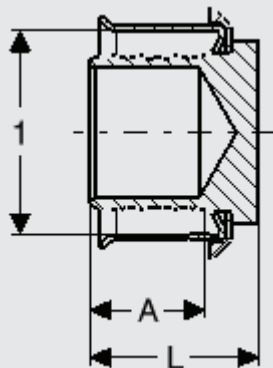


PEX Press Test Plugs			
Stock Code	Dimensions 1	A (in)	L (in)
85000	3/8"	0.472	0.728
85121	1/2"	0.472	0.728
85131	5/8"	0.472	0.728
85141	3/4"	0.472	0.728
85161	1"	0.610	0.925

Viega... the global leader in plumbing and heating systems.


301 N. Main, 9th Floor • Wichita, KS 67202 • Ph: 800-976-9819 • Fax: 800-976-9817 • E-Mail: service@viega.com • www.viega.com

Dimensional Documentation


PEX Press Fittings

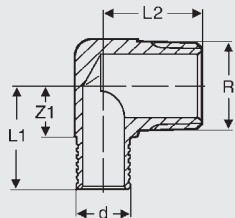

Bronze PEX Press Male NPT Elbows							
Stock Code	d x R (size)	L1 (in)	L1 (mm)	Z1 (in)	Z1 (mm)	L2 (in)	L2 (mm)
62520	1/2" PEX Press x 1/2" M NPT	1.10	28.0	0.51	13.0	1.14	29.8
62525	1/2" PEX Press x 3/4" M NPT	1.22	30.9	0.63	15.9	1.26	31.9
62540	3/4" PEX Press x 3/4" M NPT	1.22	30.9	0.63	15.9	1.26	31.9
62545	3/4" PEX Press x 1" M NPT	1.50	38.0	0.91	23.0	2.24	57.0
62560	1" PEX Press x 1" M NPT	1.61	41.0	0.87	22.0	2.28	58.0

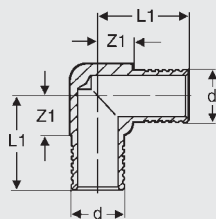


Bronze PEX Press Elbows					
Stock Code	d x d (size)	L1 (in)	L1 (mm)	Z1 (in)	Z1 (mm)
63520	1/2" PEX Press	0.93	23.5	0.33	8.5
63540	3/4" PEX Press	1.05	26.7	0.46	11.7
63560	1" PEX Press	1.57	40.0	0.83	21.0
63570	1-1/4" PEX Press	1.74	44.3	0.80	20.3
63580	1-1/2" PEX Press	1.88	47.8	0.94	23.8

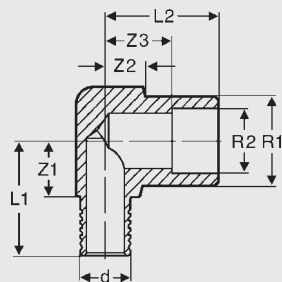


Bronze PEX Press Copper Tubing Elbows											
Stock Code	d x R (size)	L1 (in)	L1 (mm)	Z1 (in)	Z1 (mm)	L2 (in)	L2 (mm)	Z2 (in)	Z2 (mm)	Z3 (in)	Z3 (mm)
19307	1/2" PEX Press x 1/2" Copper (female) or 3/4" Copper (male)	1.05	26.7	0.46	11.7	1.06	26.9	0.48	12.1	~	~
19308	1/2" PEX Press x 3/4" Copper (female)	1.16	29.4	0.57	14.4	1.22	31.0	~	~	0.47	12.0
19309	3/4" PEX Press x 3/4" Copper (female)	1.16	29.4	0.57	14.4	1.22	31.0	~	~	0.47	12.0
19310	1/2" PEX Press x 1/2" Copper (female)	1.05	26.7	0.46	11.7	1.06	26.9	0.48	12.1	~	~
19311	3/4" PEX Press x 1/2" Copper (female) or 3/4" Copper (male)	1.16	29.4	0.57	14.4	1.23	31.3	0.43	10.8	0.73	18.5

Dimensional Documentation

PEX Press Zero Lead Fittings with Attached Sleeves

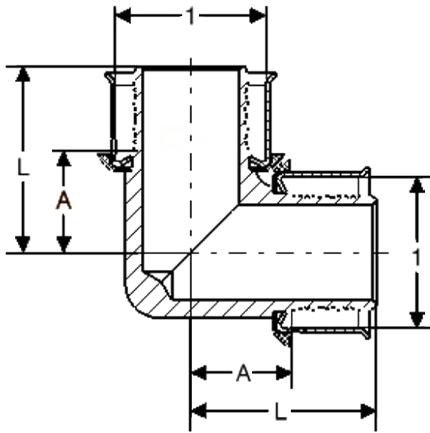

PEX Press Elbows			
Stock Code	Dimensions 1	A (in)	L (in)
93520	1/2"	0.469	0.965
93530	5/8"	0.594	1.091
93540	3/4"	0.594	1.091
93560	1"	0.878	1.496
93570	1-1/4"	0.945	1.811
93580	1-1/2"	1.142	2.008
93590	2"	1.331	2.382

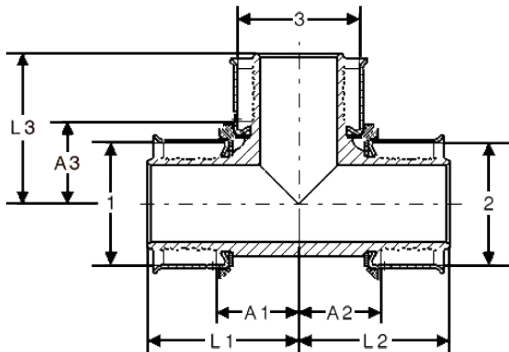

PEX Press Tees / Reducing Tees							
Stock Code	Dimensions 1 x 2 x 3	A1 (in)	A2 (in)	A3 (in)	L1 (in)	L2 (in)	L3 (in)
94020	1/2"	0.469	0.469	0.469	0.965	0.965	0.965
94021	1/2" x 3/8" x 3/8"	0.469	0.469	0.469	0.965	0.965	0.965
94022	1/2" x 1/2" x 3/4"	0.622	0.622	0.594	1.118	1.118	1.091
94030	5/8"	0.594	0.594	0.594	1.091	1.091	1.091
94040	3/4"	0.594	0.594	0.594	1.091	1.091	1.091
94032	3/4" x 1/2" x 1/2"	0.594	0.594	0.622	1.091	1.091	1.118
94034	3/4" x 1/2" x 3/4"	0.594	0.622	0.594	1.091	1.118	1.091
94036	3/4" x 3/4" x 1/2"	0.594	0.594	0.622	1.091	1.091	1.118
94060	1"	0.878	0.878	0.878	1.496	1.496	1.496
94037	1" x 1/2" x 1/2"	0.583	0.587	0.823	1.201	1.083	1.319
94039	1" x 1/2" x 1"	0.760	0.744	0.760	1.378	1.240	1.378
94038	1" x 3/4" x 1/2"	0.583	0.587	0.823	1.201	1.083	1.319

Viega... The global leader in plumbing and heating systems.

301 N. Main, 9th Floor • Wichita, KS 67202 • Ph: 877-976-9819 • Fax: 1-800-976-9817 • E-Mail: service@viega.com • www.viega.com