




Fantech

SUBMITTAL DATA

RVF SERIES Exterior-Mounted Centrifugal Fans

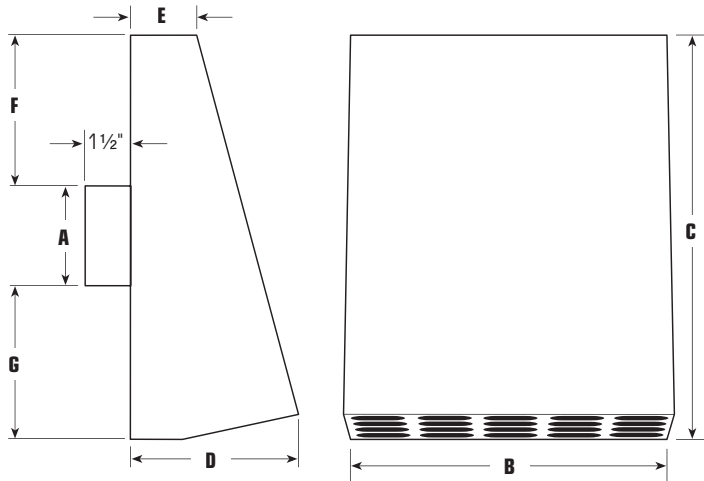

STANDARD FEATURES

- Galvanized steel housing with baked powder coat finish
- Powered by ebm-papst external rotor motorized mixed flow impeller
- Permanently lubricated sealed ball bearings
- 100% speed controllable
- Automatic reset thermal overload protection
- Prewired electrical box
- Five-year factory warranty

Model	A	B	C	D	E	F	G	Metal Gauge	Avg Wt. (lbs)
RVF 4*	3 7/8	10 1/4	13	6	2 3/4	7	2	20	8
RVF 4XL	3 7/8	10 1/4	13	6	2 3/4	5 3/4	3 1/4	20	10
RVF 6	5 7/8	10 1/4	13	6	2 3/4	4 3/4	2 1/4	20	10
RVF 6XL	5 7/8	14 1/4	17	6	2 3/4	6 3/4	4 1/4	20	14
RVF 8XL	7 7/8	14 1/4	17	6	2 3/4	5 3/4	3 1/4	20	14

All dimensions in inches.

* Model is Energy Star qualified

Fan Specifications							Motor Specifications				
Line	Qty	Model No.	Tag	CFM	SP	Fan RPM	Watts	Volts	Phase	Hertz	Encl
1											
2											
3											
4											
5											

Accessory Items	1	2	3	4	5	Accessory Items	1	2	3	4	5
<input type="checkbox"/>						<input type="checkbox"/>					
<input type="checkbox"/>						<input type="checkbox"/>					
<input type="checkbox"/>						<input type="checkbox"/>					
<input type="checkbox"/>						<input type="checkbox"/>					
<input type="checkbox"/>						<input type="checkbox"/>					

Project: _____ Submitted: _____

Customer: _____ Approved: _____

Location: _____



Fantech

United States 1712 Northgate Blvd. • Sarasota, FL. 34234 • 1.800.747.1762 • www.fantech.net
Canada 50 Kanalfakt Way • Bouctouche, NB E4S 3M5 • 1.800.565.3548 • www.fantech.ca

Fantech, reserves the right to modify, at any time and without notice, any or all of its products' features, designs, components and specifications to maintain their technological leadership position.

Article #: 450373
Rev Date: 070507