

# CUSTOM HOOD SOLUTIONS

**NOW IN STOCK  
READY FOR  
IMMEDIATE DELIVERY!**



FROM  
**Fantech**



## Fantech Introduces Custom Range Hood Liners



Fantech Custom Hood Liners, Remote-Mounted Inline Exhaust Fans and Silencers work together to give you the perfect solution for quiet, efficient kitchen ventilation.

- Heavy duty 22 gauge stainless steel construction
- Dimmable halogen lights
- Variable speed control
- Removable aluminum filters
- Prewired for use with remote mount inline or exterior mount fans

For more information call: **1-800-747-1762**  
or click on **[www.fantech-us.com](http://www.fantech-us.com)**



**Fantech**

1712 Northgate Blvd. • Sarasota, FL 34234



# Fantech

## SHL Series

### Stainless Steel Range Hood Liners


**NOW IN STOCK**  
**READY FOR IMMEDIATE DELIVERY!**



#### 22-GAUGE STAINLESS STEEL

Features include:

- Dimmable Halogen Lights
- Variable Speed Control
- Prewired for Use with Fantech Inline or Exterior Mounted Fans
- Removable Aluminum Filters

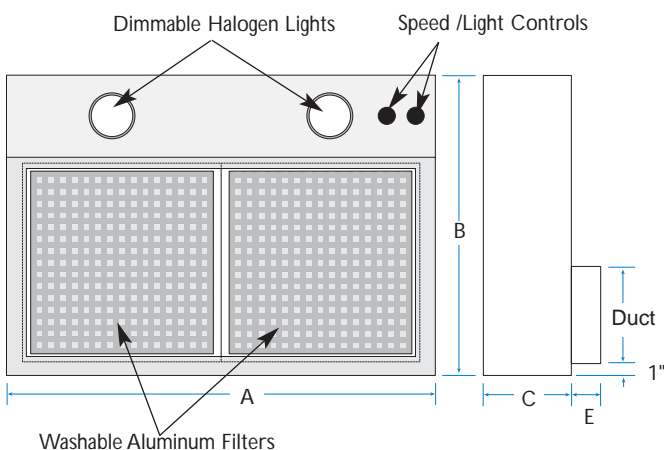

Model	UPC#	Duct†	A	B	C	E
SHL36	47036	8	34 1/2	22	6	3
SHL48	47048	10	46 1/2	22	6	3

Dimensional information shown in inches.

†Duct connections are 1/8" smaller than duct size.



Typical Range Hood Installation using Fantech's SHL Hood Liner, LD Silencer and FKD Inline Fan. Hood liner can also be used with Exterior Mounted Fans. See fan selection chart below.

#### Recommended Fans for Range Hood Liners

The following Fantech remote mount inline or exterior mounted fans are recommended for use with the new SHL Series Hood Liner to create a powerful yet quiet kitchen ventilation system.

##### SHL36

Model	Location	Mounting	Airflow at 0"	Typical Airflow†	Sones	Sones with Silencer
FX 8	interior	inline	481	370	7.3	2.6
FX 8XL	interior	inline	521	450	10.0	3.3
FKD 8XL	interior	inline	836	650	14.1	6.3
FKD 10XL	interior	inline	1266	1020	20.2	8.0
RVF 8XL	exterior	wall	435	370	9.8	3.7
RE 8XL	exterior	roof/wall	401	350	9.7	3.6
RE 10XL	exterior	roof/wall	753	700	16.4	5.2

##### SHL48

Model	Location	Mounting	Airflow at 0"	Typical Airflow†	Sones	Sones with Silencer
FX 10	interior	inline	481	370	7.3	2.6
FX 10XL	interior	inline	521	450	10.0	3.3
FKD 10	interior	inline	836	650	14.1	6.3
FKD 10XL	interior	inline	1266	1020	20.2	8.0
FKD 12XL	interior	inline	2016	1460	18.9	8.4
RE 10XL	exterior	roof/wall	753	720	16.4	5.2

†Typical airflow is an estimate based on a system with 20-feet of duct, two 90 degree elbows, backdraft damper, roof cap and filter.

#### Fantech Hood Silencers

Model	UPC#	Ø Duct	Outside Ø	Length
LD 6	79060	6	10 1/4	23 5/8
LD 8	79080	8	12 1/2	23 5/8
LD 10	79100	10	14	35 1/2
LD 12	79120	12	17 3/4	35 1/2
LD16	79160	16	25	35 1/2

Galvanized steel silencers can typically reduce "perceived" sound level of kitchen ventilation system by more than 50%.

#### United States

1712 Northgate Blvd.  
Sarasota, FL 34234  
(T) 800.747.1762 • (F) 800.487.9915  
(T) 941.309.6000 • (F) 941.309.6099

#### Ontario & Western Canada

10-6665 Tomken Rd., Unit 10  
Mississauga, ON • Canada L5T 2C4  
(T) 800.407.6195 • (F) 800.407.8965  
(T) 905.696.9241 • (F) 905.696.9236

#### Québec & Atlantic Provinces

50 Kanafflakt Way  
Bouctouche, NB • Canada E4S 3M5  
(T) 800.565.3548 • (F) 877.747.8116  
(T) 506.743.9500 • (F) 506.743.9600

Fantech product specifications are subject to change without notice.

Form # SHL502