

White-Rodgers 25M Series

Universal

Universal Replacement Clothes Dryer Combination Gas Control


- Two models replace virtually all of our 25M Series appliance gas valves
- Reduce your truck stock
- Quick replacement because of its “exact change-out” design
- Electronic Quick Shutoff feature protects your customer and your reputation

25M01A-100

*Universal
Right Angle Left Application*

25M01A-101

*Universal
Right Angle Right Application*

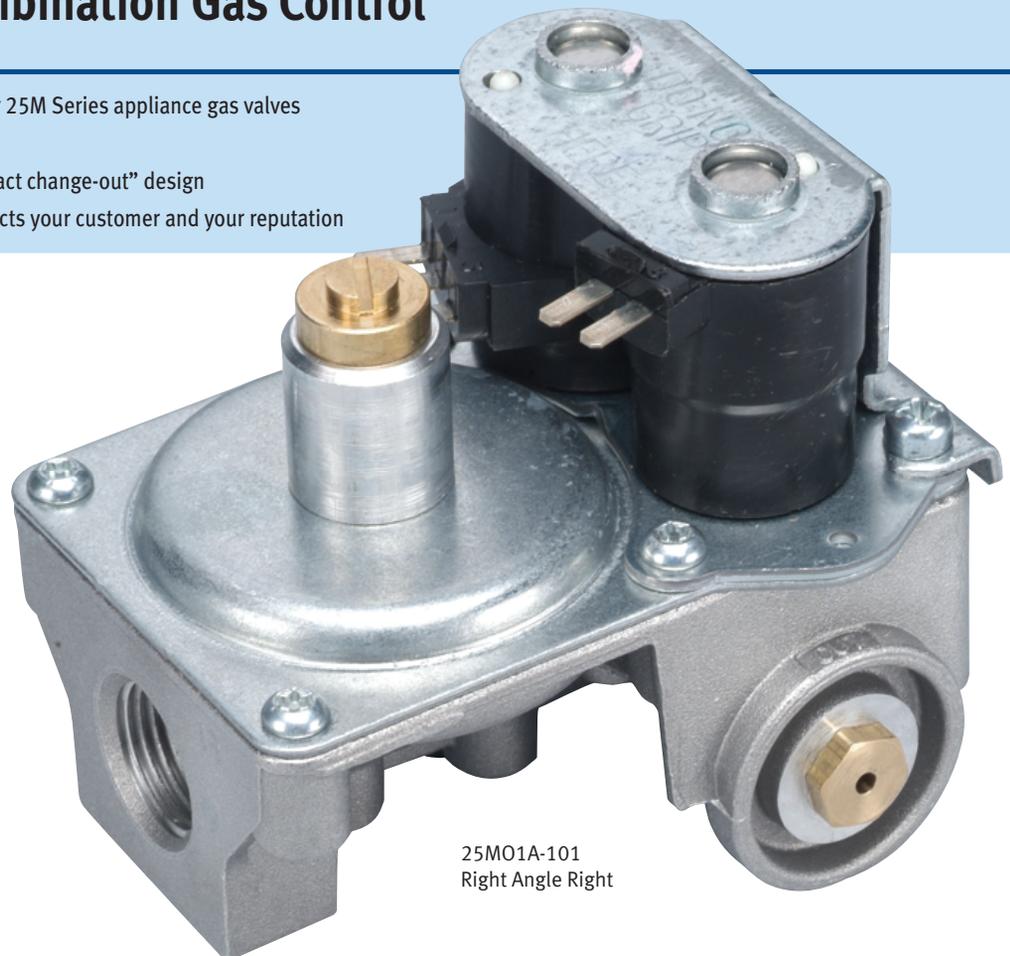

25M01A-101
Right Angle Right

Replace the original with the original.

Two universal models replace virtually all 25M Appliance Gas Valves.

White-Rodgers, the leader in appliance gas valves, now has available two universal replacement 25M01A Clothes Dryer Gas Valves. These universal products are a combination gas pressure regulator and dual automatic gas valve, designed specifically for use on gas clothes dryers.

These two universal 25M01A models will replace virtually all of our existing 25M01A and 25M51A Series gas valves. This means you can reduce your truck stock and save time on the job with its “exact change-out” replacement design. The 25M01A-100 is the Right Angle Left (RAL) model and the 25M01A-101 is the Right Angle Right (RAR) model.

Plus, you can trust White-Rodgers quality products to help protect your reputation. The universal 25M01A gas valves include the Electronic Quick Shutoff feature. The dual-coil design of the primary solenoid ensures that the gas valve, in conjunction with the dryer ignition circuit, quickly and reliably shuts off the flow of gas in the event of an interruption in power...and then does not allow the flow of gas again until the system has been reset.

White-Rodgers

25M Series Universal Replacement Gas Dryer Combination Control

25M01A-100

Universal
Right Angle Left Application

25M01A-101

Universal
Right Angle Right Application

Features	Kit Includes	Dimensions	Thermal Specifications
Compact Design	Extensive Cross Reference	Pipe Size: 3/8" x 11/32"	Operating Ambient Temperature: 40° to 175°F
Split Coil	LP/NAT Spring	Capacity	Outlet Pressure Adjust Range:
Inlet/Outlet Screen	Eight Orifices (6 Nat/2 LP)	1" P.D. Capacity @ 40K	Natural Gas: 2.5" to 4.0" W.C.
Field Adjustable Regulator	2 Bushings	Electrical Specifications	LP Gas: 9.0" to 12.0" W.C.
Replaceable Operating Coils (no gas interruption)	2 Nuts	<i>Rating</i>	Maximum Pressure:
Outlet Pressure Tap		120V @ 60 Hz	1/2 PSI

Gas Dryer-OEM Combination Valve Replacement Guide

OEM Model #	White-Rodgers Replacement Part Number	Orifice Size	Flow Direction	Gas Type	Reg Setting(s)	Inlet Pressure	Customer P/N on Labels
25M01A-128	25M01A-101	#43 (.089)	RAR	Natural	3.5"	7"	6-3061760
25M01A-130	25M01A-100	#45 (.082)	RAL	Natural	3.5"	7"	6-3060840
25M01A-131	25M01A-101	#41 (.096)	RAR	Natural	3.5"	7"	6-3083450
25M01A-132	25M01A-101	#41 (.096)	RAR	Natural	3.5"	7"	3-08541
25M01A-143	25M01A-100	#44 (.086)	RAL	Natural	3.3"	7"	630822
25M01A-144	25M01A-100	#44 (.086)	RAL	Natural	3.3"	7"	145493
25M01A-145	25M01A-100	#42 (.0935)	RAL	Natural	3.3"	7"	131180700
25M01A-146	25M01A-100	*#44 (.086)	RAL	Natural	3.6"	7"	58804
25M01A-149	25M01A-100	*#40 (.098)	RAL	Natural	3.5"	7"	60353
25M01A-151	25M01A-100	#47 (.0785)	RAL	Natural	3.0"	7"	3401776
25M01A-152	25M01A-100	#40 (.098)	RAL	Natural	3.5"	7"	60667
25M01A-153	25M01A-100	**2.4mm (.0945)	RAR	Natural	3.0"	7"	8281911
25M01A-155	25M01A-100	#44 (.086)	RAL	Natural	3.5"	7"	62959
25M01A-156	25M01A-100	*#42 (.0935)	RAL	Natural	3.5"	7"	504091
25M01A-157	25M01A-100	*#42 (.0935)	RAL	Natural	3.5"	7"	510506
25M01A-164	25M01A-101	#43 (.089)	RAR	Natural	3.0"	7"	20065959
25M01A-166	25M01A-101	#42 (.0935)	RAR	Natural	3.0"	7"	8281908
25M01A-167	25M01A-101	#52 (.0635)	RAR	Natural	3.0"	7"	8281915
25M01A-168	25M01A-101	#44 (.086)	RAR	Natural	3.0"	7"	8281914
25M01A-169	25M01A-101	#52 (.0635)	RAR	Natural	3.0"	7"	8281910
25M01A-175	25M01A-101	#48 (.0760)	RAR	Natural	3.5"	7"	
25M01A-176	25M01A-101	#43 (.089)	RAR	Natural	3.0"	7"	964D498G
25M01A-177	25M01A-101	#46 (.081)	RAR	Natural	3.5"	7"	53-3288
25M01A-181	25M01A-101	*#46 (.081)	RAR	Natural	3.5"	7"	63-6786
25M01A-185	25M01A-100	#38 (.1015)	RAL	Natural	3.3"	7"	131180500
25M01A-186	25M01A-101	#44 (.086)	RAR	Natural	3.0"	7"	8281919
25M01A-187	25M01A-100	#42 (.0935)	RAL	Natural	3.0"	7"	8181917
25M01A-196	25M01A-100	#43 (.089)	RAL	Natural	3.5"	7"	
25M01A-876	25M01A-101	#54 (.055)	RAR	LP	11.0"	14"	572D366G
25M51A-177	25M01A-101	#56 (.0465)	RAR	Non-Regulated			53-2908

* Must utilize original orifice holder with new valve and new orifice.
 ** Must utilize original orifice installed on valve.



St. Louis, Missouri Markham, Ontario
 314-553-3600 905-201-4701
www.white-rodgers.com

The Emerson logo is a trademark and a service mark of Emerson Electric Co.



WR-9507