

BOSHART INDUSTRIES

Telephone: 1-519-595-4444 - Toll Free: 1-800-561-3164

Fax: 1-519-595-4380 - www.boshart.com

8-5

June 29/12

STAINLESS STEEL CONSTANT PRESSURE MANIFOLD

- 1" FPT tank port makes this manifold functional with any tank on the market
- 1" FPT ports can be bushed down to match your tank and transducer
- MPT x FPT line connections on both ends for ease of installation
- Two 3/4" FPT ports accommodate a relief valve and a hose bibb
- One 1/4" FPT port accommodates a 2" or 2-1/2" dial 1/4" MPT center back mount gauge



 
PART NO.	TANK CONNECTIONS	IN-LINE CONNECTIONS	TOTAL LENGTH	TRANSDUCER PORT	DRAIN/RELIEF PORTS	PRESSURE GAUGE PORT	QUANTITY CTN	CASE	LIST PRICE-A
07M-125SS	1" FPT	1- 1/4" MPT x 1" FPT	11"	(1) 1"	(2) 3/4"	(1) 1/4"	4	24	65.86
07M-200SS	1" FPT	2" MPT x 1-1/2" FPT	13-3/4"	(1) 1"	(2) 3/4"	(1) 1/4"	1	12	125.01

BRONZE/BRASS CONSTANT PRESSURE MANIFOLD

- Available with 3/4" or 1" FPT tank and transducer ports
- MPT x FPT line connections on both ends for ease of installation
- Two 3/4" FPT ports accommodate a relief valve and a hose bibb
- One 1/4" FPT port accommodates a 2" or 2-1/2" dial 1/4" MPT center back mount gauge



PART NO.	TANK CONNECTIONS	LINE CONNECTIONS	TOTAL LENGTH	TRANSDUCER PORT	DRAIN/RELIEF PORTS	PRESSURE GAUGE PORT	QUANTITY CTN	CASE	LIST PRICE-A
07M-125	3/4" FPT	1- 1/4" MPT x 1" FPT	13-5/8"	(1) 3/4"	(2) 3/4"	(1) 1/4"	1	16	73.27
07M-125-10	1" FPT	1- 1/4" MPT x 1" FPT	13-5/8"	(1) 1"	(2) 3/4"	(1) 1/4"	1	16	74.31
2-07M-125	3/4" FPT	1- 1/4" MPT x 1" FPT	13-5/8"	(1) 3/4"	(2) 3/4"	(1) 1/4"	1	16	61.48




NO LEAD BRASS CONSTANT PRESSURE MANIFOLD

PART NO.	TANK CONNECTIONS	LINE CONNECTIONS	TOTAL LENGTH	TRANSDUCER PORT	DRAIN/RELIEF PORTS	PRESSURE GAUGE PORT	QUANTITY CTN	CASE	LIST PRICE-A
07M-125-10NL	1" FPT	1- 1/4" MPT x 1" FPT	13-5/8"	(1) 1"	(2) 3/4"	(1) 1/4"	1	16	76.14
07M-125NL	3/4" FPT	1- 1/4" MPT x 1" FPT	13-5/8"	(1) 3/4"	(2) 3/4"	(1) 1/4"	1	16	74.81

MANIFOLD BRACKET

The bracket allows a manifold to be secured to the brackets with "U" bolts and a small pressure tank inserted to the manifold. This bracket is interchangeable to allow for two different mounting options. Brackets are steel with black powder coat finish and are supplied with lag screws, "U" bolts, nylon lock nuts and plastic end caps.

PART NO.	DESCRIPTION	QUANTITY CARTON	LIST PRICE-A
07M-125-MB	For 1-1/4" Manifold	20	40.48
07M-200-MB	For 2" Manifold	20	42.98

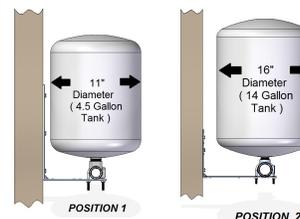

SINGLE FLAT BAR MOUNTING BRACKET KIT

This NEW design allows the universal bracket to be installed anywhere a solid mounting structure exists. The 2" wide one piece zinc plated steel bracket is interchangeable to allow for two different mounting positions.

Each bracket comes complete with a hardware kit which includes:

- Three (3) 1/4" x 2" stainless steel hex head lag screws to mount on a single wall stud
- Three (3) 1/4" x 2" stainless steel nail in anchors to mount on a concrete wall
- Two (2) stainless steel U-Bolts
- Four (4) 1/4-20 UNC stainless steel nylon insert locking nuts

PART NO.	DESCRIPTION	QUANTITY CTN	CASE	LIST PRICE-A
07MB-125	2" wide x 7-3/4" x 11-3/4" with U-bolt for 1-1/4" Manifold	1	20	28.48
07MB-200	2" wide x 7-3/4" x 11-3/4" with U-bolt for 2" Manifold	1	20	29.01

