


### 65 & 66 Damper

- For use in 5" (65) to 6" (66) round pipe
- Furnished with handle, washer and wing nut
- Has one bearing

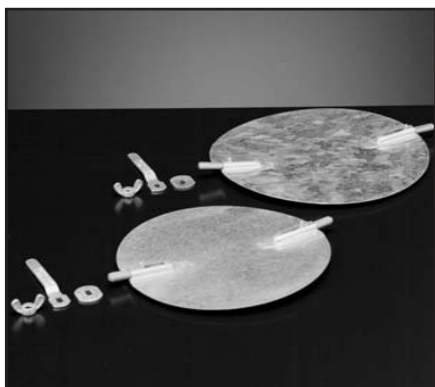

### 607/608 Damper

- Two bearings
- For use in 7" (607) to 8" (608) round pipe
- Furnished with handle, washer and wing nut



### 506/507/508 Damper

- Steel warm-air damper
- 6" (506), 7" (507) and 8" (508) sizes
- Spindle is reversible and may be inserted from either end
- The heavy spring holds damper securely under most conditions



### 69 Regulator Set

- 704 Washer
- 705 Handle
- 706 Wing Nut
- 708 (one) 5/16" Bearing
- For small dampers

69 and 70 regulator sets are furnished with retractable bolt bearing for fast, easy assembly. Merely slip bearing over edge of damper at the bearing line, lay the bearing on any firm surface, and drive the prong through the damper. The prong firmly clinches the bearing to the damper. 5/16" bearings are ample for most damper installations. Maximum damper thickness: .022" galv.



### 70 Regulator Set

- 704 Washer
- 705 Handle
- 706 Wing Nut
- 708 (two) 5/16" Bearings
- For large dampers

69 and 70 regulator sets are furnished with retractable bolt bearing for fast, easy assembly. Merely slip bearing over edge of damper at the bearing line, lay the bearing on any firm surface, and drive the prong through the damper. The prong firmly clinches the bearing to the damper. 5/16" bearings are ample for most damper installations. Maximum damper thickness: .022" galv.



### 80-3/8 Regulator Set

- 60 - 3/8" Regulator
- 56 - 3/8" Square Shank Bearing
- 80 - 3/8" Dial Regulator set
- For large dampers

80-3/8 regular sets are furnished with two solid bearings, six rivets and three sheet metal screws. Dial regulator, inner disc, handle, bolt and wing nut assembled and packaged individually. Inner disc prevents air leakage.




### 102 Damper Tip

- Fixed bearing
- Has same fastening features as No. 708 retractable bolt bearing



### 2 Casing Clip

- For fastening casings and drawbands
- 14-gauge steel

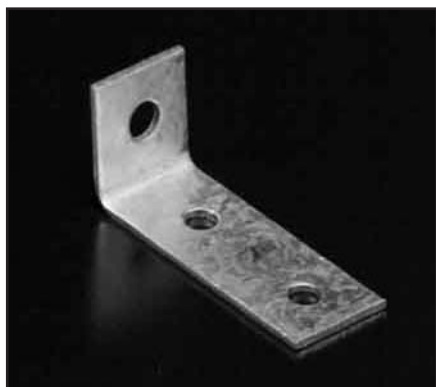

### 27 Casing Clip

- For fastening casings and drawbands
- 16-gauge steel

## Accessories

- 704 Washer
- 705 Handle
- 706 Wing Nut
- 708 - 5/16" Bearing only
- 60 - 3/8" Regulator only (square shank) - Same as furnished with 80-3/8 Regulator Set. Required separately when 3/8" square rod is used instead of bearings. Use No. 65 - 3/8" damper rod clips with both 1/4" and 3/8" square rod to fasten damper to rod.
- 65 - 3/8" Rod Clip ("U" Bolt) - Used with both 1/4" and 3/8" square rod to fasten damper to rod.