



GRUNDFOS Pressure Boosting

– Domestic water supply solutions

Grundfos' EZ Boost is a complete constant pressure boosting system. Its rugged design and easy-to-use interface ensures low-maintenance and trouble free operation.

- Dry-run protection
- Over voltage and under voltage protection
- Standard home outlet voltages (single phase)
- Many installation options

The Grundfos MQ is a compact, all-in-one pressure boosting system, designed for domestic water supply applications. The MQ, with its smart operation is both easy to install and reliable.

- Complete system
- Low noise
- Built-in protective functions
- Automatic reset



EZ Boost




MQ

GRUNDFOS EZ BOOST

Constant pressure at the touch of a button



Performance Curve:

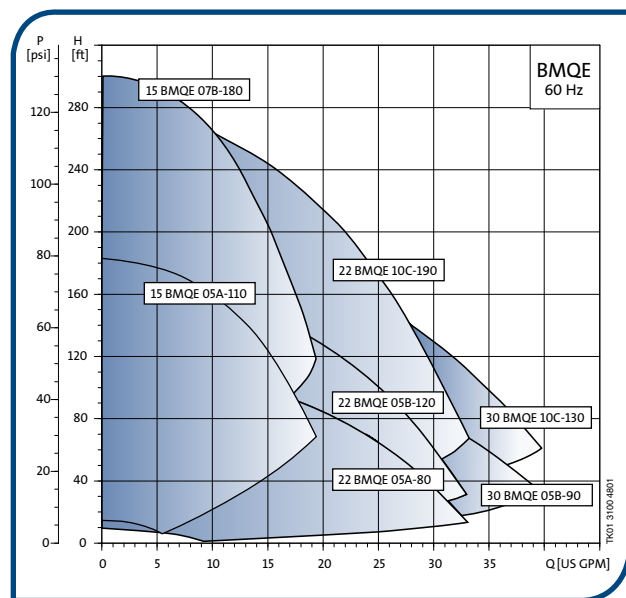


Pump Type	Volts	Material #
15 BMQE 05A-110	115	91128524
15 BMQE 05A-110	230	91128525
15 BMQE 07B-180	230	91128526
22 BMQE 05A-80	115	91128527
22 BMQE 05A-80	230	91128528
22 BMQE 05B-120	230	91128529
22 BMQE 10C-190	230	91128530
30 BMQE 05B-90	230	91128531
30 BMQE 10C-130	230	91128533

GRUNDFOS MQ

Flow-based pressure boosting system



Performance Curve:

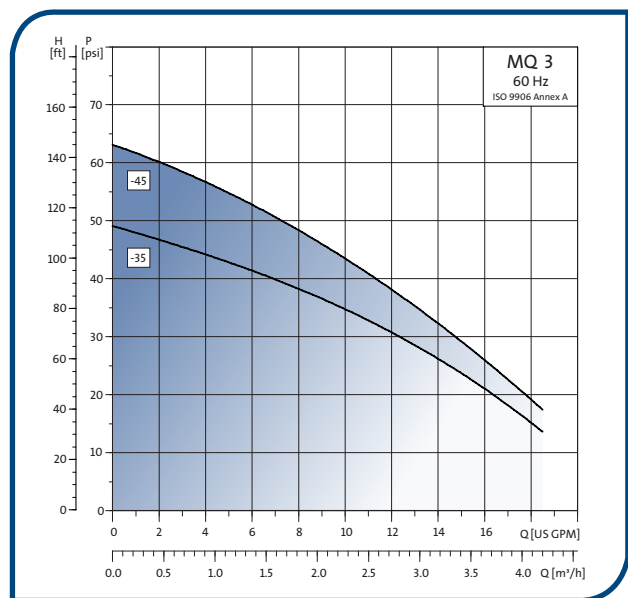

Pump Type	Volts	Material #
MQ 3-35	115	96860172
MQ 3-45	115	96860195
MQ 3-35	230	96860201
MQ 3-45	230	96860207

L-DWS-SL-02 9/09 (US)