

# AIR MOVEMENT

Dryer Duct, Vent Hose, Hose Clamps..... 32-33  
Duct Strap, Ties, Clamps..... 34-35  
Permanent Air Filters .....32  
Tapes..... 35-36  
Pure-Beam™ Ultraviolet Light .....36  
Ventilation Products ..... 33-34



# PURE-BEAM™ Ultraviolet Light

*The Pure-Beam™ ultraviolet light is designed for HVAC air disinfection and surface irradiation. Exposure to Pure-Beam™ significantly reduces air contamination caused by fungus, mold, and viruses and can cleanse surfaces overcome by mold and slime.*

- The Pure-Beam™ ultraviolet light is an excellent way to maintain indoor air quality.
- This UV Light includes a ballast, transformer, and bracket for even more convenience.
- Overall dimensions are small which makes installation easy.
- The included transformer allows operation using 120, 208, and 240/220 VAC power.
- UV lights are unobtrusive and transparent in operation, requiring little maintenance.



## FREQUENTLY ASKED QUESTIONS

**Q: What are the dimensions of the bulb?**

**A:** 14" L x 2" W x 2" H

**Q: What type of UV Light is used?**

**A:** UV-C.

**Q: What data is available to see how effective this product is?**

**A:** Scientific tests show that UV light exposure can significantly reduce air contamination caused by mold, fungus, viruses, and can cleanse surfaces of mold and slime. Ultraviolet light technology has been endorsed or specified by numerous government agencies as well as various industry groups such as:

- GSA
- NIOSH
- ASHRAE
- EPA
- CDC



**Q: What is the kill zone?**

**A:** The kill zone is the area surrounding the UV lamp in which contaminants are destroyed. Shining UV light on a surface even 6 feet away for a length of time can easily disinfect it. However, in air disinfection, the kill zone is typically 2 – 2.5 feet on all sides of the UV lamp due to the fast-moving air current.

**Q: How far from plastic surfaces does the light have to be placed in order to avoid any degradation?**

**A:** Choose a mounting location that prevents ultraviolet light exposure to plastic materials and wiring that has unknown resistance to ultraviolet light.

**Q: If placed near a filter, will any degradation of the filter occur?**

**A:** If installed near an air filter, check with the filter manufacturer for UV properties and safety.

**Q: How long does a bulb last?**


**A:** The lamp is guaranteed to last at least 9000 hours or one year.

**Q: What is the warranty period?**

**A:** The ballast has a 5 year warranty period.

**Q: What voltage does this UV light operate on?**

**A:** The lamp is powered by a 24 VAC ballast. It can be connected directly to the HVAC system's 24 VAC if there is at least 50 VA available. The transformer included also allows the system to operate at 110/120V or 208V/230V.

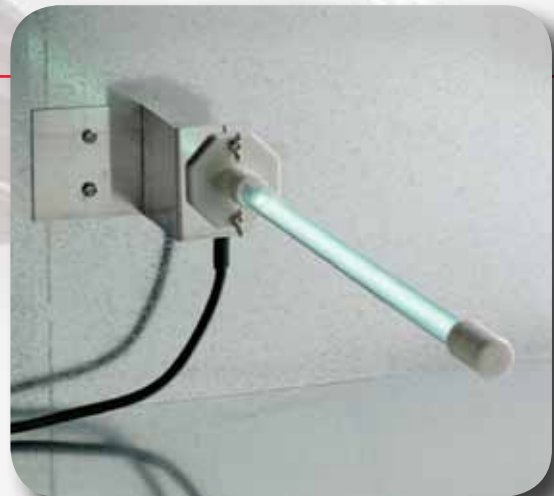

## PERMANENT AIR FILTERS

Every filter makes trade-offs between letting too much air through (good for the unit) and trapping too much “stuff” (good for the homeowner). Where is the right balance? What is best for the homeowner and their unit? DiversiTech offers two permanent air filters. Choose the Red Label Filter for a good balance between ample air flow and ability to trap dust. Choose the Blue Label Filter if you feel greater air flow is needed, perhaps for older units.

### Red Label Permanent Air Filters

- 0.12 Initial Resistance
- 82% Peak Dust Arrestance
- 76% Average Dust Arrestance
- 147 gm. Dust Holding Capacity



CATALOG NO.	1" NOMINAL SIZE	DESCRIPTION	UOM	ORDER MULTIPLE
AFR1212-1	12" x 12" x 1"	Red Label Permanent Air Filter	EA	1
AFR1220-1	12" x 20" x 1"	Red Label Permanent Air Filter	EA	1
AFR1224-1	12" x 24" x 1"	Red Label Permanent Air Filter	EA	1
AFR1420-1	14" x 20" x 1"	Red Label Permanent Air Filter	EA	1
AFR1424-1	14" x 24" x 1"	Red Label Permanent Air Filter	EA	1
AFR1425-1	14" x 25" x 1"	Red Label Permanent Air Filter	EA	1
AFR1430-1	14" x 30" x 1"	Red Label Permanent Air Filter	EA	1
AFR1520-1	15" x 20" x 1"	Red Label Permanent Air Filter	EA	1
AFR1620-1	16" x 20" x 1"	Red Label Permanent Air Filter	EA	1
AFR1624-1	16" x 24" x 1"	Red Label Permanent Air Filter	EA	1
AFR1625-1	16" x 25" x 1"	Red Label Permanent Air Filter	EA	1
AFR1818-1	18" x 18" x 1"	Red Label Permanent Air Filter	EA	1
AFR1824-1	18" x 24" x 1"	Red Label Permanent Air Filter	EA	1
AFR1825-1	18" x 25" x 1"	Red Label Permanent Air Filter	EA	1
AFR2020-1	20" x 20" x 1"	Red Label Permanent Air Filter	EA	1
AFR2024-1	20" x 24" x 1"	Red Label Permanent Air Filter	EA	1
AFR2025-1	20" x 25" x 1"	Red Label Permanent Air Filter	EA	1
AFR2030-1	20" x 30" x 1"	Red Label Permanent Air Filter	EA	1
AFR2424-1	24" x 24" x 1"	Red Label Permanent Air Filter	EA	1
AFR2525-1	25" x 25" x 1"	Red Label Permanent Air Filter	EA	1
AFR-CUSTOM-1	Custom 1"	Red Label Permanent Air Filter	EA	1
AFR-CUSTOM-2	Custom 2"	Red Label Permanent Air Filter	EA	1

2" Red Label Permanent Air Filters are available in all above sizes. Specify 2" when ordering.

### Blue Label Permanent Air Filters

- 0.08 Initial Resistance
- 73% Peak Dust Arrestance
- 67% Average Dust Arrestance
- 99 gm. Dust Holding Capacity



CATALOG NO.	1" NOMINAL SIZE	DESCRIPTION	UOM	ORDER MULTIPLE
AFB1020-1	10" x 20" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1212-1	12" x 12" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1220-1	12" x 20" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1224-1	12" x 24" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1420-1	14" x 20" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1424-1	14" x 24" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1425-1	14" x 25" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1430-1	14" x 30" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1520-1	15" x 20" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1620-1	16" x 20" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1624-1	16" x 24" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1625-1	16" x 25" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1818-1	18" x 18" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1824-1	18" x 24" x 1"	Blue Label Permanent Air Filter	EA	1
AFB1825-1	18" x 25" x 1"	Blue Label Permanent Air Filter	EA	1
AFB2020-1	20" x 20" x 1"	Blue Label Permanent Air Filter	EA	1
AFB2024-1	20" x 24" x 1"	Blue Label Permanent Air Filter	EA	1
AFB2025-1	20" x 25" x 1"	Blue Label Permanent Air Filter	EA	1
AFB2030-1	20" x 30" x 1"	Blue Label Permanent Air Filter	EA	1
AFB2424-1	24" x 24" x 1"	Blue Label Permanent Air Filter	EA	1
AFB2525-1	25" x 25" x 1"	Blue Label Permanent Air Filter	EA	1
AFB-CUSTOM-1	Custom 1"	Blue Label Permanent Air Filter	EA	1
AFB-CUSTOM-2	Custom 2"	Blue Label Permanent Air Filter	EA	1

2" Blue Label Permanent Air Filters are available in all above sizes. Specify 2" when ordering.

#### LIMITED LIFETIME WARRANTY

DiversiTech hereby guarantees to the original purchaser that this DiversiTech permanent air filter will remain free of defects in materials and workmanship, when used in accordance with the recommended guidelines, for the life of the unit on which it is installed. Should this air filter be found to be defective, the remedies of the original purchaser are expressly limited to having DiversiTech replace the filter free of charge. To obtain the replacement filter, the original purchaser must return the defective filter to DiversiTech, 2175 East Park Drive, Conyers, GA 30013, with postage charges prepaid. The warranty does not include the cost of installing the DiversiTech permanent air filter or any other costs, all of which shall be borne by the original purchaser. This warranty does not cover damage due to abuse, improper installation, installation in other than standard residential air conditioning and/or heating units, cleaning by high pressure hose or sprays or by use of highly caustic or corrosive cleaning agents. DiversiTech makes no other warranty whatsoever and all other warranties of merchantability and fitness whether expressed or implied are limited to the life of the original air conditioning or heating unit on which the DiversiTech permanent air filter is installed.

## DRYER DUCT, VENT HOSE, HOSE CLAMPS

### Louvered Dryer Vent Hood

Louvered vent hoods are available with aluminum pipe and collar or hood only. Ideal for dryer and bathroom fan exhausts.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-014	4" Hood Only – White	EA	12
650-015	4" Hood Only w/Bird Guard – White	EA	12
650-016	4" Hood, Pipe and Collar – White (Assembled)	EA	12
650-017	4" Hood, Pipe and Collar – White (Unassembled)	EA	18
650-036	3" Hood, Pipe and Collar – White (Assembled)	EA	12

### Plastic Wide Mouth Dryer Vent Hood

Hood, aluminum pipe and collar.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-031	3" White Hood – Assembled	EA	12
650-012	4" White Hood – Assembled	EA	12
650-013	4" White Hood – Unassembled	EA	18
650-023	4" Brown Hood – Assembled	EA	12

**DRYER DUCT, VENT HOSE, HOSE CLAMPS cont'd**

**Metallic Duct – 5 Ply**

Pure aluminum 5 ply multi-layered flexible metallic duct. U.L. 181 Listed. Will “contain” a fire up to 265°F.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
FUL0425	4" x 25' 5 Ply Metallic Duct	EA	4
FUL0625	6" x 25' 5 Ply Metallic Duct	EA	4

**Metallic Duct – 2 Ply**

2 ply metallic duct – aluminum outside, polyester inside. Ideal for bath fan ducting and all purpose venting.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
FM0450	4" x 50' 2 Ply Metallic Duct	EA	1

**Semi-Rigid Aluminum Duct**

8' length compressed to 28".



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-011	4" x 8' Flexible Aluminum Duct	EA	9
650-021	3" x 8' Flexible Aluminum Duct	EA	14
650-074	6" x 8' Flexible Aluminum Duct	EA	3

**Periscope Connection Kit**

For tight space duct venting. Contains one male snap-lock fitting and one draw-band with clamp. Adjustable 17" to 28".



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-020	4" Periscope Kit	EA	9

**Dryer Vent Hose**

High quality flexible white vinyl tubing. Available in 3" or 4" diameters. One 50' roll per box.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-005	Dryer Vent Hose – 3" x 50'	EA	1
650-006	Dryer Vent Hose – 4" x 50'	EA	1

**Dryer Hose Clamps**

Available for 3" or 4" dryer vent hose. Steel screw design or convenient spring action design.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-008	Steel Screw Clamp for 4" Hose	EA	50
650-010	Spring Clamp for 4" Hose	EA	500

**Aluminum Dryer Vent Hoods, Kits, and Fittings**

Aluminum vent hood with flange plate. Kits include flexible vinyl tubing and two clamps.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-001	4" Aluminum Hood	EA	12
650-002	3" Aluminum Hood	EA	12
650-003	4" Hood / 8' Tubing	EA	1
650-004	4" Hood / 5' Tubing	EA	1
650-018	4" 90° Elbow	EA	12
650-038	4" Aluminum Wide Mouth	EA	10

**VENTILATION PRODUCTS**

**Versa Cap® Flue and Hot Stack Caps**

Non-clogging positive draft design, recommended for flue or hot stack installation. Clamp fitting adjustable for all standard sizes. Aluminum model. U.L. Listed.

CATALOG NO.	PIPE O.D.	DOUBLE WALL	SINGLE WALL	J-M TRANS. SITE	HEIGHT/OVERALL DIAMETER	UOM	ORDER MULTIPLE
6-3050	2-7/8"-5"	3 and 4	3 and 4	3 and 4	4-1/2" x 6-5/8"	EA	12
6-5070	4-7/8"-7"	5 and 6	5 and 6	5 and 6	4-3/4" x 9-1/2"	EA	12
6-7090	6-7/8"-9"	7 and 8	7 and 8	7 and 8	5-7/8" x 11-5/8"	EA	12
6-9011	8-7/8"-11"	9 and 10	9 and 10	9 and 10	6-1/2" x 12-3/4"	EA	6
6-1200	11-7/8"-14-1/2"	12	12 and 14	12	8-11/16" x 17-9/16"	EA	2



### Flue Caps

PVC Flue Caps are an affordable way to protect today's high efficiency furnaces from dirt, moisture and other debris.

- Protection for high efficiency furnaces
- Universal flue cap fits 1.5", 2" and 3" PVC pipe
- Reduces draft inducer motor rust
- Helps to eliminate pressure switch service calls
- Resistant to UV radiation and oxidative degradation
- CSA approved for use in 90% AFUE heating applications



EC-1

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
EC-1	E cap Flue Cap	EA	12

### Smokeys

Smoke emitter cartridges provide effective, low cost leak testing of heat exchangers, air ducts, tanks and boilers. Visual air balancing of HVAC systems. Cartridges produce clean, non-toxic, oil-free smoke through chemical reaction. Use also for fire drills as well as the placement and testing of smoke alarms/detectors.



14175

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
14145	45 second burn time, 150 cu. ft., pack of 10	PK	1
14175	75 second burn time, 600 cu. ft., pack of 10	PK	1
14250	2-1/2 minute burn time, 1,100 cu. ft., pack of 5	PK	1
14340	4 minute burn time, 2,500 cu. ft., pack of 5	PK	1
14460	8 minute burn time, 18,000 cu. ft.	EA	1

### Roof Flashing

Easy to install. The no-caulk flashing slips over vent stack and automatically adjusts to pipe size and roof angle. 24 gauge galvanized steel.



5-11830



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
5-11830	Roof Flashing - 1/2" - 3/4" - 1"	EA	12
5-11840	Roof Flashing - 1-1/4" - 1-1/2"	EA	12
5-11853	Roof Flashing - 2"	EA	12
5-11866	Roof Flashing - 3"	EA	12
5-11879	Roof Flashing - 4"	EA	12

## DUCT STRAP, TIES, CLAMPS

### Cable Tie Holder

Finally an easier way to hold 24" to 48" cable ties. Easy to carry across your back or around your waist.



CTH-1

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
CTH-1	Cable Tie Holder	EA	1


### Duct Fans

- Features electrical junction box for UL and code compliant electrical connection.

An efficient way to increase air circulation, keep room temperatures consistent, and lower heating and cooling costs. Metal construction, powerful no-maintenance motors and a one-use thermal fuse mean these fans will be up to the task for years. Straightforward installation into any 120V system with detailed instructions, templates, and diagrams. Available in many sizes. A great way to give slow vents a boost. Conforms to UL STD 507, Certified to CSA STD C22.2 #113



625-AF6

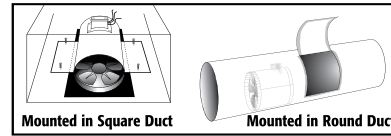

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
625-AF6	Duct Fan 6" dia., 240 CFM, 37W	EA	1
625-AF8	Duct Fan 8" dia., 420 CFM, 37W	EA	1
625-AF10	Duct Fan 10" dia., 650 CFM, 35W	EA	1
625-AF12	Duct Fan 12" dia., 975 CFM, 65W	EA	1
625-AF14	Duct Fan 14" dia., 1350 CFM, 65W	EA	1

### Roof Louver

Unique interior louver design, eliminating the need for a screen. The square hood has been designed for maximum air movement. Large nailing flange for easy installation. U.L. Listed.




6-R50A



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
6-R50A	Roof Louver - Aluminum	EA	10

### Egg Crate Louvers - Air Return Diffusers

White polystyrene 1/2" open cell grid.

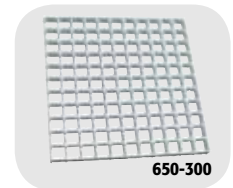

650-300

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
650-300	Egg Crate Louvers - 2' x 2' x 1/2"	EA	20
650-200	Egg Crate Louvers - 2' x 4' x 3/8"	EA	15
650-100	Egg Crate Louvers - 2' x 4' x 1/2"	EA	10

### Heavy Duty Cable Ties

6.6 nylon, the heavy duty duct straps feature smooth insertion, and a locking mechanism that gives ductwork a firm hold. Accommodates 7 to 15 inch duct. Tensioning tool for 32"+ allows operator to adjust strap to any desired tension.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
<b>7-P24</b>	24" Long - Fits up to 6" Duct - 175 lb. Tensile	EA	50
<b>7-P36</b>	36" Long - Fits up to 10" Duct - 175 lb. Tensile	EA	50
<b>7-P36B</b>	36" Long - Black - Fits up to 10" Duct - 175 lb. Tensile	EA	50
<b>7-P48</b>	48" Long - Fits up to 14" Duct - 175 lb. Tensile	EA	50
<b>7-P48B</b>	48" Long - Black - Fits up to 14" Duct - 175 lb. Tensile	EA	50
<b>7-L300</b>	Tensioning Tool for 120-175 lb. Ties	EA	1

### Duct Strap - Woven Polypropylene

Webbed duct strap possessing high tensile and abrasion resistance. Chemical resistant. Use for flex duct - easy to cut and staple to joists. U.L. Listed to spec 2043.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
<b>710-100</b>	Duct Strap - 1-3/4" x 100 Yards - Black	EA	24
<b>NEW 710-100LA</b>	Duct Strap - 1-3/4" x 100 yards - Black - City of L.A. Approved	EA	24
<b>710-101</b>	Duct Strap - 1-3/4" x 100 Yards - Silver	EA	24
<b>710-102</b>	Duct Strap - 3" x 100 Yards - Black	EA	8
<b>710-103</b>	Duct Strap - 3" x 100 Yards - Silver	EA	8

### Strapping Hanger Iron

Galvanized 3/4" vent strapping, hanger iron, plumber's tape, pipe hanger tape and many other uses. 1/4" centers for bolts or nails.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
<b>710-A1710</b>	Hanger Iron (Galv.) - 10' Rolls - 28 Gauge	EA	50
<b>710-A1650</b>	Hanger Iron (Galv.) - 50' Rolls - 28 Gauge	EA	10
<b>710-A16100</b>	Hanger Iron (Galv.) - 100' Rolls - 28 Gauge	EA	6

### Duct Strap - Metallic - Roll

Galvanized duct strap in convenient cardboard dispenser. Solid strapping, easy to drill or nail.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
<b>710-001</b>	Metallic Duct Strap - 26 Gauge - 1" x 100'	EA	1
<b>710-002</b>	Metallic Duct Strap - 30 Gauge - 1" x 100'	EA	1
<b>710-003</b>	Metallic Duct Strap - 30 Gauge - 1-1/2" x 100'	EA	1
<b>710-004</b>	Metallic Duct Strap - 26 Gauge - 1-1/2" x 100'	EA	1
<b>710-005</b>	Metallic Duct Strap - 22 Gauge - 1" x 100'	EA	1

### Hanging Wire

18 gauge galvanized on reel.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
<b>710-182G</b>	2# Roll - 330' - 18 Gauge Galvanized	EA	16
<b>710-185G</b>	5# Roll - 830' - 18 Gauge Galvanized	EA	16

## TAPES

### Stick-E-Tape

Self-adhesive aluminum tape with temperature range of -40°F to 200°F. Easily painted. Excellent vapor barrier; effective UV and water shield over urethane foam. Preferred duct and pipe wrap.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
<b>50302</b>	Stick-E-Tape - AFT-701-2 - 2" x 50' Roll	EA	24
<b>50304</b>	Stick-E-Tape - AFT-701-4 - 4" x 50' Roll	EA	12
<b>50306</b>	Stick-E-Tape - AFT-701-6 - 6" x 50' Roll	EA	8

### Aluminum Foil Tape

Prevents heating and cooling losses. Blocks odors and moisture. Easy to handle. Use for HVAC and refrigeration systems. -35°F to +260°F working temperatures. 3-5 year shelf life. Made in USA.



CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
<b>640-AF2</b>	2" Aluminum Foil Tape - 50 yds.	EA	24
<b>640-AF25</b>	2-1/2" Aluminum Foil Tape - 50 yds.	EA	20
<b>640-AF3</b>	3" Aluminum Foil Tape - 50 yds.	EA	16

### Foil Scrim Kraft Tape

Non-tearable, diamond patterned backing with an aggressive rubber based adhesive system for consistently dependable performance. Made in the USA.



640-FSK2

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
640-FSK2	Foil Scrim Kraft Tape – 2" – 50 Yards	EA	24
640-FSK3	Foil Scrim Kraft Tape – 3" – 50 Yards	EA	16

### Flex Duct Tape

Specially designed to meet new UL181B-FX code for flex duct. Higher adhesion and tack than traditional cloth duct tapes. Conformable, hand tearable foil; 3 mil thickness. 2" x 120 yds. Code identification printed on the tape. Acrylic adhesive for superior performance in extreme environments. (-35°F to 260°F)



640-FD2S

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
640-FD2S	Flex Duct Tape – Silver – 2"	EA	24
640-FD2B	Flex Duct Tape – Black – 2"	EA	24
640-FD3S	Flex Duct Tape – Silver – 3"	EA	16
640-FD3B	Flex Duct Tape – Black – 3"	EA	16

### UL Listed Foil Tape

Unique acrylic adhesive for airtight bonds on joints and seams of fiberglass duct systems. Flexible, easy to use. Meets or exceeds performance standard AFLS-100-73 and UL 181 A-P.



640-UL25

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
640-UL25	UL 181 Listed Foil Tape – 2-1/2" – 60 Yards	EA	16
640-UL3	UL 181 Listed Foil Tape – 3" – 60 Yards	EA	16

### Cloth Duct Tapes

High-tack, excellent strength. Superior performance in sealing air handling systems. Heavy cloth content for easier tearing and additional strength. Made in the USA.



PC-622-S

PC-622-B

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
PC-622-S	2" x 60 Yards – Premium Grade Duct Tape – Silver	EA	24
PC-622-B	2" x 60 Yards – Premium Grade Duct Tape – Black	EA	24
PC-609-S	2" x 60 Yards – Industrial Grade Duct Tape – Silver	EA	24
PC-609-B	2" x 60 Yards – Industrial Grade Duct Tape – Black	EA	24
PC-600-S	2" x 60 Yards – Contractor Grade Duct Tape – Silver	EA	24
PC-600-B	2" x 60 Yards – Contractor Grade Duct Tape – Black	EA	24
PC-783	2" x 60 Yards – Metallized UL181B-FX Flex Duct Tape	EA	24

## ULTRAVIOLET LIGHT

### Pure-Beam™ Ultraviolet Light

Pure-Beam™ ultraviolet light is designed for HVAC air disinfection and surface irradiation. The 17 watt UV-C lamp is a powerful tool for improved indoor air quality. Installs in the HVAC system or ductwork on either the return or supply air side of the furnace or air handler. DiversiTech's Pure-Beam™ ultraviolet light provides a healthier environment in your home, thanks to the germicidal qualities of the UV light spectrum present in the Pure-Beam™ light. Ultraviolet light deactivates the DNA of dust mites, bacteria, viruses and other pathogens and destroys their ability to multiply and cause disease. Placement of a Pure-Beam™ light in an airstream or near a drain pan can help to decrease the air contamination of any home.

Exposure to Pure-Beam™ significantly reduces air contamination caused by fungus, mold, and viruses and can cleanse surfaces overcome by mold and slime. Overall size is 14" L x 2" W x 2" H for easy placement. Includes the UV lamp, a UL listed ceramic base, and mounting bracket.



UV-1



UV-BULB

CATALOG NO.	DESCRIPTION	UOM	ORDER MULTIPLE
UV-1	Ultraviolet Light with 24 VAC elec. ballast	EA	1
NEW UV-BULB	Replacement Bulb – 24V	EA	1



Literature – Download all literature from the DiversiTech website using the Form ID shown in the icon. The URL is [www.diversitech.com/literature/FORMID.pdf](http://www.diversitech.com/literature/FORMID.pdf)