

# ARM Control Expandable Zone Relays

2, 3, 4 and 6 Zone Controls



## SWITCHING RELAYS & ACCESSORIES

### ARM4P



MODEL	ZONES	TRANSFORMER VOLTAGE
ARM2P	2	120 VAC, 60 Hz, 20 VA
ARM3P	3	120 VAC, 60 Hz, 30 VA
ARM4P	4	120 VAC, 60 Hz, 30 VA
ARM6P	6	120 VAC, 60 Hz, 30 VA

### Features:

Priority Safety Timer - Ensures Other Zones Get Heat Every 30 Minutes & Prevents Freeze-ups

5-second Time Delay for Boiler Shut-off

Premium plug-in replaceable relays

Electronic Fuse - Auto Reset

30VA Transformer\*† - Robust Enough to Handle up to 15 Zones

24 VAC Transformer Terminals

Plug-in, Add-on Zone Modules (AD-1 or AD-4)

Double-sided printed circuit board construction - 100% Factory Tested For Reliability

Switchable Priority

High relay load rating - 7.2 Amp / 1/3HP

CSA listed

Separate xx (isolated switch) & ZC/ZR Relays protect Boiler Aquastat.

Relay Diagnostic Light - Easily Seen Through Window On Cover

Clearly marked Terminals With Clamping Plates

\* ARM-2P uses 20 VA Transformer. † Requires dry contact type thermostat or use of IR822 Isolation Relay

### AD-4 Add-On Zoning Modules For ARM Relay Control




### SPECIFICATIONS:

MODEL	ZONES	TRANSFORMER VOLTAGE	SWITCHING ACTION	THERMOSTAT CURRENT	SINGLE PHASE MOTOR RATING 120V AC
AD-1	1	N/A	0.085	SPST	1/3HP
AD-4	4	N/A	0.085	SPST	1/3HP

### DPM2 Outdoor Reset Control

The DPM2 monitors outside temperature and adjusts boiler water temperature to match the outdoor demand – maximizing efficiency and reducing fuel usage.

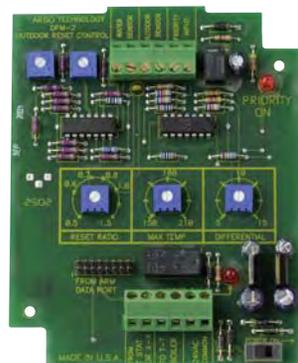

- Can be used with any Argo Relay or Zone Value Control
- Or can work with most competitors' relays
- Reduces heating costs an average of 10% to 15% a year (depending on climate).

### Standard Equipment:

