


BOSHART INDUSTRIES

Telephone: 1-519-595-4444 - Toll Free: 1-800-561-3164

Fax: 1-519-595-4380 - www.boshart.com


TRIDICATORS - 2 1/2" DIAL - 1/4" CBM

- Black Steel Case
- Brass Connection
- Acrylic Window
- Accuracy: Pressure: $\pm 3-2-3\%$ Temperature: $\pm 2\%$
- Bourdon Tube
- BiMetal Element

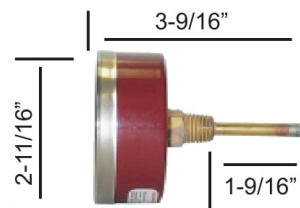

PART NO.	TEMPERATURE RANGE	INCREMENTS	PRESSURE RANGE	INCREMENTS	LIST PRICE-A
TR25-CB1-60/250	30-250 °F 0-120 °C	5 2	0-75 PSI 0-500 kPa	2 20	16.49



- Black Steel Case
- Brass Connection
- Acrylic Window
- Accuracy: Pressure: $\pm 3-2-3\%$ Temperature: $\pm 2\%$
- Bourdon Tube
- BiMetal Element

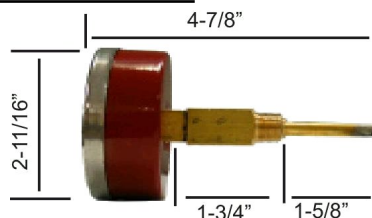

PART NO.	TEMPERATURE RANGE	INCREMENTS	PRESSURE RANGE	INCREMENTS	LIST PRICE-A
TR25X1-CB1-60/250	30-250 °F 0-120 °C	5 2	0-75 PSI 0-500 kPa	1 10	19.02

TRIDICATORS - 3" DIAL - 1/2" CBM

- 3" Dial general purpose industrial combination pressure gauge/thermometer
- Black steel case with acrylic window
- 1/2" MPT brass center back mount connection
- Bourdon tube and coiled bi-metal element
- Dual scale degree F and degree C
Range: 30 - 250°F - 5 degree increments
Range: 0 - 120°C - 2 degree increments
- Dual scale PSI & kPa increments
Range: 0 - 75 psi - 1 psi increments
Range: 0 - 500 kPa - 10 kPa increments
- Accuracy: Pressure: $\pm 3-2-3\%$ Temperature: $\pm 2\%$

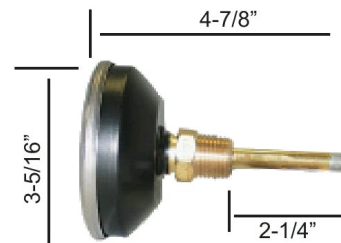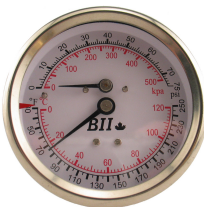


PART NO.	TEMPERATURE RANGE	INCREMENTS	PRESSURE RANGE	INCREMENTS	OVERALL LENGTH	PROBE LENGTH	LIST PRICE-A
TR30-CB2-60/250	30-250 °F 0-120 °C	5 2	0-75 PSI 0-500 kPa	1 10	4-7/8"	2-1/4"	19.87

• Short Probe							
TR30-CB2S-60/250	30-250 °F 0-120 °C	5 2	0-75 PSI 0-500 kPa	1 10	3-3/16"	11/16"	19.87



TRIDICATORS - 3" DIAL - 1/2" LM

- Black Steel Case
- Brass Connection
- Acrylic Window
- Accuracy: Pressure: $\pm 3-2-3\%$ Temperature: $\pm 2\%$
- Bourdon Tube
- BiMetal Element

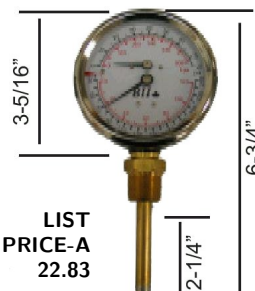

PART NO.	TEMPERATURE RANGE	INCREMENTS	PRESSURE RANGE	INCREMENTS	LIST PRICE-A
TR30-LM2-60/250	30-250 °F 0-120 °C	5 2	0-75 PSI 0-500 kPa	1 10	22.83