




## XII. REPAIR PARTS (continued)

Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>1. CASTING ASSEMBLY</b>								
1	Section Assembly	61707031	61707041	61707051	61707061	61707071	61707081	61707091
1A	Left End Section	71707001						
1B	Center Section	[1] 71707003	[2] 71707003	[3] 71707003	[4] 71707003	[6] 71707003	[6] 71707003	[7] 71707003
1C	Right End Section	71707002						
1D	Slip Nipple, #3	[4] 806600009	[6] 806600009	[8] 806600009	[10] 806600009	[12] 806600009	[14] 806600009	[16] 806600009
1E	Flue Gas Baffle	[2] 71107002	[3] 71107002	[4] 71107002	[5] 71107002	[6] 71107002	[7] 71107002	[8] 71107002
1F	Tie Rod, 1/4" -20	[2] 100109-01	[2] 100108-05	[2] 100108-07	[2] 100108-13	[2] 100108-14	[2] 100108-15	[2] 100108-16
1G	Hex Nut, 1/4" -20	[4] 80860407						


## XII. REPAIR PARTS (continued)

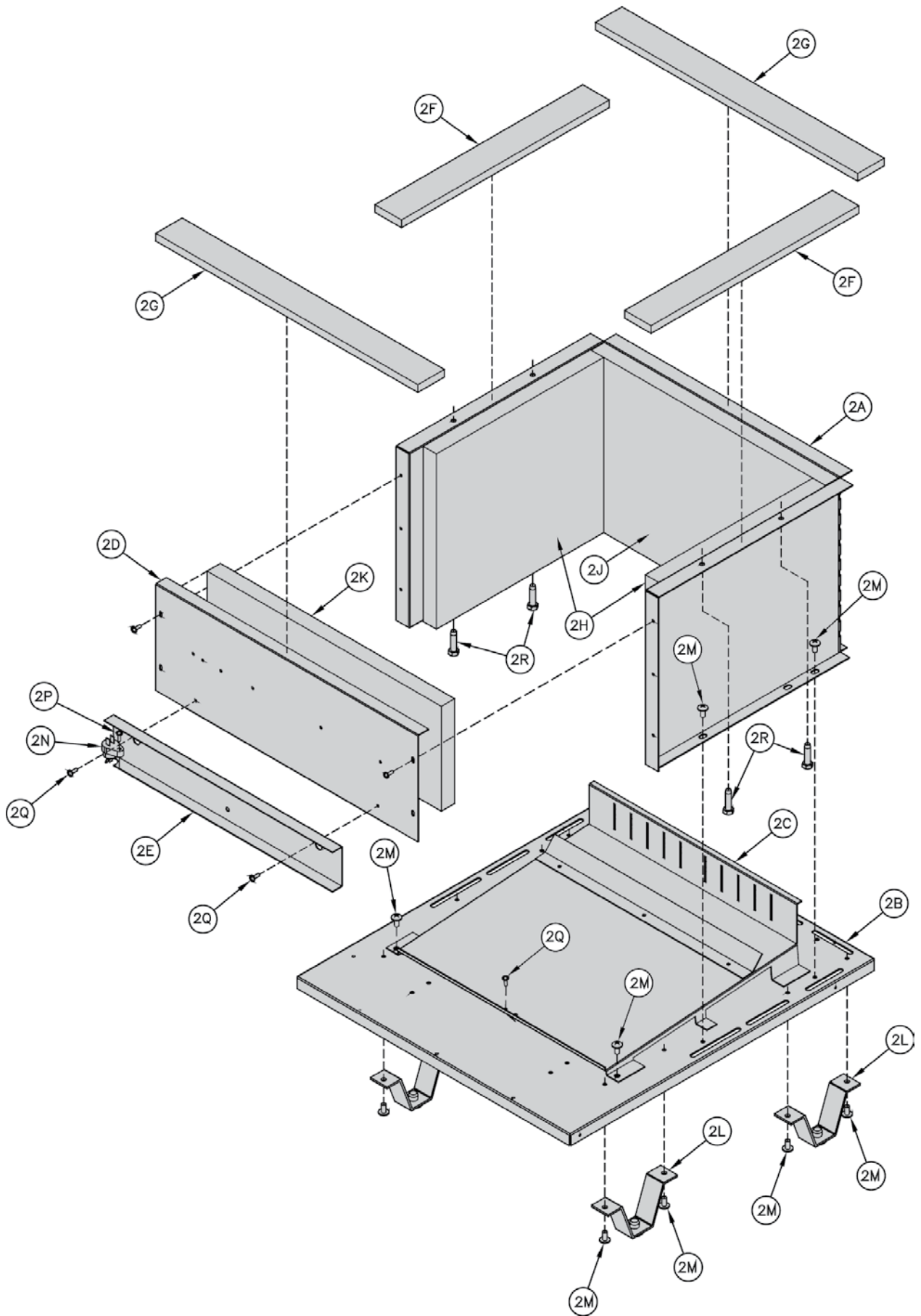

## XII. REPAIR PARTS (continued)


Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>2. BASE ASSEMBLY</b>								
2A	Base Wrapper	71807031	71807041	71807051	71807061	71807071	71807081	71807091
2B	Base Tray	71807032	71807042	71807052	71807062	71807072	71807082	71807092
2C	Burner Tray Assembly	61807031	61807041	61807051	61807061	61807071	61807081	61807091
2D	Base Front Panel	102705-03	102705-04	102705-05	102705-06	102705-07	102705-08	102705-09
2E	Burner Access Panel	102707-03	102707-04	102707-05	102707-06	102707-07	102707-08	102707-09
2F	Cerafelt Gasket 1/2" x 2"	6206002						
2G	Cerafelt Gasket 1/2" x 2"	6206002						
2H	Base Side Insulation	[2] 72007001						
2J	Base Rear Insulation	72007031	72007041	72007051	72007061	72007071	72007081	72007091
2K	Base Front Insulation	72007032	72007042	72007052	72007062	72007072	72007082	72007092
2L	Base Leg Assembly	[4] 6186001						
2M	Self Tapping Screw, 1/4" -20 x 1/2"	[18] 80860700						
2N	Flame Roll-out Switch	80160044						
2P	Sheet Metal Screw, #8 x 3/4"	80860030						
2Q	Self Tapping Screw, 10-32 x 3/8"	[5] 80860705		[6] 80860705			[7] 80860705	
2R	Self Tapping Screw Hex Cap, 5/16 - 18 x 1-1/4"	[4] 80860717						

## XII. REPAIR PARTS (continued)

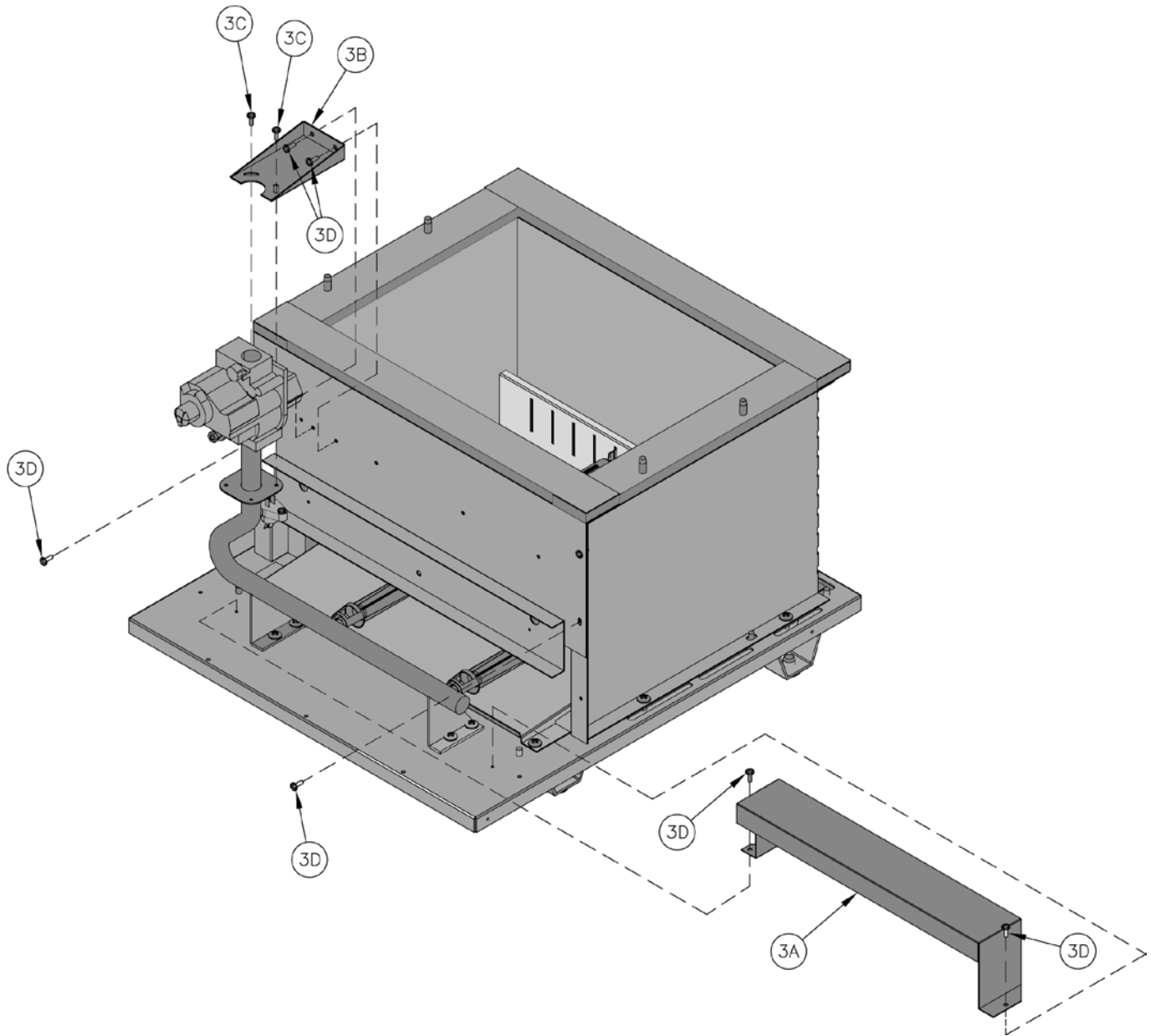


Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>3. BASE ASSEMBLY</b>								
3A	Burner Cover (Natural Gas Only)	102033-03	102033-04	102033-05	102033-06	102033-07	102033-08	102033-09
3B	Manifold Support Bracket	718070001						
3C	Sheet Metal Screw, #8 x 1/2"	[2] 80860000						
3D	Self Tapping Screw, 10-32 x 3/8"	[6] 80860705						

## XII. REPAIR PARTS (continued)

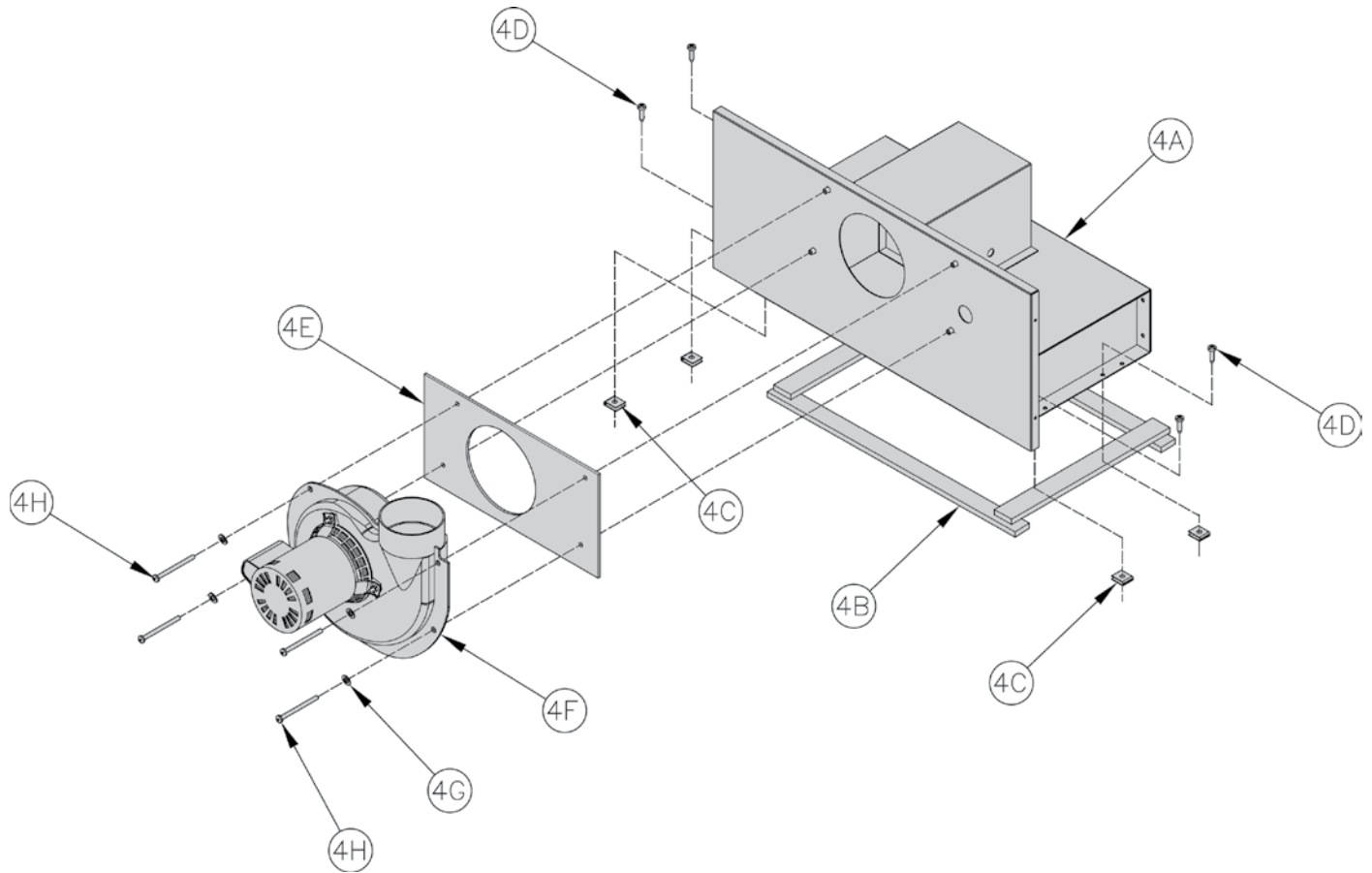

Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>4. FAN/CANOPY ASSEMBLY</b>								
4A	Canopy Assembly - Sea Level	61107031	61107041	61107051	61107061	61107071	61107081	61107091
	Canopy Assembly - High Altitude	61107032	61107042	61107052	61107062	61107072	61107082	61107092
4B	Cerafelt	9206005						
4C	U-Clip	[4] 80861512						
4D	Sheet Metal Screw, #10 x 1"	[4] 808600141						
4E	Fan Gasket	8206085						
4F	Fan	81161512						
4G	Lock Washer, #10	[4] 80860636						
4H	Machine Screw, #10-24 x 2-1/2"	[4] 808608982						

6 XII. REPAIR PARTS (continued)

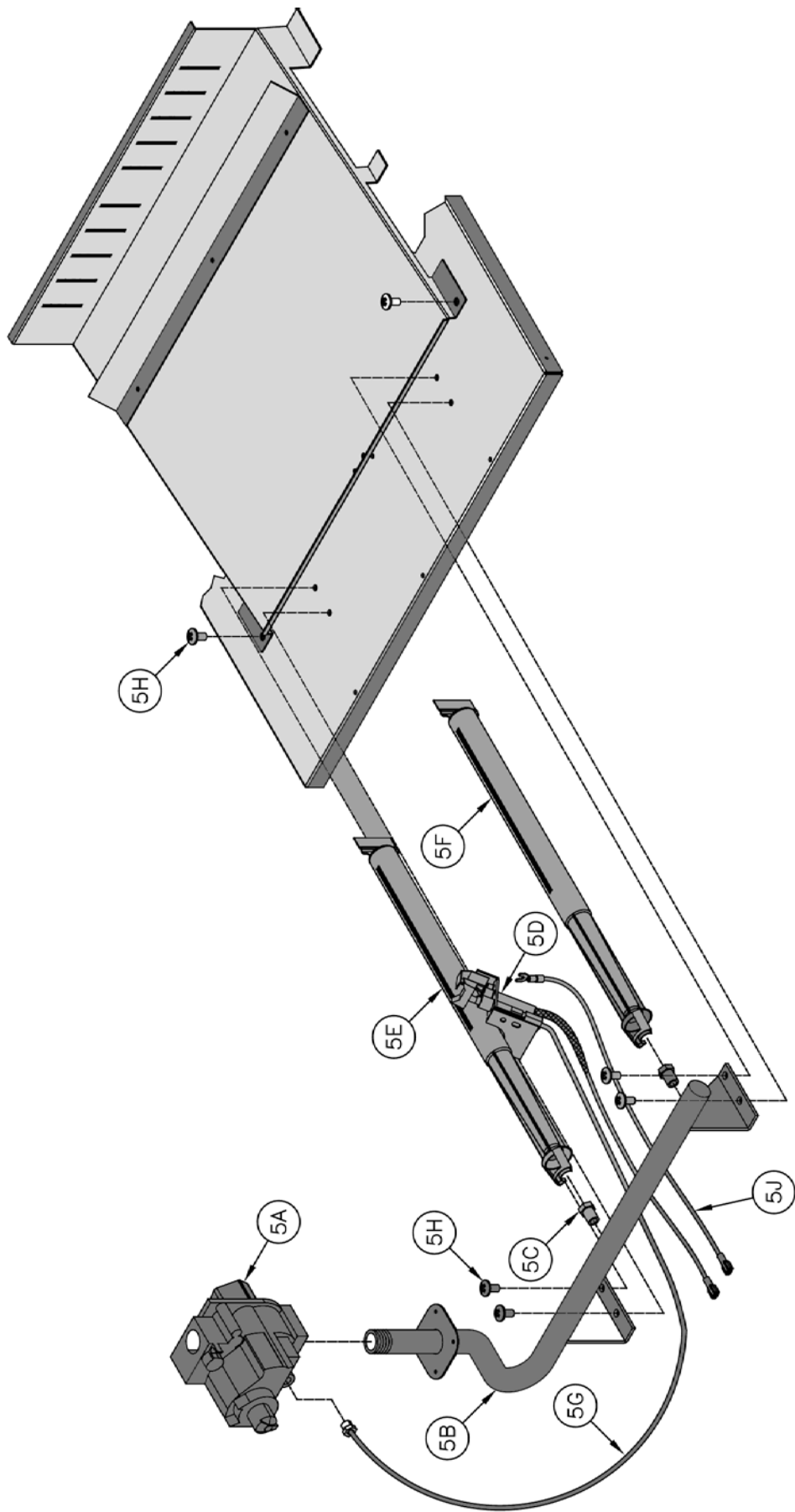


## XII. REPAIR PARTS (continued)

Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>5. BURNER ASSEMBLY</b>								
5A	Gas Valve (Natural Gas), Honeywell VR8204P1171	81660282				N/A		
	Gas Valve (Natural Gas), Honeywell VR8304P4496	N/A				81660283		
	Gas Valve (LP Gas), Honeywell VR8204C3015	81660146				N/A		
	Gas Valve (LP Gas), Honeywell VR8304P4280	N/A				81660181		
5B	½" Gas Manifold	82207031	82207041	82207051	82207061	---	---	---
	¾" Gas Manifold	---	---	---	---	82207071	82207081	82207091
5C	Burner Orifices - Natural Gas #47	[4] 822710	[6] 822710	[8] 822710	[10] 822710	[12] 822710	[14] 822710	[16] 822710
	Burner Orifices - LP Gas #56	[4] 822707	[6] 822707	[8] 822707	[10] 822707	[12] 822707	[14] 822707	[16] 822707
5D	Pilot Assembly - Natural Gas	103704-01						
	Pilot Assembly - LP Gas	103705-01						
5E	Burner w/ Pilot Bracket	100147-01						
5F	Main Burner	[3] 100146-01	[5] 100146-01	[7] 100146-01	[9] 100146-01	[11] 100146-01	[13] 100146-01	[15] 100146-01
5G	Pilot Tubing	8236122						
5H	Self Tapping Screw, ¼ - 20 x ½"	[6] 80860700						
5J	Ground Wire Assembly	103776-01						




## XII. REPAIR PARTS (continued)

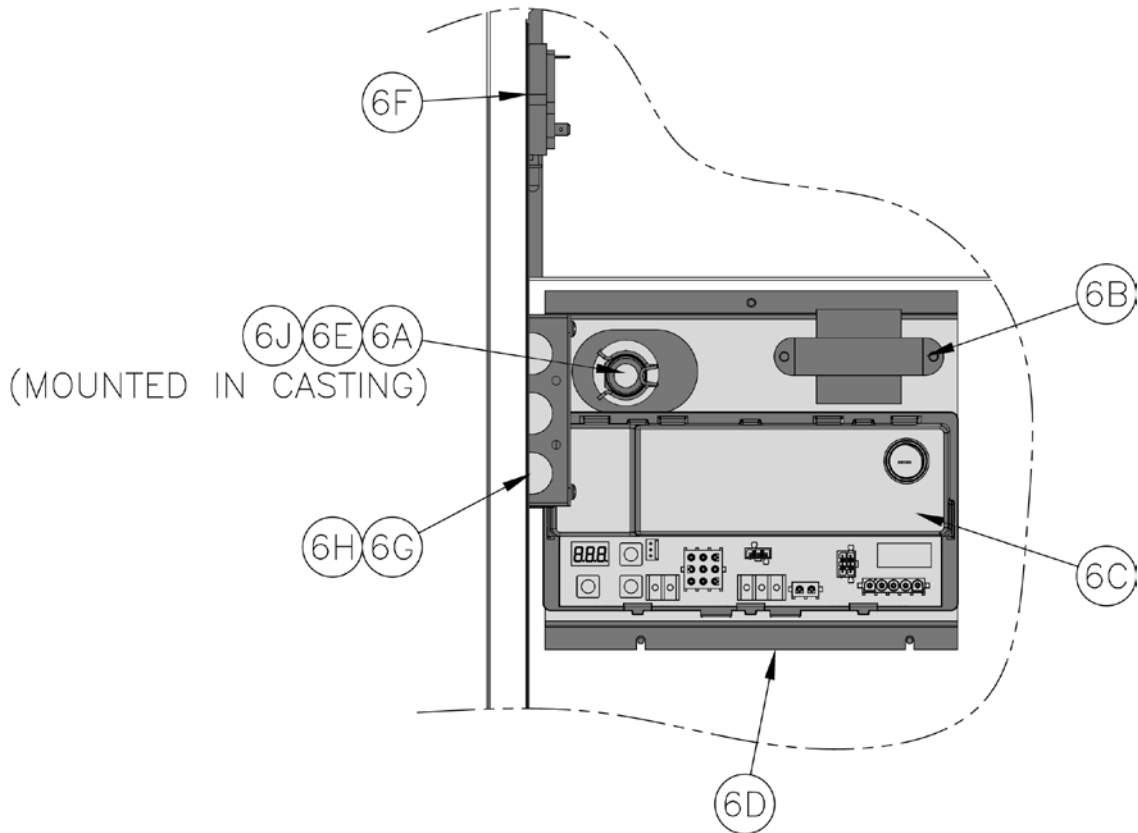


Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>6. CONTROL PANEL ASSEMBLY</b>								
6A	Limit Rated Temperature Sensor, 12", Honeywell 50001464-001	103195-01						
6B	Transformer, Honeywell AT140B1297	102516-01						
6C	Boiler Control, Induced Draft, Honeywell S9361A2075	103661-01						
6D	Control Panel	103727-01						
6E	Temperature Sensor Clip	102422-01						
6F	Differential Pressure Switch Sea Level 0' - 4,999' (Natural Gas)	80160762	80160761	104576-01	104575-01	104730-01		
	Differential Pressure Switch Sea Level 0' - 4,999' (LP Gas)			80160761	80160760	80160759	80160760	
	Differential Pressure Switch High Altitude 4,999' - 10,000' (Natural Gas)	104804-01		80160959	104804-01			
	Differential Pressure Switch High Altitude 4,999' - 10,000' (LP Gas)	104804-01			104802-01			
6G	Junction Box 4" x 4" x 1½"	8136259						
6H	Junction Box Cover	8136180						
6J	½" Immersion Well, Honeywell 123869A	80160456						

## XII. REPAIR PARTS (continued)

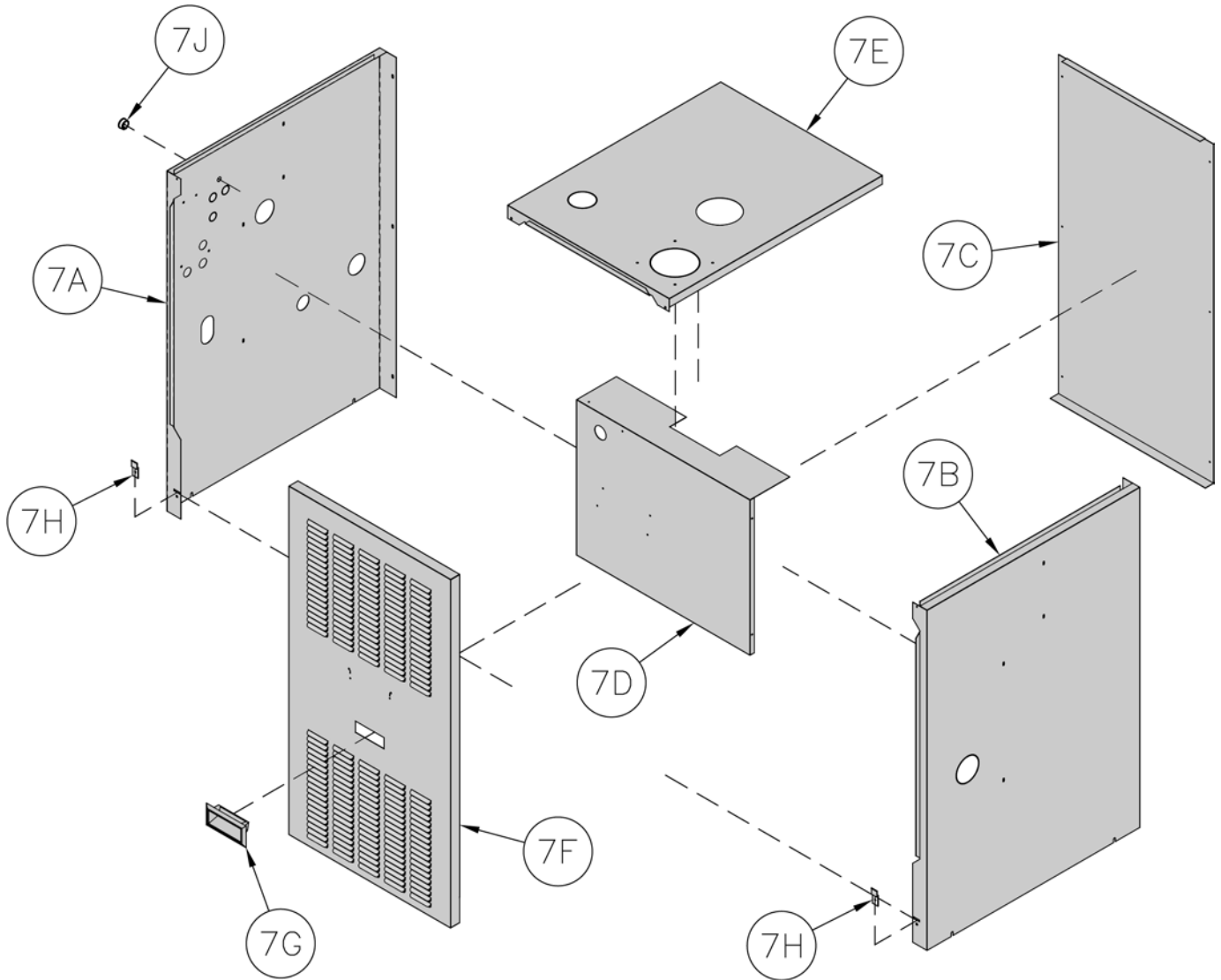

Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>7. JACKET PARTS</b>								
7A	Left Side Panel	60407002						
7B	Right Side Panel	60407001						
7C	Rear Panel	60407033	60407043	60407053	60407063	60407073	60407083	60407093
7D	Vestibule Panel	60407034	60407044	60407054	60407064	60407074	60407084	60407094
7E	Top Panel	60407032	60407042	60407052	60407062	60407072	60407082	60407092
7F	Front Door	104148-03	104148-04	104148-05	104148-06	104148-07	104148-08	104148-09
7G	Handle	8056184						
7H	Door Clip	[2] 7041921						
7J	Bushing	8136048						

## XII. REPAIR PARTS (continued)

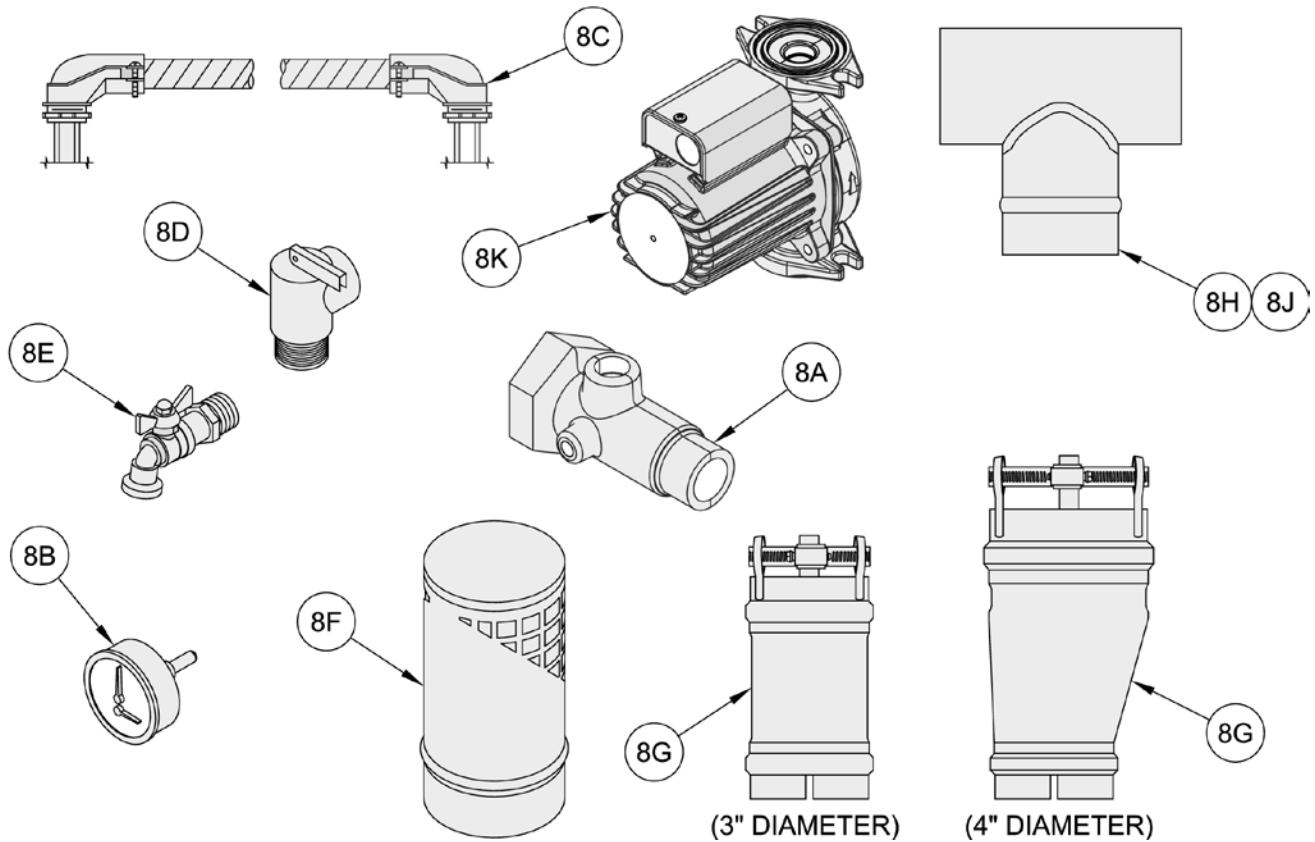

Key No.	Description	[Quantity] Part Number						
		PVG3	PVG4	PVG5	PVG6	PVG7	PVG8	PVG9
<b>8. MISCELLANEOUS PARTS CARTON</b>								
8A	Water Manifold							80607001
8B	Temperature/Pressure Gauge							100282-01
8C	Circulator Wiring Harness							6130701
8D	Safety Relief Valve							81660363
8E	Boiler Drain Valve							806603061
8F	Vent Terminal		8110701					N/A
8G	Vent Connector			8110703				8110704
8H	Vent Tee AL294C, 3"			N/A			8116310	N/A
8J	Vent Tee AL294C, 4"							8116313
8K	Taco 007							8056170
	Grundfos UPS15-58FC Kit							102805-02
	Grundfos Alpha Circulator							104935-01
	Bell & Gosset NRF-22 Circulator and Gaskets Kit							8056174