



RESIDENTIAL AND COMMERCIAL REPLACEMENT PARTS LIST

CF-32, CF-50 and CF-70 Gallon Oil Fired Models




Includes Hydrojet®
Total Performance System

***Effective: APRIL, 2011
ECO 7624***

NOTE: BOTH MODEL AND SERIAL
NUMBERS ARE REQUIRED FOR
ORDERING REPLACEMENT PARTS

Dimensions and specifications
subject to change without notice.

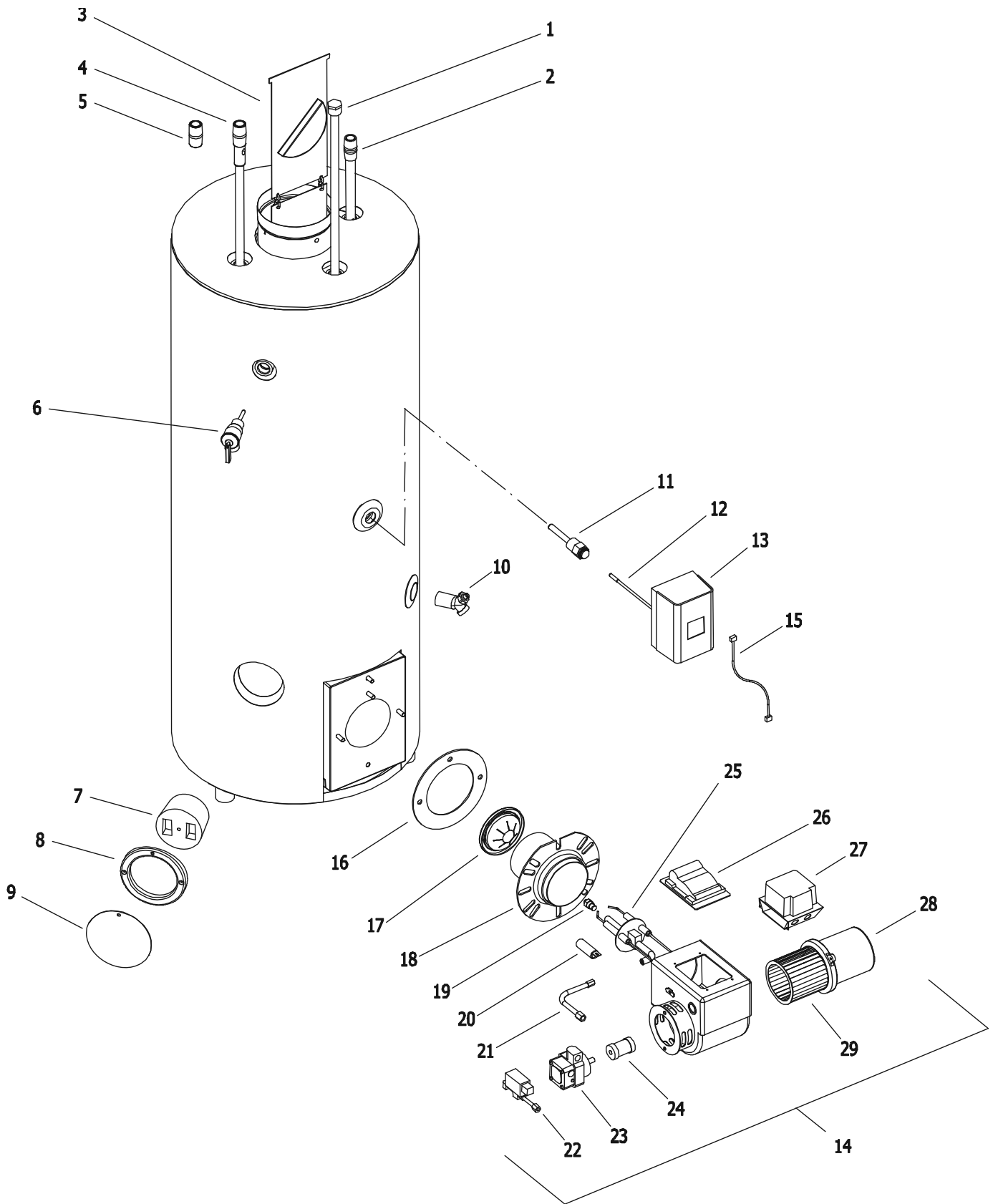

Item	Part Description	Model CF-32-6 BW501	Model CF-50-6 BW502	Model CF-70-3 BW506
		BWC Part # Below	BWC Part # Below	BWC Part # Below
1	Plug Type Anode (Magnesium)	224-47782-03	224-47782-05	224-47782-07
	Plug Type Anode (Aluminum)	224-38508-09	224-38508-09	224-38508-07
2	Cold Water Inlet Dip Tube	229-39625-02	229-39625-05	229-44700-05
3	Flue Baffle	239-46268-00	239-46268-00	243-39974-00
4	Hot Water Outlet Anode (Magnesium)	224-47776-03	224-47776-05	---
	Hot Water Outlet Anode (Aluminum)	224-32999-27	224-32999-10	---
5	Hot Water Outlet Nipple	---	---	229-32762-18
6	T & P Relief Valve	230-32920-01	230-32920-01	230-30246-00
7	Peephole Plug	239-39687-00	239-39687-00	239-39687-00
8	Peephole Flange	239-43076-01	239-43076-01	239-43076-01
9	Peephole Cover	243-39717-00	243-39717-00	243-39717-00
10	Brass Drain Valve	265-42351-02	265-42351-02	265-42351-02
11	Thermal Immersion Well	233-46558-01	233-46558-01	233-46558-01
12	Thermister Only*	233-46553-01	233-46553-01	233-46553-01
13	Thermostat w/Thermister (electronic)*	233-46038-00	233-46038-00	233-46038-00
14	Burner Assembly Complete 120V 1/S Pump	228-44392-01	228-44392-03	228-44392-05
		Beckett Part # Below	Beckett Part # Below	Beckett Part # Below
15	Wire Harness*	51924	51924	51925
16	Burner Flange Gasket	---	---	3616
17	Burner Firing Head	360003	360003	360003
18	Air Tube w/Nozzle Line Electrode Assy**	Specify	Specify	Specify
19	Oil Nozzle	.65 x 80B Delavan	.75 x 80B Delavan	.85 x 80B Delavan
20	Cad Cell	7006Q	7006Q	7006Q
21	Copper Oil Feedline	5394	5394	5394
22	Pump Solenoid (240 volt only)	2234U	2234U	2234U
23	Oil Pump 120V (Single)	21844U	21844U	21844U
	Oil Pump 120V (Dual)	21941U	21941U	21941U
	Oil Pump 240V, 60Hz (Single)	2460U	2460U	2460U
	Oil Pump 240V, 60Hz (Dual)	2583U	2583U	2583U
24	Oil Pump Drive Coupling	2454U	2454U	2454U
25	Electrode Replacement Kit	5780	5780	5780
26	Ignition Transformer (120V)	51771U	51771U	51771U
	Ignition Transformer (240V, 60Hz)	21175U	21175U	21175U
27	Primary Control 120V	7456U	7456U	7456U
	Primary Control 240V, 60Hz	7414U	7414U	7414U
28	Blower Motor (120V)	21805U	21805U	21805U
	Blower Motor (240V, 60Hz)	21174U	21174U	21174U
29	Blower Wheel	2999U	2999U	2999U

*Provided with burner complete (item 14). Also available individually.

**Specify Oil Burner Model. Example: BW501



For U.S. and Canada field service,
contact your professional installer or
local Bradford White sales representative.

Sales/800-523-2931
Fax/215-641-1670
Parts Fax/215-641-2180

Technical Support/800-334-3393
Fax/269-795-1089

Warranty/800-531-2111
Fax/269-795-1089

International:
Telephone/215-641-9400
Telefax/215-641-9750



Sales/866-690-0961
905-238-0100

Fax/905-238-0105

Technical Support/800-334-3393

Email
parts@bradfordwhite.com
techserv@bradfordwhite.com

www.bradfordwhite.com