

PolyPro[®]



**Polypropylene venting products
for high-efficiency condensing
appliance installations.
Listed to ULC-S636.**

DuraVent
Member of  M&G Group

Specifications

Applications

PolyPro is a polypropylene vent pipe for use with ANSI Category II and IV gas-burning appliances, including high-efficiency water heaters, condensing boilers and warm air furnaces. PolyPro is listed by Intertek to the ULC S636 standard in Canada as a Class IIA, IIB and IIC vent system suitable for exhaust temperatures up to 230°F / 110°C, and a maximum positive pressure of 15 in-w.c.

Materials and Construction

Rigid pipe constructed of 2.2mm (minimum) thick polypropylene. Flex is double-wall polypropylene. EPDM or optional Viton Gaskets

Clearances

0" clearance to combustibles for exhaust temperatures up to 194°F / 90°C, and 0" clearance for vertical installations up to exhaust temperatures of 230°F / 110°C and ¼" / 6mm clearance to combustibles for horizontal installations at exhaust temperatures up to 230°F / 110°C. PolyPro concentric vent system components, including concentric Horizontal Termination and Vertical Termination, are listed at 0" clearance to combustibles for exhaust temperatures up to 230°F / 110°C.

Diameters

2" (60mm), 3" (80mm), 4" (100mm), 5" (130mm), 6" (150mm), and 8" (200mm).

Listings

Listed with the appliance in the USA and Canada, check with appliance manufacturer. Intertek / ETL listed to ULC S636 Listed as a Class IIA, IIB, and IIC vent system.

PolyPro complies with LEED® credit IEQc4.1 on VOC limits.

PolyPro is approved by the
Massachusetts Plumbers Board.
Approval code G1-0811-42.



PolyPro®

PolyPro and PVC/CPVC: PVC pipes are commonly used for venting water heaters, condensing boilers and warm air furnaces, yet PVC was never designed for such use. An engineered alternative for venting condensing gas appliances, PolyPro is 100% recyclable; contains no chlorides, or heavy metals; and is easier and faster to install than PVC, saving the contractor time and money. PolyPro does not release hazardous gases during combustion and has been used safely throughout Europe since the early 1990s. Polypropylene has a higher operating temperature limit of 230°F/110°C (PVC is 149°F/65°C max and CPVC is 194°F/90°C). PolyPro is engineered with a corrosion-free, condensation management system.

Flex

PolyPro Flex through B Vent as a Chase: Retrofit venting for new, high-efficiency appliances. When replacing a mid-efficiency appliance with a new condensing 90+ appliance, you can use the existing B vent (any brand) as a chase for the new appliance with PolyPro. The perfect solution for utilizing the B Vent already in place, use the convenient pull cone to insert double-wall PolyPro Flex through the B Vent pipe and terminate in either a two pipe or single pipe system. At the other end is the unique B Vent/PolyPro Support Cap, allowing for the connection of flex to rigid PolyPro lengths and elbows to finish the installation.

Terminations

DuraVent's concentric PolyPro vertical terminations are lab tested to handle harsh weather and remain icicle free in freezing temperatures. Air circulation and weather conditions like rain, wind and ice have the potential to reduce the efficiency of a unit's performance and the operation of its venting system.



Commercial & OEM Product Development

M&G DuraVent engineers are expertly skilled to develop venting components to OEM specs. To satisfy specific venting requirements, DuraVent has the experience to provide custom design, prototyping and testing of vent systems and components engineered to the demands of specific appliances.

The PolyPro Commercial Difference


- Available in 5in. (130mm), 6in. (150mm) and 8in. (200mm) diameters.
- Completely smooth inner wall for optimal flow performance.
- Components designed for complete discharge of condensate.
- Design allows for system distance adjustment from the back of the appliance.
- Sizing services available to help in calculating required vent size.

New & Improved Locking System

Incorporates a locking tab on the male end of the pipe and a revised locking band that slides over the tab, twists and firmly grasps the socket of the next pipe. This approach offers installers a number of important advantages including a secure mechanical connection (rather than relying on friction alone) and the ability to inspect the joint after installation for proper insertion depth.

The locking band is placed on the pipe, elbows and tees at the factory. Including the locking band(s) with the part will ensure the requirement for the listing is met. There is no need to remember to include separate locking bands on your order as before. All new parts with the upgraded locking system will have a new part number ending in "L".

To see the new PolyPro locking system, visit duravent.com and click on the link for the PolyPro Locking System video or scan the QR code below with your smartphone.

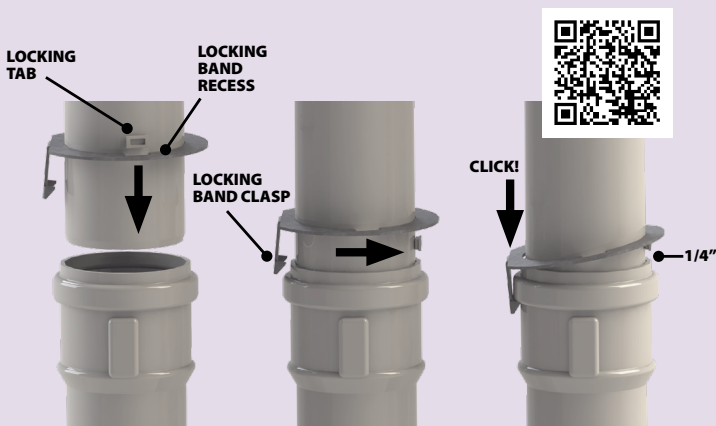

M&G DuraVent is dedicated to one thing: focusing on the design and manufacturing of venting products. As experts in this industry, our team is passionate about creating innovative, quality products. We invest in equipment with the latest technology to develop and test venting products that are engineered to one standard: excellence. All measuring equipment is calibrated to the same levels as used by testing agencies and are compliant with ISO 17025, the test-laboratory standard.



Wind Tunnel Laboratory


The wind tunnel lab allows us to gather precise data with 270 degrees of measurement on terminations. All data is analyzed for product performance under rigorous conditions before going to market.

Rain Testing


M&G labs test the vapor/moisture barrier of products by subjecting them to extreme rain and wind conditions. These tests are compliant with both the US and Canadian requirements as well as the stringent European standards.

Climate Testing


M&G labs have developed a patented ice testing system in the climate room. Tests run to -4°F (-20°C). PolyPro vertical terminations are engineered to remain icicle free.

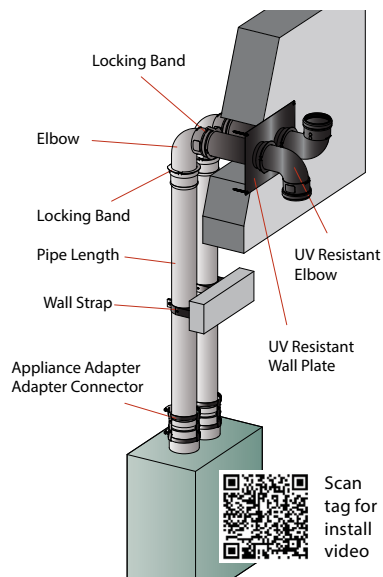


Horizontal Twin Pipe Elbow Termination

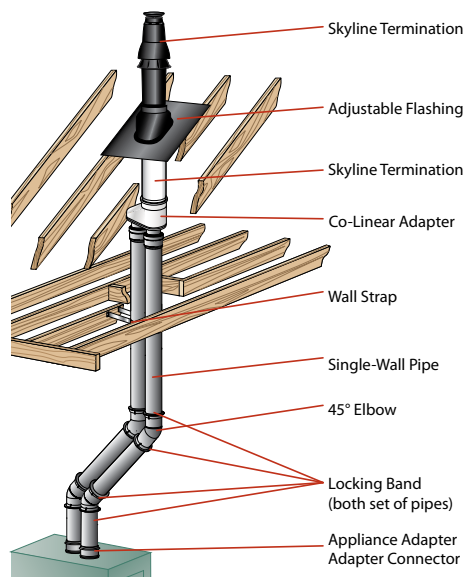


Twin Pipe with Concentric Termination

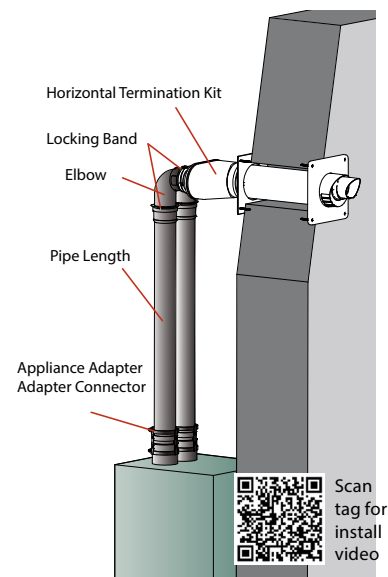

Horizontal Twin Pipe Concentric

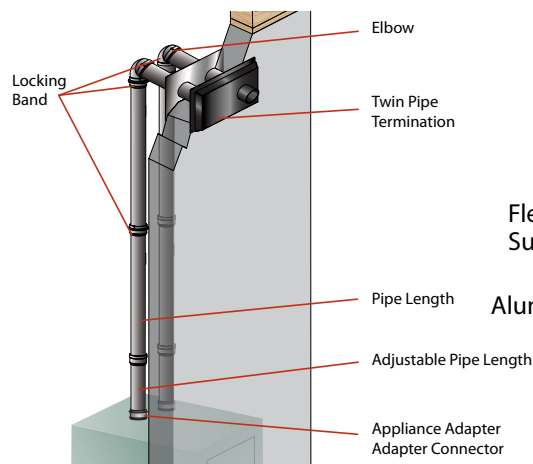


Horizontal Twin Pipe Below Grade

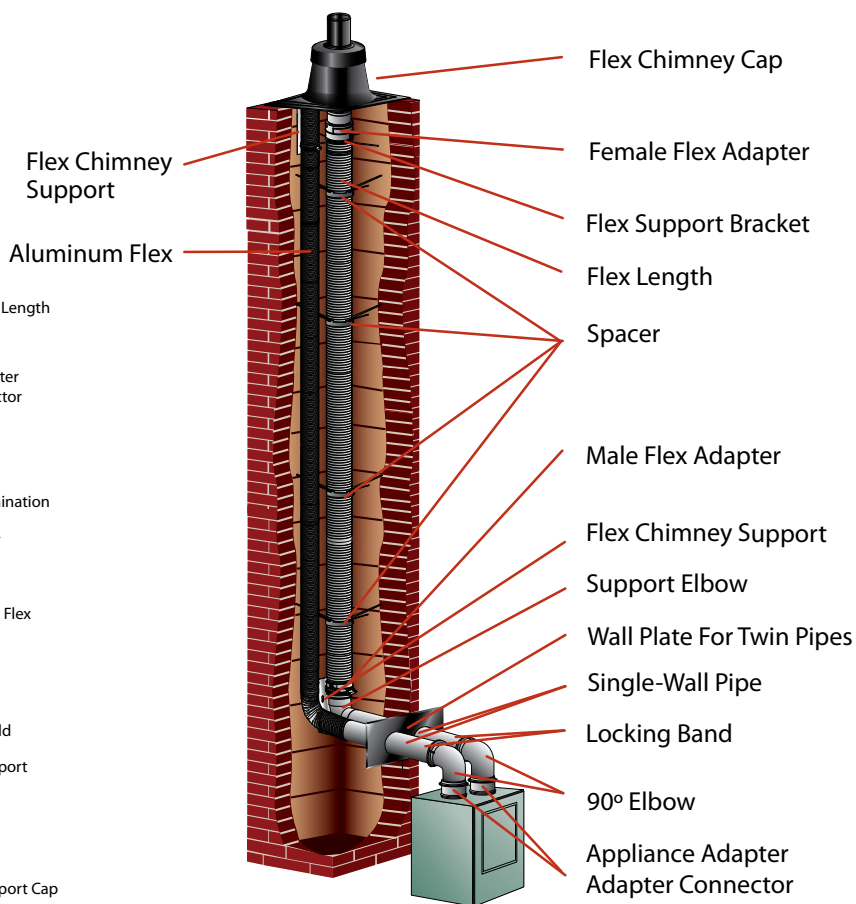

Flex Through Chimney w/Air Intake


See PolyPro Flex section for information on how to create your own air intake kit.

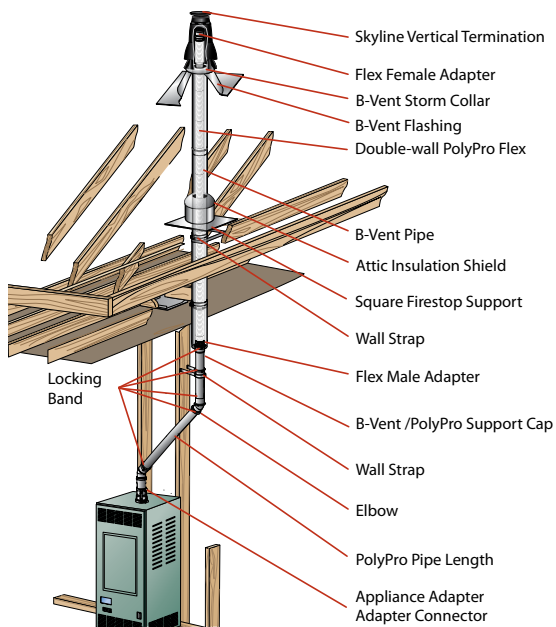

Flex Through B vent as a Chase

PolyPro Venting System


Single-Wall Pipe

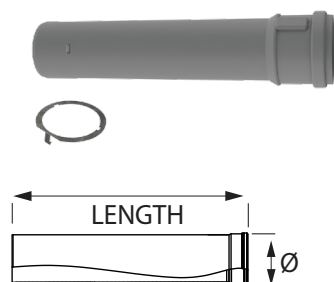

Use to vent condensing appliances. 2" | 60mm of overlap at the joint. Listed to ULC S636. Locking Bands are required at all joint connections 2"-4" diameters. Includes 1 Locking Band.

| SIZE | 12" 305mm | | 36" 914mm | | 72" 1829mm | |
|------------|--------------|-----------|--------------|-----------|--------------|-----------|
| | ORDER # | STOCK # | ORDER # | STOCK # | ORDER # | STOCK # |
| 2" 60mm | 2PPS-12L | 810009667 | 2PPS-36L | 810009669 | 2PPS-72L | 810009671 |
| 3" 80mm | 3PPS-12L | 810009657 | 3PPS-36L | 810009696 | 3PPS-72L | 810009698 |
| 4" 100mm | 4PPS-12L | 810009723 | 4PPS-36L | 810009725 | 4PPS-72L | 810009727 |
| 5" 130mm | 5PPS-12L | 810009755 | 5PPS-36L | 810009756 | 5PPS-72L | 810009757 |
| 6" 150mm | 6PPS-12L | 810009772 | 6PPS-36L | 810009774 | 6PPS-72L | 810009776 |
| SIZE | 40" 1016mm | | 75" 1905mm | | | |
| | ORDER # | STOCK # | ORDER # | STOCK # | | |
| 8" 200mm | 8PPS-40L | 810009793 | 8PPS-75L | 810009794 | | |


Black UV Resistant Single-Wall Pipe

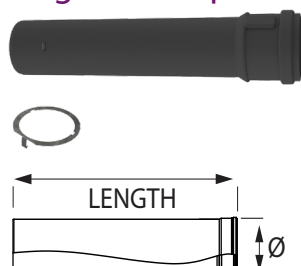

Use to vent condensing appliances. 2" | 60mm of overlap at the joint. Listed to ULC S636. Made of UV resistant polypropylene. Includes 1 Locking Band.

| SIZE | 12" 305mm | | 36" 914mm | |
|------------|-------------|-----------|-------------|-----------|
| | ORDER # | STOCK # | ORDER # | STOCK # |
| 2" 60mm | 2PPS-12BL | 810009668 | 2PPS-36BL | 810009670 |
| 3" 80mm | 3PPS-12BL | 810009695 | 3PPS-36BL | 810009697 |
| 4" 100mm | 4PPS-12BL | 810009724 | 4PPS-36BL | 810009726 |
| 6" 150mm | 6PPS-12BL | 810009773 | 6PPS-36BL | 810009775 |


Adjustable Pipe

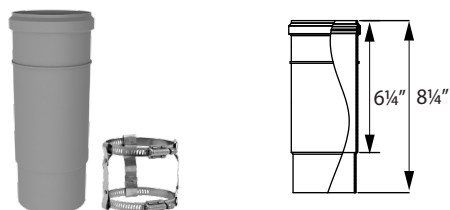

Use to add length to straight length of PolyPro pipe. Slips over standard single-wall pipe length. 4 1/2" | 114mm of adjustment. Adjustable pipe not available in 8" | 200mm diameter. Includes 1 Adapter Connector clamp.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|-----------|-----------|------------|-----------|-----------|
| 2" 60mm | 2PPS-08AL | 810009674 | 5" 130mm | 5PPS-08AL | 810009759 |
| 3" 80mm | 3PPS-08AL | 810009702 | 6" 150mm | 6PPS-08AL | 810009778 |
| 4" 100mm | 4PPS-08AL | 810009731 | | | |


Test Port

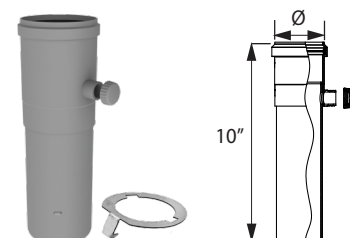

Use to test for proper appliance operation without penetrating or disconnecting the vent wall. Install immediately above the appliance. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-TPL | 810009690 | 5" 130mm | 5PPS-TPL | 810009769 |
| 3" 80mm | 3PPS-TPL | 810009718 | 6" 150mm | 6PPS-TPL | 810009789 |
| 4" 100mm | 4PPS-TPL | 810009751 | 8" 200mm | 8PPS-TPL | 810009805 |


45° Elbow

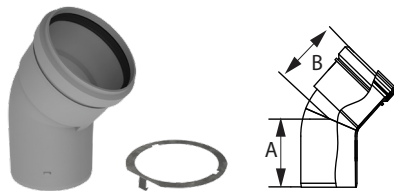

Offsets around obstructions as needed. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A | B |
|------------|-----------|-----------|-----------------|------------------|
| 2" 60mm | 2PPS-E45L | 810009675 | 2 7/8" 72.5mm | 2 11/16" 69mm |
| 3" 80mm | 3PPS-E45L | 810009703 | 2 7/8" 73mm | 2 7/8" 73mm |
| 4" 100mm | 4PPS-E45L | 810009733 | 2 13/16" 78mm | 2 13/16" 78mm |
| 5" 130mm | 5PPS-E45L | 810009760 | 3 3/4" 95mm | 3 13/16" 98mm |
| 6" 150mm | 6PPS-E45L | 810009781 | 3 13/16" 98mm | 3 15/16" 101mm |
| 8" 200mm | 8PPS-E45L | 810009798 | 4 7/8" 111mm | 5 7/8" 131mm |


Black UV Resistant 45° Elbow

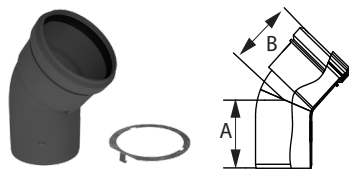

Offsets around obstructions as needed. Made of UV resistant polypropylene. May be used for terminations. Order Bird Guard Screen to protect opening. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A | B |
|------------|------------|-----------|-----------------|-----------------|
| 2" 60mm | 2PPS-E45BL | 810009676 | 2 7/8" 73mm | 2 11/16" 69mm |
| 3" 80mm | 3PPS-E45BL | 810009704 | 2 7/8" 73mm | 2 7/8" 73mm |
| 4" 100mm | 4PPS-E45BL | 810009734 | 2 13/16" 78mm | 2 1/2" 65mm |


90° Elbow

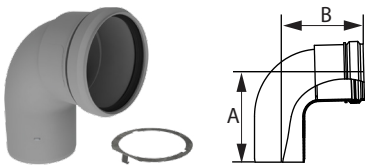

Offsets around obstructions as needed. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A | B |
|------------|-----------|-----------|------------------|------------------|
| 2" 60mm | 2PPS-E90L | 810009677 | 4" 100mm | 4" 100mm |
| 3" 80mm | 3PPS-E90L | 810009658 | 4 5/16" 110mm | 4 5/16" 110mm |
| 4" 100mm | 4PPS-E90L | 810009735 | 4 1/2" 115mm | 4 1/2" 115mm |
| 5" 130mm | 5PPS-E90L | 810009761 | 6 3/4" 169mm | 5 15/16" 152mm |
| 6" 150mm | 6PPS-E90L | 810009782 | 7 1/4" 183mm | 6 1/2" 166mm |
| 8" 200mm | 8PPS-E90L | 810009799 | 8 15/16" 227mm | 7 3/4" 195mm |

Black UV Resistant 90° Elbow

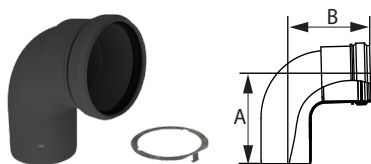

Offsets around obstructions as needed. Made of UV resistant polypropylene. May be used for terminations. Order Bird Guard Screen to protect opening. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A | B |
|------------|------------|-----------|-----------------|-----------------|
| 2" 60mm | 2PPS-E90BL | 810009678 | 4" 100mm | 4" 100mm |
| 3" 80mm | 3PPS-E90BL | 810009705 | 4 5/16" 110mm | 4 5/16" 110mm |
| 4" 100mm | 4PPS-E90BL | 810009736 | 4 1/2" 115mm | 4 1/2" 115mm |
| 6" 150mm | 6PPS-E90BL | 810009783 | 7 1/4" 183mm | 6 1/2" 166mm |


Black UV Resistant Extended 90° Elbow



Made of UV resistant polypropylene. May be used for terminations. Order Bird Guard Screen to protect opening. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A | B |
|------------|-------------|-----------|-----------------|------------------|
| 2" 60mm | 2PPS-E90EBL | 810009679 | 14" 358mm | 16" 405mm |
| 3" 80mm | 3PPS-E90EBL | 810009706 | 14 1/4" 360mm | 16 5/16" 415mm |
| 4" 100mm | 4PPS-E90EBL | 810009737 | 14 1/4" 360mm | 16 1/2" 420mm |

Condensate Drain

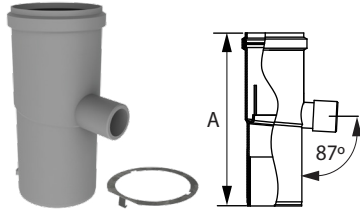

Use to properly manage corrosive condensates common with high efficiency gas appliances. Reference 8PPS-CD for 8" Tee Cap with integrated drain. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A | SIZE | ORDER # | STOCK # | A |
|------------|----------|-----------|------------|------------|----------|-----------|------------|
| 2" 50mm | 2PPS-CDL | 810000347 | 7" 180mm | 5" 130mm | 5PPS-CDL | 810000350 | 7" 180mm |
| 3" 80mm | 3PPS-CDL | 810000348 | 7" 180mm | 6" 150mm | 6PPS-CDL | 810000351 | 7" 180mm |
| 4" 100mm | 4PPS-CDL | 810000349 | 7" 180mm | | | | |

Tee Cap



Use cap on Tees, Condensate Drain or on other components where a cap is needed.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|---------|-----------|------------|---------|-----------|
| 2" 60mm | 2PPS-C | 810004103 | 5" 130mm | 5PPS-C | 810004226 |
| 3" 80mm | 3PPS-C | 810004142 | 6" 150mm | 6PPS-C | 810004261 |
| 4" 100mm | 4PPS-C | 810004185 | 8" 200mm | 8PPS-C | 810004292 |


Tee Cap with Condensate Drain



Use cap on Tees, Condensate Drain or on other components where a cap is needed.

| SIZE | ORDER # | STOCK # |
|------------|---------|-----------|
| 2" 60mm | 2PPS-CD | 810004104 |
| 8" 200mm | 8PPS-CD | 810004291 |


Tee with Cap

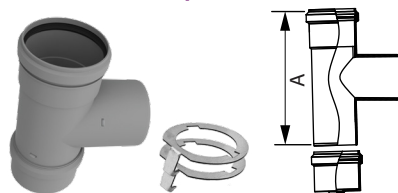

Use for a 90° offset or to combine connections. 8" diameter includes cap. Includes 2 Locking Bands.

| SIZE | ORDER # | STOCK # | A | SIZE | ORDER # | STOCK # | A |
|------------|---------|-----------|------------------|------------|---------|-----------|-------------------|
| 2" 60mm | 2PPS-TL | 810009687 | 7" 180mm | 5" 130mm | 5PPS-TL | 810009767 | 11" 280mm |
| 3" 80mm | 3PPS-TL | 810009659 | 7 7/8" 200mm | 6" 150mm | 6PPS-TL | 810009787 | 11" 280mm |
| 4" 100mm | 4PPS-TL | 810009748 | 8 11/16" 220mm | 8" 200mm | 8PPS-TL | 810009803 | 13 13/16" 350mm |

Black UV Resistant Tee

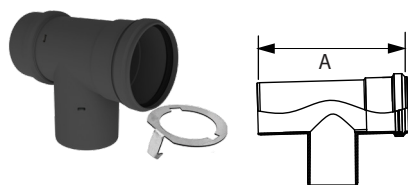

Use as a termination. Made of UV resistant polypropylene. Gasket not included. Order Bird Guard Screen to protect opening. Includes 1 Locking Bands.

| SIZE | ORDER # | STOCK # | A |
|------------|----------|-----------|-----------------|
| 2" 60mm | 2PPS-TBL | 810009688 | 7" 180mm |
| 3" 80mm | 3PPS-TBL | 810009716 | 7 7/8" 200mm |
| 4" 100mm | 4PPS-TBL | 810009749 | 8 1/16" 220mm |


Black UV Resistant Termination Tee



Use as a termination. Manufactured with two female ends to accept Bird Screen on both ends. Use bird screen to protect openings. Made of UV resistant polypropylene. Bird Guard Screens & 2 Locking Bands included.

| SIZE | ORDER # | STOCK # |
|------------|-----------|-----------|
| 6" 150mm | 6PPS-TTBL | 810009790 |


Black Wall Plate

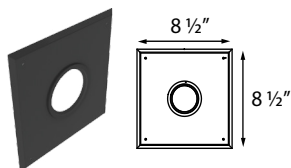

Use to trim wall penetration. Painted black metal with gasket.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-WPB | 810004112 | 4" 100mm | 4PPS-WPB | 810004195 |
| 3" 80mm | 3PPS-WPB | 810004152 | | | |


Black Wall Plate for Twin Pipes

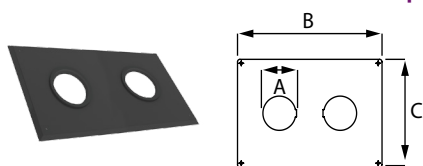

Use to trim wall penetration when using two pipes. Painted black metal with gasket.


| SIZE | ORDER # | STOCK # | A | B | C |
|------------|----------|-----------|------------|-----------------|----------------|
| 2" 60mm | 2PPS-WPT | 810004113 | 2" 60mm | 11 7/8" 302mm | 8 1/2" 216mm |
| 3" 80mm | 3PPS-WPT | 810004153 | 3" 80mm | 11 7/8" 302mm | 8 1/2" 216mm |
| 4" 100mm | 4PPS-WPT | 810004196 | 4" 100mm | 12 7/8" 327mm | 8 1/2" 216mm |

Tee with Drain Cap

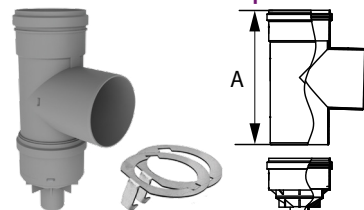

Use to manage condensates at the bottom of a vertical run. Includes 2 Locking Bands.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|-----------|-----------|------------|-----------|-----------|
| 2" 60mm | 2PPS-TCDL | 810009689 | 5" 130mm | 5PPS-TCDL | 810009768 |
| 3" 80mm | 3PPS-TCDL | 810009717 | 6" 150mm | 6PPS-TCDL | 810009788 |
| 4" 100mm | 4PPS-TCDL | 810009750 | 8" 200mm | 8PPS-TCDL | 810009804 |

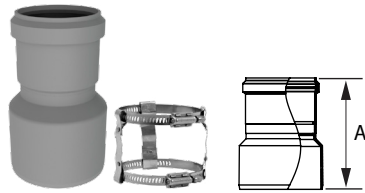Reducer


Use to transition the vent system to a smaller diameter. Includes 1 Adapter Connector clamp.

| SIZE | ORDER # | STOCK # | A |
|-----------------------|----------|-----------|------------------|
| 3" - 2" 80 - 60mm | 3PPS-R2L | 810009714 | 5" 130mm |
| 4" - 3" 100 - 80mm | 4PPS-R3L | 810009746 | 5" 130mm |
| 5" - 4" 130 - 100mm | 5PPS-R4L | 810009764 | 7 5/8" 193mm |
| 6" - 5" 150 - 130mm | 6PPS-R5L | 810009785 | 7 3/4" 197mm |
| 8" - 6" 200 - 150mm | 8PPS-R6L | 810009801 | 5 15/16" 150mm |


Increaser

Use to transition the vent system to a larger diameter. Install in vertical orientation. Includes 1 Adapter Connector clamp.

| SIZE | ORDER # | STOCK # | A |
|-----------------------|----------|-----------|-----------------|
| 2" - 3" 60 - 80mm | 2PPS-X3L | 810009694 | 4 5/16" 110mm |
| 3" - 4" 80 - 100mm | 3PPS-X4L | 810009722 | 4 5/16" 110mm |
| 4" - 5" 100 - 130mm | 4PPS-X5L | 810009754 | 4 5/16" 110mm |
| 5" - 6" 130 - 150mm | 5PPS-X6L | 810009771 | 4 5/16" 110mm |
| 6" - 8" 150 - 200mm | 6PPS-X8L | 810009792 | 5 3/4" 145mm |

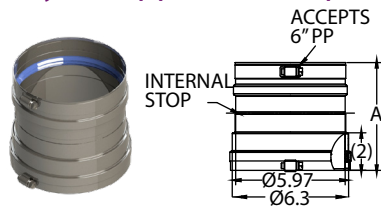6" Fulton EDR 750-1500 to 6" PolyPro Appliance Adapter

| SIZE | ORDER # | STOCK # | A |
|------|-------------------|-----------|------|
| 6" | 6PPS-FULTEDR-6PPF | 810010023 | 5.9" |

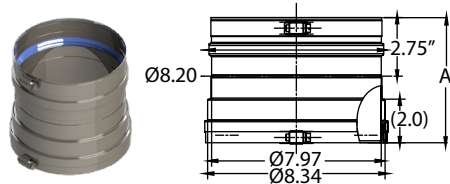8" Fulton EDR 2000 to 8" PolyPro Appliance Adapter

| SIZE | ORDER # | STOCK # | A |
|------|-------------------|-----------|------|
| 8" | 8PPS-FULTEDR-8PPF | 810010025 | 5.9" |

Appliance Adapter for PVC Pipe

Use to connect PolyPro vent system to an appliance outlet. Has a double female adapter. One end accepts PVC male pipe and the other accepts PolyPro male pipe. No adapter connector and/or Locking Band required.

| SIZE | ORDER # | STOCK # |
|------------|-----------|-----------|
| 3" 80mm | 3PPS-AD-M | 810007169 |
| 4" 100mm | 4PPS-AD-M | 810007170 |

Appliance Adapter for PVC Coupler



Use to adapt rigid PolyPro pipe length to the inside of the PVC/CPVC coupler or other plastic appliance outlet. Must be used with Adapter Connector for flue gas. Includes 1 Adapter Connector clamp.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-ADL | 810009672 | 4" 100mm | 4PPS-ADL | 810009728 |
| 3" 80mm | 3PPS-ADL | 810009699 | | | |


Female Appliance Adapter



Use to connect PolyPro to a nominal sized pipe with a smooth male end outlet. No adapter connector and/or Locking Band required. Hose clamps on both ends.

| SIZE | ORDER # | STOCK # | A | B | C |
|------------|------------|-----------|------------------|------------|------------|
| 3" 80mm | FSAAU3-3PP | 810004171 | 3 1/5" 81mm | 3" 80mm | 5" 130mm |
| 4" 100mm | FSAAU4-4PP | 810004210 | 4" 100mm | 4" 100mm | 5" 130mm |
| 6" 150mm | FSAAU6-6PP | 810004283 | 5 15/16" 151mm | 6" 150mm | 5" 130mm |
| 8" 200mm | FSAAU8-8PP | 810004312 | 7 15/16" 199mm | 8" 200mm | 5" 130mm |


Male PVC Appliance Adapter

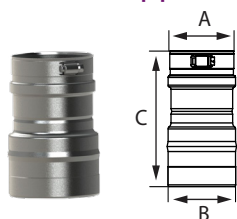

Use to connect PolyPro vent system to a standard stainless steel appliance outlet equipped with an integrated hose clamp and gasket. Must be used with Adapter Connector for flue gas, unless a clamp is supplied on the appliance outlet. Same O.D. as PVC.

| SIZE | ORDER # | STOCK # | A | B | C |
|-----------------|-----------------|-----------|-----------------|-----------------|------------------|
| 3" to 2" 80mm | 3PPS-03PVC-2PPF | 810007345 | 2 2/5" 61mm | 3 1/2" 89mm | 6" 150mm |
| 3" to 3" 80mm | 3PPS-03PVC-3PPF | 810004167 | 3 3/16" 81mm | 3 1/2" 89mm | 6 13/16" 173mm |
| 4" 100mm | 4PPS-04PVC-4PPF | 810004207 | 4" 102mm | 4 1/2" 114mm | 6 13/16" 173mm |
| 6" 150mm | 6PPS-06PVC-6PPF | 810004281 | 5 3/16" 132mm | 5 9/16" 141mm | 6 13/16" 173mm |
| 8" 200mm | 8PPS-08PVC-8PPF | 810004310 | 6" 152mm | 6 5/8" 168mm | 6 15/16" 176mm |


Female PVC Appliance Adapter

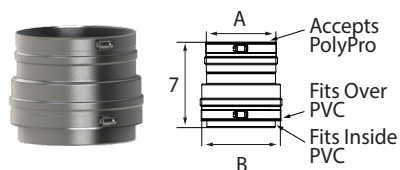

Use to directly connect PolyPro to a male PVC Pipe appliance outlet. Seals on the O.D. of the PVC pipe and has a clamp. No adapter connector and/or Locking Band required.

| SIZE | ORDER # | STOCK # | A | B |
|------------|-----------------|-----------|------------------|------------------|
| 5" 130mm | 5PPS-05PVC-5PPF | 810004244 | 5" 130mm | 5 11/16" 144mm |
| 6" 150mm | 6PPS-06PVC-6PPF | 810004280 | 5 15/16" 151mm | 6 11/16" 170mm |
| 8" 200mm | 8PPS-08PVC-8PPF | 810004309 | 7 15/16" 132mm | 7 7/8" 200mm |


FasNSeal Adapter

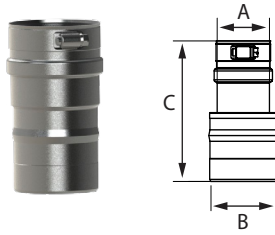

Use to transition from FasNSeal vent system to PolyPro vent system. Can be used as an appliance adapter or inline. No Locking Band required.

| SIZE | ORDER # | STOCK # | A | B | C |
|------------|--------------|-----------|------------------|-----------------|------------------|
| 3" 80mm | FSA-03M-2PPF | 810004170 | 2 3/8" 60mm | 3" 76mm | 6 1/8" 156mm |
| 3" 80mm | FSA-03M-3PPF | 810004169 | 3 1/8" 79mm | 3" 76mm | 5 15/16" 151mm |
| 4" 100mm | FSA-04M-4PPF | 810004209 | 4" 100mm | 4" 100mm | 5 15/16" 151mm |
| 5" 130mm | FSA-05M-5PPF | 810004247 | 5 3/16" 132mm | 5" 130mm | 5 15/16" 151mm |
| 6" 150mm | FSA-06M-6PPF | 810007030 | 5 15/16" 151mm | 6" 150mm | 6" 150mm |
| 7" 178mm | FSA-07M-6PPF | 810004463 | 6 1/8" 156mm | 6 3/16" 160mm | 7" 178mm |
| 8" 200mm | FSA-08M-8PPF | 810007031 | 8" 200mm | 8" 200mm | 6" 150mm |


PolyPro to FasNSeal Adapter

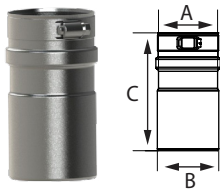

Use to transition from PolyPro vent system to FasNSeal vent system or to connect a metric appliance to FasNSeal. Can be used as an appliance adapter or inline. Locking Band required for 3" - 4" diameters, recommended for 5" - 8" diameters.

| SIZE | ORDER # | STOCK # | A | B | C |
|------------|-----------------|-----------|------------|------------------|------------------|
| 3" 80mm | 3PPS-ADM-03FNSF | 810009701 | 3" 80mm | 3 1/8" 79mm | 3 13/16" 97mm |
| 4" 100mm | 4PPS-ADM-04FNSF | 810009730 | 4" 100mm | 3 15/16" 99mm | 5 15/16" 151mm |
| 5" 130mm | 5PPS-ADM-05FNSF | 810009758 | 5" 130mm | 5 1/8" 131mm | 5 15/16" 151mm |
| 6" 150mm | 6PPS-ADM-06FNSF | 810009777 | 6" 150mm | 5 15/16" 151mm | 7" 178mm |
| 8" 200mm | 8PPS-ADM-08FNSF | 810009795 | 8" 200mm | 7 7/8" 199mm | 7" 178mm |


Adapter Connector

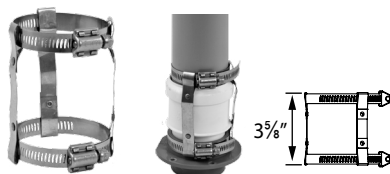

Use to secure PolyPro pipe to PVC/CPVC coupler or appliance outlet. Universal size for 2-4 inch and 5-8 inch systems. M&G DuraVent requires its use with flue gas applications and recommends it with air intake applications.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|---------|---------|-----------|---------|----------|-----------|
| 2" - 4" | PPS-PAC | 810004128 | 5" - 8" | PPS-PACL | 810004243 |

Wall Strap - metal

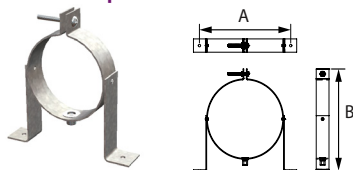

Use to support offsets and pipe used in vertical rise or horizontal runs as per installation instructions. Wall Strap legs can be rotated up to 360° for versatility. Accepts standard 1/4" all-thread. Available in galvanized or stainless steel metals. Note: Vent pipe must be supported at least every 10 feet (3m) vertically. Horizontal or sloped sections of vent pipe require a wall strap on each pipe section.

| SIZE | GALVANIZED | | A | B | SIZE | STAINLESS STEEL | | A | B |
|------------|------------|-----------|----------------|----------------|------------|-----------------|-----------|----------------|----------------|
| | ORDER # | STOCK # | | | | ORDER # | STOCK # | | |
| 2" 60mm | 2PPS-WSM | 810004110 | 3 5/8" 92mm | 4 7/8" 124mm | 2" 60mm | 2PPS-WSM-SS | 810004111 | 3 5/8" 92mm | 4 7/8" 124mm |
| 3" 80mm | 3PPS-WSM | 810004150 | 4 3/8" 112mm | 5 1/4" 133mm | 3" 80mm | 3PPS-WSM-SS | 810004151 | 4 3/8" 112mm | 5 1/4" 133mm |
| 4" 100mm | 4PPS-WSM | 810004193 | 5 1/8" 130mm | 5 5/8" 143mm | 4" 100mm | 4PPS-WSM-SS | 810004194 | 5 1/8" 130mm | 5 5/8" 143mm |
| 5" 130mm | 5PPS-WSM | 810004232 | 6 3/8" 162mm | 6 3/4" 171mm | 5" 130mm | 5PPS-WSM-SS | 810004233 | 6 3/8" 162mm | 6 3/4" 171mm |
| 6" 150mm | 6PPS-WSM | 810004266 | 7 1/8" 181mm | 7 5/8" 194mm | 6" 150mm | 6PPS-WSM-SS | 810004267 | 7 1/8" 181mm | 7 5/8" 194mm |
| 8" 200mm | 8PPS-WSM | 810004296 | 9 1/8" 232mm | 9 5/8" 245mm | 8" 200mm | 8PPS-WSM-SS | 810004297 | 9 1/8" 232mm | 9 5/8" 245mm |


Locking Band



Use to secure two sections of pipe together. Required to comply with ULC S636 listed installations for 2" to 4" diameters. Locking Bands are recommended for 5" diameter.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-LB2 | 810009654 | 5" 130mm | 5PPS-LB2 | 810009914 |
| 3" 80mm | 3PPS-LB2 | 810009655 | 6" 150mm | 6PPS-LB2 | 810009915 |
| 4" 100mm | 4PPS-LB2 | 810009656 | 8" 200mm | 8PPS-LB2 | 810009916 |

 
Locking Band Clamp



Use to secure two sections of pipe together. Locking Bands are recommended for 5"-8" diameters. Use to secure two sections of PolyPro pipe together. Typically used in vertical installations.

| SIZE | ORDER # | STOCK # | A | B |
|------------|----------|-----------|----------------|---------------|
| 2" 60mm | 2PPS-LBC | 810007146 | 2 3/8" 60mm | 2 1/2" 64mm |
| 3" 80mm | 3PPS-LBC | 810007147 | 3 1/8" 80mm | 2 1/2" 64mm |
| 4" 100mm | 4PPS-LBC | 810007148 | 4" 100mm | 2 1/2" 64mm |
| 5" 130mm | 5PPS-LBC | 810004242 | 5 1/8" 130mm | 2 1/2" 64mm |
| 6" 150mm | 6PPS-LBC | 810004278 | 6 1/8" 156mm | 2 1/2" 64mm |
| 8" 200mm | 8PPS-LBC | 810004306 | 8 1/8" 207mm | 2 1/2" 64mm |


Firestop Spacer

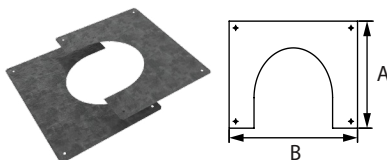

Use when penetrating floor levels. Two piece design for easier installation.

| SIZE | SINGLE-WALL PIPE | | A | B |
|------------|------------------|-----------|-----------------|-----------------|
| | ORDER # | STOCK # | | |
| 2" 60mm | 2PPS-FSS | 810004115 | 4" 100mm | 7" 178mm |
| 3" 80mm | 3PPS-FSS | 810004155 | 4" 100mm | 7" 178mm |
| 4" 100mm | 4PPS-FSS | 810004198 | 4" 100mm | 7" 178mm |
| 5" 130mm | 5PPS-FSS | 810004234 | 8 1/8" 206mm | 10" 254mm |
| 6" 150mm | 6PPS-FSS | 810004269 | 7 3/4" 197mm | 9 3/4" 248mm |
| 8" 200mm | 8PPS-FSS | 810004298 | 10 1/2" 267mm | 12 3/4" 324mm |
| SIZE | CONCENTRIC PIPE | | A | B |
| | ORDER # | STOCK # | | |
| 2" 60mm | 2PPS-FS | 810004114 | 7" 178mm | 8 3/4" 223mm |
| 3" 80mm | 3PPS-FS | 810004154 | 7 7/8" 200mm | 9 7/8" 251mm |
| 4" 100mm | 4PPS-FS | 810004197 | 7 7/8" 200mm | 9 7/8" 251mm |


Flat Roof Flashing

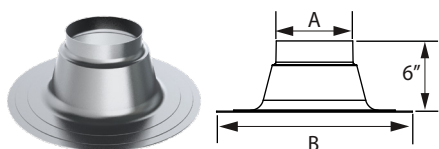

Use to weather-proof the penetration of vent pipe through the roof. For concentric pipe.

| SIZE | SINGLE-WALL PIPE | | A | B |
|------------|------------------|-----------|----------------|------------------|
| | ORDER # | STOCK # | | |
| 5" 130mm | 5PPS-FF | 810007171 | 5 1/2" 140mm | -- |
| 6" 150mm | 6PPS-FF | 810004268 | 6 1/4" 160mm | -- |
| 8" 200mm | 8PPS-FF | 810004302 | 8 1/4" 210mm | -- |
| SIZE | CONCENTRIC PIPE | | A | B |
| | ORDER # | STOCK # | | |
| 2" 60mm | 2PPS-FF | 810004116 | 4 5/8" 120mm | 13 3/4" 350mm |
| 3" 80mm | 3PPS-FF | 810004156 | 5 1/2" 140mm | 15 5/16" 390mm |
| 4" 100mm | 4PPS-FF | 810004199 | 6 1/4" 170mm | 17" 430mm |


Adjustable Roof Flashing 1/12 - 5/12 pitch

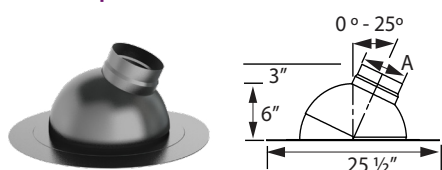

Use to weather proof penetration of vent through the roof. For concentric pipe. Made of aluminum. Adjusts from 0 - 25° (0/12 to 5/12).

| SIZE | CONCENTRIC PIPE | | A |
|-----------------------|-----------------|-----------|------------|
| | ORDER # | STOCK # | |
| 2" x 4" 60 - 100mm | 2PPS-F5 | 810004117 | 4" 100mm |
| 3" x 5" 80 - 130mm | 3PPS-F5 | 810004157 | 5" 130mm |
| 4" x 6" 100 - 150mm | 4PPS-F5 | 810004200 | 6" 150mm |


Adjustable Roof Flashing 5/12 - 12/12 pitch

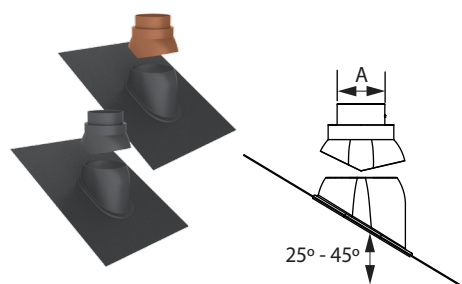

Use to weather proof penetration of vent through the roof. For concentric pipe. Made of polypropylene. Adjusts from 25° to 45° (5/12 to 12/12). Black or terra-cotta. UV resistant.

| SIZE | BLACK | | A |
|-----------------------|-------------|-----------|------------|
| | ORDER # | STOCK # | |
| 2" x 4" 60 - 100mm | 2PPS-F12 | 810004118 | 4" 100mm |
| 3" x 5" 80 - 130mm | 3PPS-F12 | 810004158 | 5" 130mm |
| 4" x 6" 100 - 150mm | 4PPS-F12 | 810004201 | 6" 150mm |
| SIZE | TERRA-COTTA | | A |
| | ORDER # | STOCK # | |
| 2" x 4" 60 - 100mm | 2PPS-F12-TC | 810004119 | 4" 100mm |
| 3" x 5" 80 - 130mm | 3PPS-F12-TC | 810004159 | 5" 130mm |
| 4" x 6" 100 - 150mm | 4PPS-F12-TC | 810004202 | 6" 150mm |


Twin Pipe Termination

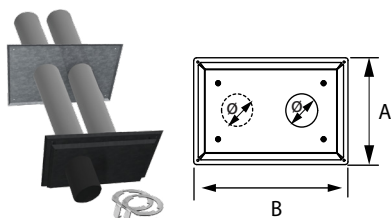

Use to terminate horizontally with two single-wall PolyPro pipes for intake and exhaust. Simple design ensures adequate separation of intake air from exhaust. Termination is painted black. Includes black UV resistant polypropylene exhaust nozzle equipped with Bird Screen, interior wall plate, and two 12" pipe lengths. Includes 2 Locking Bands.

| SIZE | ORDER # | STOCK # | A | B |
|------------|-----------|-----------|----------------|-----------------|
| 2" 60mm | 2PPS-HTPL | 810009685 | 8 1/2" 216mm | 11 7/8" 302mm |
| 3" 80mm | 3PPS-HTPL | 810009713 | 8 1/2" 216mm | 11 7/8" 302mm |
| 4" 100mm | 4PPS-HTPL | 810009745 | 8 1/2" 216mm | 12 1/4" 311mm |

Single Horizontal Termination

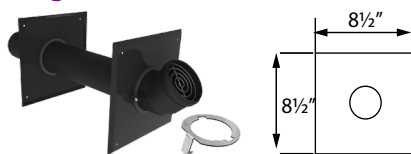

Use to terminate horizontally with one single-wall PolyPro pipe. Termination and wall plate can be rotated to suit application. Elbow is UV resistant black with bird screen. Also includes interior wall plate, and 14" length of pipe. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # |
|-----------|-----------|-----------|
| 2" 60mm | 2PPS-HSTL | 810009684 |
| 3" 80mm | 3PPS-HSTL | 810009712 |


Lochinvar Horizontal Termination Kit



Use to adapt PolyPro to the IpeX 636 low profile termination. Kit includes 14" pipe welded to an adapter and metal backing plate. Check with appliance manufacturer for approval. (Outer IPEX termination cap not included. Supplied by others.) Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A | B |
|------------|-----------|-----------|------------------|----------------|
| 2" 60mm | 2PPS-HLKL | 810009683 | 14 3/16" 360mm | 8 5/8" 220mm |
| 3" 80mm | 3PPS-HLKL | 810009711 | 14 3/16" 360mm | 8 5/8" 220mm |
| 4" 100mm | 4PPS-HLKL | 810009743 | 14 3/16" 360mm | 8 5/8" 220mm |


Vertical Termination Cap Kit - Concentric

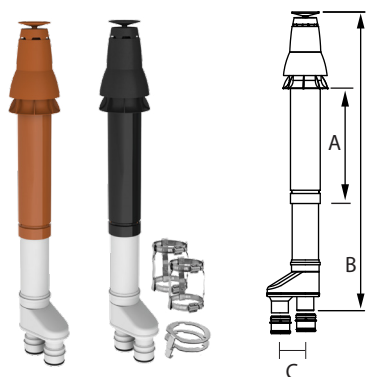

Use for concentric vertical terminations. Includes 2 appliance adapters and co-linear adapter. Black or terra-cotta cap. UV resistant. Includes 2 Locking Bands and 2 Adapter Connector clamps.

| SIZE | BLACK | | A | B | C |
|-----------------------|-------------|-----------|-------------|------------------|----------------|
| | ORDER # | STOCK # | | | |
| 2" x 4" 60 x 100mm | 2PPS-VKL | 810009692 | 18" 460mm | 50 1/4" 1280mm | 4 3/4" 121mm |
| 3" x 5" 80 x 125mm | 3PPS-VKL | 810009720 | 23" 580mm | 53 1/4" 1354mm | 4 3/4" 121mm |
| 4" x 6" 100 x 150mm | 4PPS-VKL | 810009752 | 23" 580mm | 68 1/4" 1735mm | 5 1/2" 140mm |
| SIZE | TERRA-COTTA | | A | B | C |
| | ORDER # | STOCK # | | | |
| 2" x 4" 60 x 100mm | 2PPS-VK-TCL | 810009693 | 18" 460mm | 50 1/4" 1280mm | 4 3/4" 121mm |
| 3" x 5" 80 x 125mm | 3PPS-VK-TCL | 810009721 | 23" 580mm | 53 1/4" 1354mm | 4 3/4" 121mm |
| 4" x 6" 100 x 150mm | 4PPS-VK-TCL | 810009753 | 23" 580mm | 68 1/4" 1735mm | 5 1/2" 140mm |

Horizontal Termination Kit - Concentric

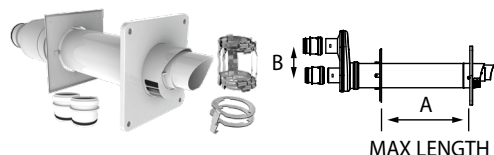

Use for concentric horizontal terminations. Includes 2 appliance adapters, white wall plate, white firestop, and co-linear adapter. White Termination with Bird Guard Screen. UV resistant. Inner plate is 8 5/8" (220mm) square, outer plate is 9 7/16" (240mm) square for all flue sizes. Includes 2 Locking Bands and two Adapter Connector clamps.

| SIZE | ORDER # | STOCK # | A | B |
|-----------------------|----------|-----------|-----------------|----------------|
| 2" - 4" 60 - 100mm | 2PPS-HKL | 810009682 | 13 3/4" 350mm | 4 3/4" 121mm |
| 3" x 5" 80 - 125mm | 3PPS-HKL | 810009710 | 13" 330mm | 4 3/4" 121mm |
| 4" x 6" 100 - 150mm | 4PPS-HKL | 810009742 | 13 3/4" 350mm | 5 1/2" 140mm |

Bird Guard Screen



Use to protect venting system from birds and rodents. Position inside pipe in place of gasket. Stainless steel. Pack of 6.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|---------|-----------|------------|---------|-----------|
| 2" 60mm | 2PPS-BG | 810004341 | 4" 100mm | 4PPS-BG | 810004367 |
| 3" 80mm | 3PPS-BG | 810004355 | 6" 150mm | 6PPS-BG | 810004276 |

EPDM Replacement Gasket



Use as a replacement gasket for rigid PolyPro products. Pack of 12.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|---------|-----------|------------|---------|-----------|
| 2" 60mm | 2PPS-GA | 810004124 | 5" 130mm | 5PPS-GA | 810004237 |
| 3" 80mm | 3PPS-GA | 810004164 | 6" 150mm | 6PPS-GA | 810004272 |
| 4" 100mm | 4PPS-GA | 810004204 | 8" 200mm | 8PPS-GA | 810004303 |

Viton Replacement Gasket




Use as a gasket for oil fuel appliances.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-GAV | 810004126 | 5" 130mm | 5PPS-GAV | 810004238 |
| 3" 80mm | 3PPS-GAV | 810004165 | 6" 150mm | 6PPS-GAV | 810004273 |
| 4" 100mm | 4PPS-GAV | 810004205 | 8" 200mm | 8PPS-GAV | 810004304 |

PolyPro Commercial Venting Components

Vertical Termination for Commercial Systems

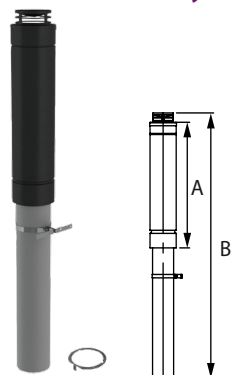


Exhaust termination for vertical through-the-roof applications. PolyPro pipe is protected by a sturdy outer metal pipe and integrated cap. Painted with a durable, powder coated black finish. Includes support hardware, including 1 Locking Band.

To complete vertical termination for commercial systems, installation requires (1) variable pitch roof flashing, (1) support clamp, and (1) storm collar.

| SIZE | ORDER # | STOCK # | A | B | O.D. |
|------------|-----------|-----------|-------------|--------------|----------------|
| 5" 130mm | 5PPS-VTML | 810009770 | 29" 745mm | 62" 1575mm | 6 3/8" 162mm |
| 6" 150mm | 6PPS-VTML | 810009791 | 29" 741mm | 62" 1575mm | 7 1/4" 184mm |
| 8" 200mm | 8PPS-VTML | 810009806 | 32" 800mm | 63" 1600mm | 9 1/8" 232mm |


Variable Pitch Roof Flashing

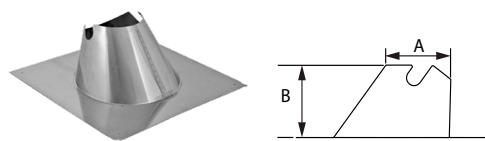

Use to weather-proof the penetration of vent pipe through the roof. For use with VTM. For pitches of 0/12 - 9/12. Made of stainless steel.

| SIZE | ORDER # | STOCK # | A | B |
|------------|---------|-----------|----|----|
| 5" 130mm | FSVPF5 | 810003241 | 7" | 7" |
| 6" 150mm | FSVPF6 | 810003295 | 8" | 7" |
| 8" 200mm | FSVPF8 | 810003383 | 9" | 7" |


Support Clamp

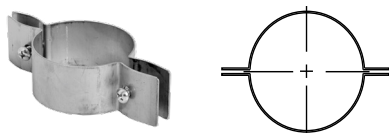

Use to position the Vertical Termination for Commercial Systems (VTM's) to the variable pitch roof flashing. The clamp is upsized one diameter to fit around the black metal outer pipe.

| SIZE | ORDER # | STOCK # | A |
|------------|---------|-----------|--------|
| 5" 130mm | FSCL6 | 810003288 | 1 1/2" |
| 6" 150mm | FSCL7 | 810003332 | 1 1/2" |
| 8" 200mm | FSCL9 | 810003414 | 1 1/2" |


Storm Collar

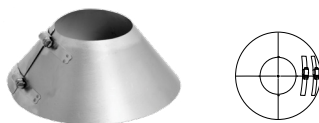

Use to create a weather tight seal between the pipe and flashing. For use with VTM.

| SIZE | ORDER # | STOCK # |
|------------|---------|-----------|
| 5" 130mm | FSCPP5 | 810007172 |
| 6" 150mm | FSCPP6 | 810007173 |
| 8" 200mm | FSCPP8 | 810007174 |


Horizontal Termination for Commercial Systems

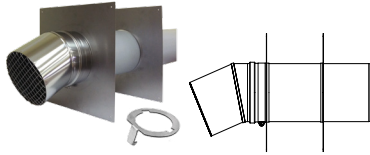

Use to terminate through-the-wall applications. 23 degree Elbow termination made with stainless steel and will fit over PolyPro pipe. Includes bird guard. The kit does not contain a PolyPro adapter. No additional Locking Band is required. For assembly, follow enclosed instructions. Available in Stainless Steel. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # |
|------------|------------|-----------|
| 4" 100mm | 4PPS-HSTSL | 810009744 |
| 5" 130mm | 5PPS-HSTL | 810009763 |
| 6" 150mm | 6PPS-HSTL | 810009784 |
| 8" 200mm | 8PPS-HSTL | 810009800 |

PolyPro Flex Venting Components

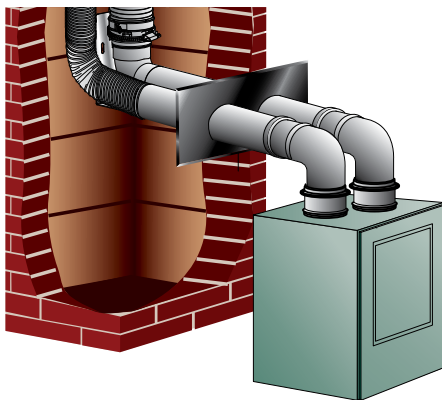

Need An Air Intake Solution? Create Your Own Kit

Order DuraFlex AL length, Hanger Bracket, Coupler and Wall Plate for Twin Pipe. (2" Air intake will require a 2"-3" Increaser: 2PPS-X3)

- (1) DuraFlex AL Length: DFA-25, DFA-35, or DFA-50
- (1) Hanger Bracket: DFA-FCB
- (1) Coupler: DFA-FCP
- (1) Wall Plate for Twin Pipe: PPS-WPT

Flex Chimney Lining Kit



Use for a vertical flex lining system. Includes black, UV resistant chimney cap, rigid flue vent, flex support bracket, 4 spacers in 3" & 4" kits, male and female flex adapters with gaskets, extended support elbow, wall plate, appliance adapter, Locking Band, and Adapter Connector clamp. Flex sold separately.

| SIZE | ORDER # | STOCK # |
|------------|----------|-----------|
| 2" 60mm | 2PPS-FKL | 810009681 |
| 3" 80mm | 3PPS-FKL | 810009707 |
| 4" 100mm | 4PPS-FKL | 810009738 |
| 5" 130mm | 5PPS-FKL | 810009762 |


Chimney Cap



Use to vertically terminate a flex system. Black, UV resistant chimney cap with rigid steel flue vent. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # |
|------------|-----------|-----------|
| 2" 60mm | 2PPS-FCTL | 810009680 |
| 3" 80mm | 3PPS-FCTL | 810009810 |
| 4" 100mm | 4PPS-FCTL | 810009811 |
| 5" 130mm | 5PPS-FCTL | 810009812 |


Vertical Flex Termination Cap

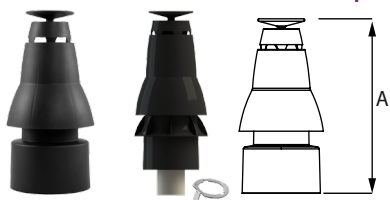

Use to vertically terminate a flex system when using the B-vent retrofit adapters. Includes male and female flex adapters and gaskets. Black, UV resistant. Match the termination size with the diameter of flex you are using. Only 3" includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A |
|-----------|-----------|-----------|-----------------|
| 2" 60mm | 2PPS-VFTL | 810009691 | 13 3/4" 349mm |
| 3" 80mm | 3PPS-VFTL | 810009719 | 17" 432mm |

B-vent Retrofit Adapters

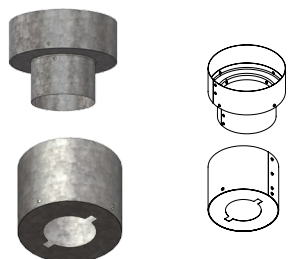

Use to retrofit any B-vent pipe as a chase for PolyPro flex when an old appliance has been replaced with a new condensing 90+ appliance. Includes adapter to cap, flex/B-Vent lower support, and C-support bracket (required for 3" flex) For venting a single appliance (not for common-venting).

| SIZE | ORDER # | STOCK # |
|---------------------------------|----------|-----------|
| 2" 60mm in a 3" 80mm chase | 2PPS-BV3 | 810004332 |
| 2" 60mm in a 4" 100mm chase | 2PPS-BV4 | 810004333 |
| 2" 60mm in a 5" 130mm chase | 2PPS-BV5 | 810004334 |
| 3" 80mm in a 5" 130mm chase | 3PPS-BV5 | 810004348 |
| 2" 60mm in a 6" 150mm chase | 2PPS-BV6 | 810006999 |
| 3" 80mm in a 6" 150mm chase | 3PPS-BV6 | 810005874 |


Support Elbow



Use the support elbow to stabilize a vertical termination. Elbow has integrated support base that is compatible with bracket or support shown on the following page. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|------------|-----------|------------|------------|-----------|
| 5" 130mm | 5PPS-SE90L | 810009765 | 8" 100mm | 8PPS-SE90L | 810009802 |
| 6" 60mm | 6PPS-SE90L | 810009786 | | | |


Support Elbow Extended

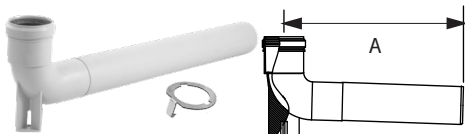

Use the extended support elbow to stabilize the vertical termination. Extended horizontal length can be trimmed to size. Elbow has integrated support base that is compatible with bracket or support shown on the following page. Includes 1 Locking Band.

| SIZE | ORDER # | STOCK # | A |
|------------|-------------|-----------|------------------|
| 2" 60mm | 2PPS-SE90XL | 810009686 | 21 1/16" 551mm |
| 3" 80mm | 3PPS-SE90XL | 810009715 | 22 1/4" 565mm |
| 4" 100mm | 4PPS-SE90XL | 810009747 | 22 7/16" 570mm |
| 5" 130mm | 5PPS-SE90XL | 810009766 | 24 7/16" 620mm |

 
Flex or Rigid Support Bracket



Use to secure the Support Elbow or the Extended Support Elbow inside a masonry chimney or chase. Heavy Duty.

| SIZE | ORDER # | STOCK # |
|----------------------|---------|-----------|
| 2"-8" 60mm - 200mm | PPS-SUP | 810004225 |


Flex Chimney Support

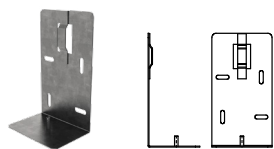

Use to support the Support Elbow inside a masonry chimney or chase. Includes mounting hardware and pipe support clamp.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-SUP | 810004338 | 4" 100mm | 4PPS-SUP | 810004364 |
| 3" 80mm | 3PPS-SUP | 810004352 | 5" 130mm | 5PPS-SUP | 810004375 |

Flex Support Bracket

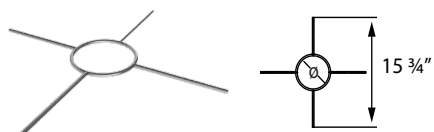

Use to support PolyPro Flex from top of masonry chimney or chase.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-FSB | 810004335 | 4" 100mm | 4PPS-FSB | 810004361 |
| 3" 80mm | 3PPS-FSB | 810004349 | 5" 130mm | 5PPS-FSB | 810004373 |

Spacer



Use to center PolyPro flex. Universal for all diameters. Simple installation and ratchet adjustment. For 3" & 4" diameters, use 3PPS-S.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|---------|-----------|-----------|---------|-----------|
| 2" 60mm | 2PPS-S | 810004336 | 3" 80mm | 3PPS-S | 810004350 |

Flex Length



Use to line masonry chimneys that vent condensing appliances. Double-wall construction. Can be cut to precise length in the field. Available in 25, 35 or 50 foot lengths. 5" diameter flex comes in rolls of 98 feet only.

| SIZE | 25 FEET | | 35 FEET | |
|------------|-------------|-----------|-------------|-----------|
| | ORDER # | STOCK # | ORDER # | STOCK # |
| 2" 60mm | 2PPS-FLEX25 | 810004318 | 2PPS-FLEX35 | 810004319 |
| 3" 80mm | 3PPS-FLEX25 | 810004321 | 3PPS-FLEX35 | 810004322 |
| 4" 100mm | 4PPS-FLEX25 | 810004324 | 4PPS-FLEX35 | 810004325 |
| SIZE | 50 FEET | | 82 FEET | |
| | ORDER # | STOCK # | ORDER # | STOCK # |
| 2" 60mm | 2PPS-FLEX50 | 810004320 | - | - |
| 3" 80mm | 3PPS-FLEX50 | 810004323 | - | - |
| 4" 100mm | - | - | 4PPS-FLEX | 810004326 |
| SIZE | 98 FEET | | | |
| | ORDER # | STOCK # | | |
| 5" 130mm | 5PPS-FLEX | 810004327 | | |


Flex Adapter Kit



Use with PolyPro flex lining system. Includes one male and one female adapter. These allow you to switch from rigid pipe to flex at the base of the system and back to rigid at the top. Flex gaskets (2) included.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|------------|----------|-----------|------------|----------|-----------|
| 3" 80mm | 3PPS-FAS | 810009373 | 5" 130mm | 5PPS-FAS | 810007033 |
| 4" 100mm | 4PPS-FAS | 810005987 | | | |

Flex Male Adapter

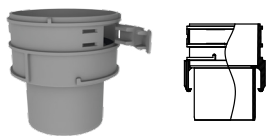

Use to connect PolyPro rigid pipe to PolyPro flex at the base of the system. Flex gasket included.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-FAM | 810004329 | 4" 100mm | 4PPS-FAM | 810004358 |
| 3" 80mm | 3PPS-FAM | 810004344 | 5" 130mm | 5PPS-FAM | 810004370 |

Flex Female Adapter



Use to terminate PolyPro flex lining system back to a rigid system. Flex gasket included.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-FAF | 810004330 | 4" 100mm | 4PPS-FAF | 810004359 |
| 3" 80mm | 3PPS-FAF | 810004345 | 5" 130mm | 5PPS-FAF | 810004371 |


Flex Coupler Adapter



Use to tightly connect one length of PolyPro flex to another. Flex gasket included.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-FAC | 810004331 | 4" 100mm | 4PPS-FAC | 810004360 |
| 3" 80mm | 3PPS-FAC | 810004346 | 5" 130mm | 5PPS-FAC | 810004372 |

Wall Plate

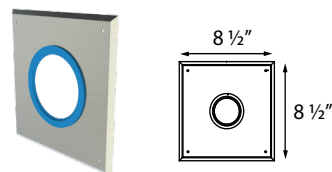

Use to trim wall penetration. Includes silicone seal for tight seal. Aluminum construction. White finish. Can be painted to suit.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|---------|-----------|------------|---------|-----------|
| 2" 60mm | 2PPS-WP | 810004339 | 4" 100mm | 4PPS-WP | 810004365 |
| 3" 80mm | 3PPS-WP | 810004353 | 5" 130mm | 5PPS-WP | 810004376 |

Viton Replacement Gasket Flex



Use as a replacement gasket for PolyPro flex products.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-GAF | 810004340 | 4" 100mm | 4PPS-GAF | 810004366 |
| 3" 80mm | 3PPS-GAF | 810004354 | 5" 130mm | 5PPS-GAF | 810004377 |

Flex Puller



Use with the provided rope to guide PolyPro flex lengths down masonry chimney. 2" version snaps onto flex, 3"-5" version twist-locks onto the male flex adapter.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|---------|-----------|------------|---------|-----------|
| 2" 60mm | 2PPS-FP | 810004342 | 4" 100mm | 4PPS-FP | 810004368 |
| 3" 80mm | 3PPS-FP | 810004356 | 5" 130mm | 5PPS-FP | 810004378 |

PolyPro Multi-Flex Venting System


Reline Upper Plate



Use to seal pipe penetration with gasket, plate needs to be silicone sealed and fastened to (field fabricated) support plate.

| SIZE | ORDER # | STOCK # | SIZE | ORDER # | STOCK # |
|-----------|----------|-----------|------------|----------|-----------|
| 2" 60mm | 2PPS-RPU | 810007982 | 4" 100mm | 4PPS-RPU | 810007963 |
| 3" 80mm | 3PPS-RPU | 810007983 | | | |

 Reline Hanger Support




Use to support flex under the support plate. Clamps around the flex and is fastened to the support plate, then covered by the reline upper plate at the correct size. Universal for 2" - 4" diameters.

| SIZE | ORDER # | STOCK # |
|------------------------|---------|-----------|
| 2" - 4" 60mm - 100mm | PPS-RH | 810007965 |



OEM Appliance Approvals of PolyPro

For a current list and more details, go to our website at www.duravent.com to the PolyPro page and look for the OEM bulletin, or scan code with your smart phone.

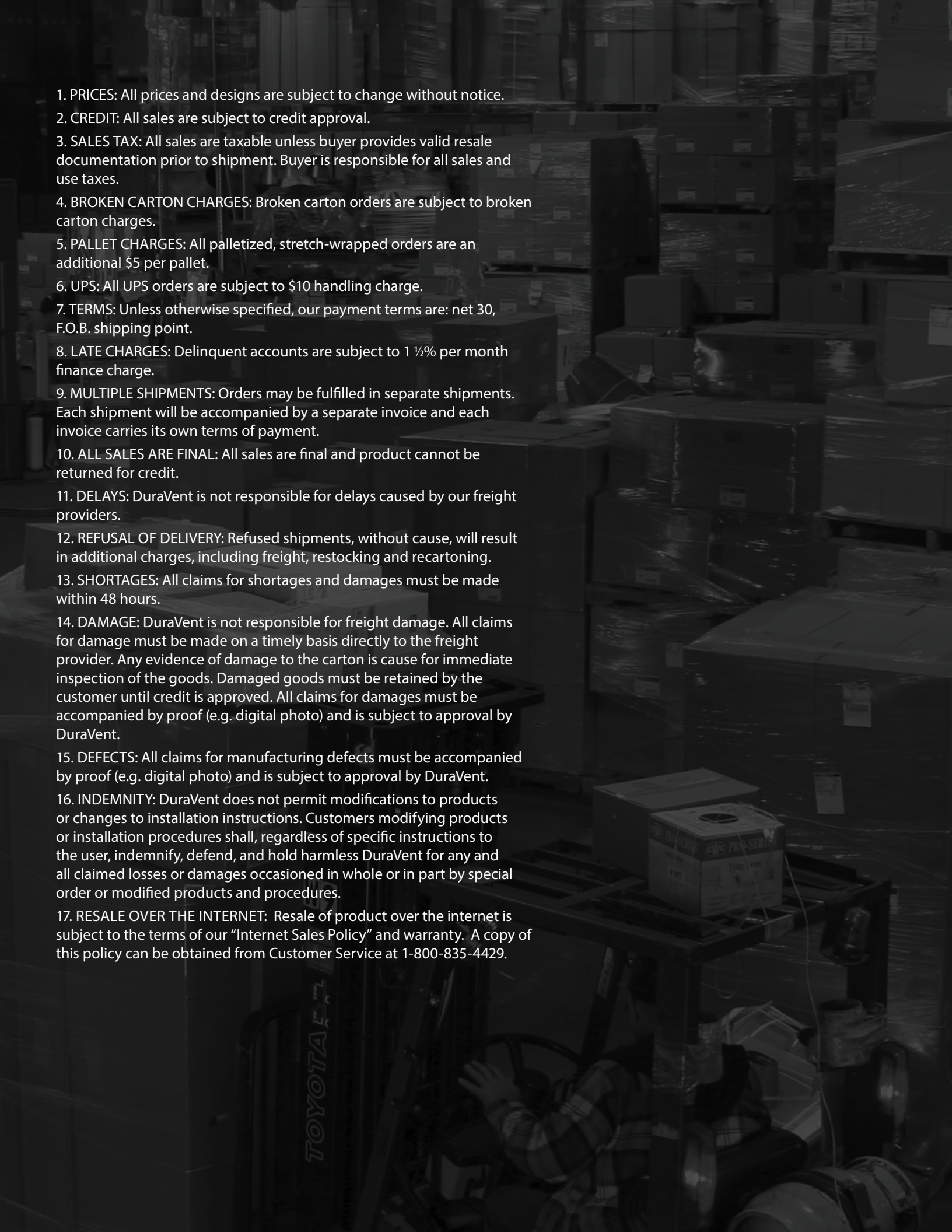- 
1. **PRICES:** All prices and designs are subject to change without notice.
 2. **CREDIT:** All sales are subject to credit approval.
 3. **SALES TAX:** All sales are taxable unless buyer provides valid resale documentation prior to shipment. Buyer is responsible for all sales and use taxes.
 4. **BROKEN CARTON CHARGES:** Broken carton orders are subject to broken carton charges.
 5. **PALLET CHARGES:** All palletized, stretch-wrapped orders are an additional \$5 per pallet.
 6. **UPS:** All UPS orders are subject to \$10 handling charge.
 7. **TERMS:** Unless otherwise specified, our payment terms are: net 30, F.O.B. shipping point.
 8. **LATE CHARGES:** Delinquent accounts are subject to 1 ½% per month finance charge.
 9. **MULTIPLE SHIPMENTS:** Orders may be fulfilled in separate shipments. Each shipment will be accompanied by a separate invoice and each invoice carries its own terms of payment.
 10. **ALL SALES ARE FINAL:** All sales are final and product cannot be returned for credit.
 11. **DELAYS:** DuraVent is not responsible for delays caused by our freight providers.
 12. **REFUSAL OF DELIVERY:** Refused shipments, without cause, will result in additional charges, including freight, restocking and recartoning.
 13. **SHORTAGES:** All claims for shortages and damages must be made within 48 hours.
 14. **DAMAGE:** DuraVent is not responsible for freight damage. All claims for damage must be made on a timely basis directly to the freight provider. Any evidence of damage to the carton is cause for immediate inspection of the goods. Damaged goods must be retained by the customer until credit is approved. All claims for damages must be accompanied by proof (e.g. digital photo) and is subject to approval by DuraVent.
 15. **DEFECTS:** All claims for manufacturing defects must be accompanied by proof (e.g. digital photo) and is subject to approval by DuraVent.
 16. **INDEMNITY:** DuraVent does not permit modifications to products or changes to installation instructions. Customers modifying products or installation procedures shall, regardless of specific instructions to the user, indemnify, defend, and hold harmless DuraVent for any and all claimed losses or damages occasioned in whole or in part by special order or modified products and procedures.
 17. **RESALE OVER THE INTERNET:** Resale of product over the internet is subject to the terms of our "Internet Sales Policy" and warranty. A copy of this policy can be obtained from Customer Service at 1-800-835-4429.

M&G DuraVent, Inc. ("DuraVent") provides this warranty for PolyPro® for ten years. Subject to the limitations set forth below, DuraVent warrants that its products will be free from defects in material or manufacturing, if properly installed, maintained and used. DuraVent products are fully warranted if installed only by a professional installer. This Warranty is transferable from the original homeowner to the buyer of the home within the warranted ten years. This warranty does not cover normal wear and tear, smoke damage or damage caused by chimney fires, acts of God, or any product that was: (1) purchased other than from an authorized DuraVent dealer, retailer or distributor; (2) modified or altered; (3) improperly serviced, inspected or cleaned; or (4) subject to negligence or any use not in accordance with the installation instructions included with the product as determined by DuraVent.

Installation instructions are available online at www.duravent.com under Support/Literature and through our Customer Service Department 800-835-4429 or customerservice@duravent.com.

DuraVent provides the following warranties for PolyPro: One Hundred Percent (100%) MSRP 10 years from the date of purchase.

All warranty obligations of DuraVent shall be limited to repair or replacement of the defective product pursuant to the terms and conditions applicable to each product line. These remedies shall constitute DuraVent's sole obligation and sole remedy under this warranty. This warranty provides no cash surrender value. The terms and conditions of this warranty may not be modified, altered or waived by any action, inaction or representation, whether oral or in writing, except upon the express, written authority of an executive officer of DuraVent.

This product is intended for venting only category II & IV appliances burning Natural Gas, Propane and Oil. All other fuels are not covered under this warranty.

LIMITATIONS ON POLYPRO INTERNET SALES: Notwithstanding any other terms or conditions of this PolyPro Warranty, DuraVent provides no warranty for PolyPro® if it is not installed by a qualified professional installer.

DuraVent must be notified and given the opportunity to inspect defective product prior to replacement under the terms of this limited lifetime warranty. All warranty claims must be submitted with proof of purchase. Labor and installation costs are not covered under this warranty. To obtain warranty service contact: DuraVent Warranty Service, 877 Cotting Ct., Vacaville CA 95688, or call 800-835-4429.

WHERE LAWFUL, DURAVENT DISCLAIMS ALL OTHER WARRANTIES, INCLUDING BUT NOT LIMITED TO IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE. IN NO EVENT WILL DURAVENT BE LIABLE FOR INCIDENTAL, CONSEQUENTIAL, PUNITIVE OR SPECIAL DAMAGES OR DIRECT OR INDIRECT LOSS OF ANY KIND, INCLUDING BUT NOT LIMITED TO PROPERTY DAMAGE AND PERSONAL INJURY. DURAVENT'S ENTIRE LIABILITY IS LIMITED TO THE PURCHASE PRICE OF THIS PRODUCT. SOME STATES DO NOT ALLOW LIMITATIONS ON IMPLIED WARRANTIES, OR THE EXCLUSION OR LIMITATION OF INCIDENTAL OR CONSEQUENTIAL DAMAGES, SO THE ABOVE LIMITATIONS AND EXCLUSIONS MAY NOT APPLY TO YOU. THIS LIMITED WARRANTY GIVES YOU SPECIFIC LEGAL RIGHTS, AND YOU MAY ALSO HAVE OTHER RIGHTS THAT VARY FROM STATE TO STATE.

For the most up-to-date installation instructions, see www.duravent.com

REV 3.22.2012

M&G DuraVent, Inc. Vacaville CA 95688



For more information
about PolyPro and to see
an updated appliance
approval list, scan qr tag
or visit duravent.com.

DuraVent
Member of M&G Group



www.duravent.com 800-835-4429 L275 9/2014