

Specific Purpose Blowers

MARS SERIES **071**



FIG. A

A272, A273,
A274



FIG. B
A276

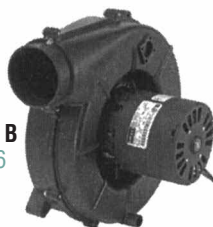


FIG. C

A278, A279,
A360, A362

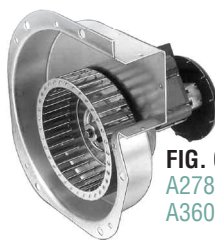


FIG. D
A361



FIG. E
A367



FIG. F
A368



FIG. G
A369,
A370



FIG. H
A373



FIG. I
A118



FIG. J
A080



FIG. K
A083



FIG. L
A063



FIG. M
A144



FIG. N
A137



FIG. O
A154



FASCO MODEL#	TYPE	VOLTS	SPD	AMPS	CROSS REF.	FIG	NOTES
A272	PSC	208-230	2	0.65	Trane 7062-3971	A	
A273	PSC	208-230	2	0.62	Trane 7062-3972	A	
A274	PSC	208-230	1	0.28	Trane 7062-3973	A	
A276	SP	115	1	1	Trane 7021-9011	B	
A278	SP	115	2	1.4	Trane 7002-2530	C	
A279	SP	115	2	0.75	Trane 7002-2531	C	
A360	SP	115	2	1	Trane 7002-2532	C	
A361	SP	115	1	1.6	Trane 7002-2558	D	
A362	SP	115	1	1.6	Trane 7002-3273	C	
A367	SP	115	2	0.95	Trane 7021-8051	E	
A368	PSC	115	2	0.8	Trane 7062-3782	F	
A369	PSC	208-230	2	0.34	Trane 7062-3915	G	
A370	PSC	208-230	2	0.18	Trane 7062-3918	G	
A373	SP	208-230	1	0.6	Trane 7021-9396	H	
A118	SP	115	1	1.8	Williamson 100,000 BTU Furnaces 7021-6999, 7021-7042	I	135
A080	SP	115	1	1.1	Williamson 7021-5510, 02-568 Franklin F3670-1 Rotron RFB6	J	
A083	SP	230	1	0.8	York 026-16323-0000, 02620224-000, 7021-1373	K	51
A063	SP	230	1	0.6	York 026-22239-700, 7021-4314	L	
A144	SP	208-230	1	0.5	York 7021-6770	M	51
A137	PSC	115	1	0.7	York International 7062-2442, 7062-3484, 024-25057-000	N	133
A154	SP	115	1	1.2	York 7021-9428	O	

NOTES: 51: Includes centrifugal switch 133: 4M 250V Capacitor included 135: Leads require modification

All Fasco PSC motors use a 5 mfd at 370 VAC run capacitor, MARS # 12005 or equivalent, unless otherwise noted.

FASCO