


HP971A Pneumatic Humidity Sensor

SPECIFICATION DATA

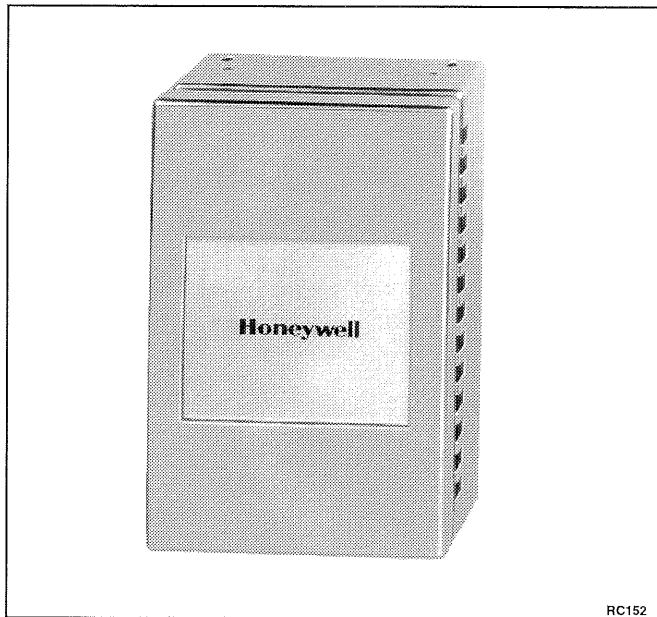

FEATURES

- Proportional control
- Corrosion resistant materials
- Simple plug-in air head connections
- Factory calibrated

GENERAL

The HP971 provides direct-acting, proportional, relative humidity sensing for humidity control and indication in a one- or two-pipe pneumatic application. It is used in conjunction with a pneumatic receiver controller.

The HP971A requires a minimum of 50 fpm air velocity for proper operation.

NOTE: Do not use the HP971 where there may be a high concentration of lithium chloride in the ambient air.



DESCRIPTION

The HP971 provides direct-acting, proportional, relative humidity sensing for humidity control and indication in a one- or two-pipe pneumatic application. It is used in conjunction with a pneumatic receiver controller.

The HP971A requires a minimum of 50 fpm air velocity for proper operation.

NOTE: Do not use the HP971 where there may be a high concentration of lithium chloride in the ambient air.

SPECIFICATIONS

Model:

HP971A: Direct-acting

Sensing Ranges:

Nonadjustable, 65 to 95% rh, 15 to 75% rh, and 15 to 85% rh (for use with HP973 Enthalpy Controller)

Output:

3 to 15 psi (21 to 103 kPa)

Ambient Temperature:

45 to 125F (7 to 52C)

Maximum Safe Pressure:

25 psi (172 kPa)

Filter:

Replaceable carriage type

Air Consumption:

0.022 scfm (10.4 ml/s)

Mounting:

Horizontal or vertical mounted with plug-in backplate

Dimension:

3-1/8 x 1-7/8 x 1-1/2 in. deep (80 x 50 x 40 mm deep)

Branchline Indication:

Self-sealing gage tap, accessible under cover

Construction:

Corrosion resistant metals and finishes with high-strength, glass-filled, Delrin and Noryl molded parts

Supply Air Pressure:

18 psi (124 kPa)

Covers:

Order separately (see 77-1003)

Fittings:

Order separately (see 95-5597)

Home and Building Control

Honeywell Inc.
Honeywell Plaza
P.O. Box 524
Minneapolis MN 55408-0524

Honeywell Latin American Division

Miami Lakes Headquarters
14505 Commerce Way Suite 500
Miami Lakes FL 33016

Home and Building Control

Honeywell Limited-Honeywell Limitée
740 Ellesmere Road
Scarborough Ontario
M1P 2V9

Honeywell Europe S.A.

3 Avenue du Bourget
B-1140 Brussels Belgium

Honeywell Asia Pacific Inc.

Room 3213-3225
Sun Hung kai Centre
No. 30 Harbour Road
Wanchai
Hong Kong

Honeywell

