

Job Name : _____
Purchaser : _____
Engineer : _____
Submitted To : _____
Submitted By : _____
Unit Designation : Schedule No.: _____

Location : _____
P.O. No. : _____
Architect : _____
Date : _____
For : ☐ Reference ☐ Approval ☐ Construction
Model No.: _____

Submittal Data : LA126HNP

Art Cool Single Zone Mini-Split



System Model

Indoor Model # LAN126HNP
Outdoor Model # LAU126HNP

Performance

Capacity (Cooling) (BTUs)	11,500
(Heating) (BTUs)	11,000
EER	10
SEER	13
HSPF	7.7
Air Circulation (CFM H/M/L)	330/261/194
Fan Speeds	4/Auto/Chaos
Dehumidification (pts/hr)	3.0
Indoor dB(A)	43/35/29
Outdoor dB(A)	48

Electrical :

Rated Voltage Outdoor (V, Hz, Ph)	115 , 60, 1
Rated Voltage Indoor	36V DC
Rated Amps	9.3
Minimum Circuit Ampacity	15
Maximum Overcurrent Protection	20

Dimensions (WxHxD) :

Indoor Dimension (inches)	23 5/8 x 23 5/8 x 5 3/4
Indoor Weight (lbs)	33.1
Outdoor Dimension (inches)	30 5/16 x 21 5/16 x 9 5/8
Outdoor Weight (lbs)	70.5

Refrigerant Piping :

Liquid Side (inches, O.D)	1/4"
Suction Side (inches, O.D)	1/2"
Additional Refrigerant (oz./ft.)	0.22
Maximum Pipe Length (ft)	49'
Maximum Elevation (ft)	25'

Operating Range :


Cooling Operating Range (°F, standard)	64-86
Heating Operating Range (°F)	60-86

Standard Features :

- Five Year Compressor Warranty
- Three Year Functional Parts Warranty
- Customizable art panel
- R-410A Refrigerant
- Plasma Air Purifying System
- Chaos Swing
- Three-way cooling
- Jet Cool
- Auto restart
- Built-in low ambient standard, down to 0°F (cooling mode)
- Gold Fin™ Anti -Corrosion Treatment for Condenser

Note :

LAN126HNP

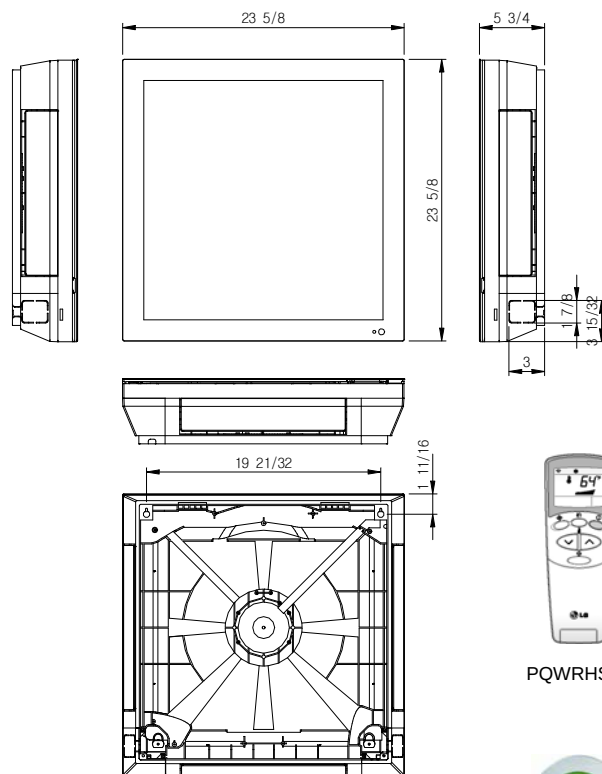

PQWRHSF0



LAU126HNP

