

EZTR4.0™

Easy 40 Gallon Tank Replacement



Introducing a Whole New Way to Install Tankless.

NORITZ®
The Simple Comforts of Life



FAST. EASY. SMART.

Top mounted connections provide an intuitive and straight forward install that lets you get the job done fast, easy, and smart.


REPLACES 40 GALLON TANK



TOP MOUNT WATER CONNECTIONS



UTILIZE EXISTING B-VENT

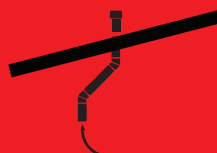

1/2 INCH GAS LINE



TOOLS OF THE TRADE.


We include all the accessories you need for a successful installation right in the box.



THIS IS WHAT INNOVATION LOOKS LIKE.

Noritz has revolutionized the tankless industry with the new EZTR40. The EZTR vents with flexible vent directly through existing B-Vent with no need to spend time changing existing vent. Water connections are on the top of the heater so now you can use flex lines direct from the top like a tank. 1/2 inch gas line connection to existing gas line saves time and money. EZ tank replacement the way you always wanted it to be.

Model Name		EZTR40
BTU Input Range		15,000 - 120,000
Max Flow Rate		6.6 GPM (4.9 GPM at 45 °F ΔT)
Vent Line		SV ONLY - Up to 35 FT.
Venting		2" FLEXIBLE PP VENT - N-FLEX KIT
Dimensions (Height) x (Width) x (Depth)		27.2" x 18.3" x 9.4"
Weight		50 LBS.
Operating Pressure		15-150 PSI
Gas Supply Pressure		NG: 4" - 10.5" LP: 8.0" - 14.0"
Connection Sizes	Water Inlet	(TOP MOUNT) 3/4"
	Hot Water Outlet	(TOP MOUNT) 3/4"
	Gas Inlet	1/2"
	Condensing Drain	1/2"
Power Supply	Supply	120 VAC (60Hz)
	Consumption	NG : 83 W LP : 80 W Freeze Prevention 129 W
Energy Factor		.91 EF
Warranty		12 YRS. HEAT EXCHANGER, 5 YRS. PARTS, 1 YR. LABOR
Temperature Settings*		115 - 140 °F (IN 5 °F INTERVALS)

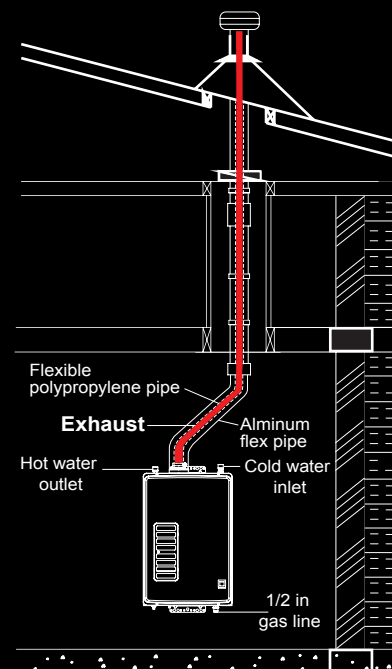

www.noritz.com

*Optional Remote Control. Refer to Owner's Guide

