



T8 Standard

F32T8/HL735/ALTO 30PK

Philips T8 lamps are energy-efficient lighting solutions.

Product data

• General Information

Cap-Base	Medium Bi-Pin [Medium Bi-Pin]
Life 12-Hr Program-start [Hrs]	36000 h
Life 12-Hr Instant Start [Hrs]	30000 h
Life 3-Hr Program Start [Hrs]	30000 h
Life 3-Hr Instant Start [Hrs]	24000 h
Features	ALTO®
Footnotes Fluorescent/CFL 1	Circle E- The encircled E means this bulb meets Federal minimum efficiency standards.

• Light Technical

Color Code	TL835 [CCT of 3500K]
Initial lumen (Nom)	2850 lm
Color Designation	TL835
Design Mean Lumens	2710 lm
Correlated Color Temperature (Nom)	3500 K
Color Rendering Index (Nom)	85

• Operating and Electrical

Power (Rated) (Nom)	32 W
---------------------	------

• Mechanical and Housing

Cap-Base Information	Green Base
Nominal Length (Inch)	48

• Approval and Application

Energy Saving Product	Energy Saving
Picogram Per Lumen Hour	25 pg/lm.h
Mercury (Hg) Content (Nom)	1.7 mg

• Product Data

Order product name	F32T8/HL735/ALTO 30PK
EAN/UPC - Product	046677453732
Order code	453738
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	30
Material Nr. (12NC)	927869783514
Net Weight (Piece)	0.001 kg

 
PHILIPS

Dimensional drawing


F32T8/835 48 ALTO ES

Product

F32T8/HL735/ALTO 30PK



G13, T8

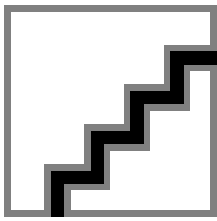

© 2015 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2015, November 29
data subject to change