

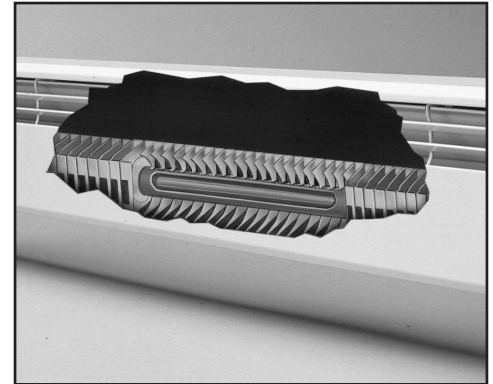


## TYPE HBB SERIES ELECTRIC HYDRONIC BASEBOARD HEATERS

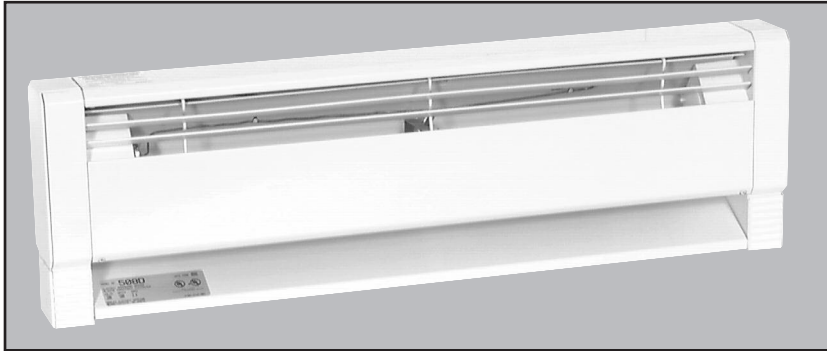

- Clean, quiet operation, without the noise of a traditional hot water piping system and the noisy blower and dirt of forced-air systems.
- Efficient and economical. Individual room control permits heating only in desired areas. Or use as total electric heat source.

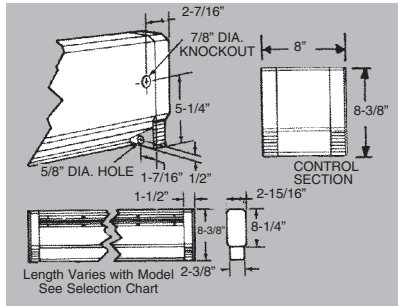

- Low unit surface temperatures, natural convection and large heating fin areas deliver a steady, uniform comfort level in room.
- Sheathed electric heating element is completely submerged in heat transfer fluid totally sealed in a copper tube spanning the length of the heater. Heat is transferred evenly across the entire length of heater. Even after thermostat is turned off, soft warmth continues to radiate because of maximum heat retention of the hydronic element.



### SELECTION CHART

| CATALOG NUMBER | VOLTS   | WATTS     | BTU/HR    | AMPS    | LENGTH | WT. (LBS.) |
|----------------|---------|-----------|-----------|---------|--------|------------|
| HBB500         | 120     | 500       | 1706      | 4.2     | 28"    | 9          |
| HBB508         | 208     | 500       | 1706      | 2.4     |        |            |
| HBB504         | 240/208 | 500/375   | 1706/1280 | 2.1/1.8 |        |            |
| HBB750         | 120     | 750       | 2560      | 6.3     | 34"    | 11         |
| HBB758         | 208     | 750       | 2560      | 3.6     |        |            |
| HBB754         | 240/208 | 750/563   | 2560/1921 | 3.1/2.7 |        |            |
| HBB1000        | 120     | 1000      | 3413      | 8.3     | 46"    | 14         |
| HBB1008        | 208     | 1000      | 3413      | 4.8     |        |            |
| HBB1004        | 240/208 | 1000/750  | 3413/2560 | 4.2/3.6 |        |            |
| HBB1250        | 120     | 1250      | 4265      | 10.4    | 58"    | 18         |
| HBB1258        | 208     | 1250      | 4265      | 6.0     |        |            |
| HBB1254        | 240/208 | 1250/938  | 4265/3200 | 5.2/4.5 |        |            |
| HBB1500        | 120     | 1500      | 5120      | 12.5    | 70"    | 21         |
| HBB1508        | 208     | 1500      | 5120      | 7.2     |        |            |
| HBB1504        | 240/208 | 1500/1125 | 5120/3839 | 6.3/5.4 |        |            |
| HBB2008        | 208     | 2000      | 6826      | 9.6     | 94"    | 29         |
| HBB2004        | 240/208 | 2000/1500 | 6826/5120 | 8.3/7.2 |        |            |

### ACCESSORIES

| CATALOG NO. | DESCRIPTION  |
|-------------|--|
| HBBT1       | 22A @ 120-240 VAC 18 AMP @ 277 VAC Single Pole Thermostat Snap Action Type. Field Installed In Junction Box. |
| HBBT2       | 22A @ 120-240 VAC 18 AMP @ 277 VAC Double Pole Thermostat Snap Action Type. Field Installed In Junction Box. |
| HBBT1TP     | Same As Model HBBT1 Except Tamper Proof.   |
| HBBT2TP     | Same As Model HBBT2 Except Tamper Proof.   |
| HBBAC       | Air Conditioner Outlet Section. 20 AMPS @ 208-240 VAC.   |
| HBBDR       | Duplex Receptacle Section. 15 AMPS @ 120 VAC.  |
| HBBLVR0     | Low Voltage Relay Control Section. 25 AMPS AT 120 VAC.   |
| HBBLVR8     | Low Voltage Relay Control Section. 25 AMPS AT 208 VAC.   |
| HBBLVR4     | Low Voltage Relay Control Section. 25 AMPS AT 240 VAC.   |
| HBBLVR7     | Low Voltage Relay Control Section. 25 AMPS AT 277 VAC.   |

### ACCESSORIES

| CATALOG NO. | DESCRIPTION                         |
|-------------|-------------------------------------|
| HBBCDS2     | Two Pole Disconnect Switch Section. |
| HBBWS       | 8" Wiring Sections.                 |
| CBDCIC      | Inside Corner Section               |
| CBDCOC      | Outside Corner Section              |
| CBDBS2      | 2 Ft. Blank Section                 |
| CBDBS3      | 3 Ft. Blank Section                 |
| CBDBS4      | 4 Ft. Blank Section                 |
| CBDBS5      | 5 Ft. Blank Section                 |
| CBDBS6      | 6 Ft. Blank Section                 |
| CBDBS8      | 8 Ft. Blank Section                 |

- Large wiring compartment is accessible from either end or front, enabling rapid, easy hookup.
- Dual ratings allow six models to cover 23 variations of wattage and voltage. Built in or remote thermostat (optional). High-temperature shutoff protection.
- Contemporary styling and neutral color blends with any decor. Just three inches deep, unit mounts flush to wall and flat on wood, tile or carpeted floor.
- 10-year limited warranty. A decade of maintenance-free performance -