

### ***FLCH4R Electric Fan-Forced Garage Heater***



- ▶ **CONTROL YOUR COMFORT**
  - BUILT-IN DIGITAL INTERFACE
  - REMOTE CONTROLLED
  - 9 HOUR TIMER
  - WITH AUTO SHUT-OFF
- ▶ **PERFECT FOR 2 CAR GARAGE**
  - 4800 WATTS AND 16,378 BTU'S/HR
- ▶ **RESIDENTIAL GRADE UNIT HEATER**
  - DURABLE UNIT WITH SCRATCH AND RUST RESISTANT FINISH
- ▶ **APPLICATIONS INCLUDE:**
  - GARAGES
  - SMALL WAREHOUSES
  - STORAGE FACILITIES
  - WORKSHOPS
  - *AND MUCH MORE*



Conforms to ANSI/UL 2021  
and CSA C22.2, No. 46  
Safety Standards




Remote control requires 2 each  
AAA batteries - Not Included




## SELECTION CHART

CATALOG NUMBER	UPC	VOLTS	WATTS	AMPS	BTU/HR	SHIP L" x W" x H"	SHIP WEIGHT
FLCH4R	6 85360 16486 1	240	4800 / 2400	20 / 10	16378 / 8189	17-3/4 x 12 x 18	13 lbs
		208	3600 / 1800	17.3 / 8.6	12284 / 6142		


### WALL MOUNTING

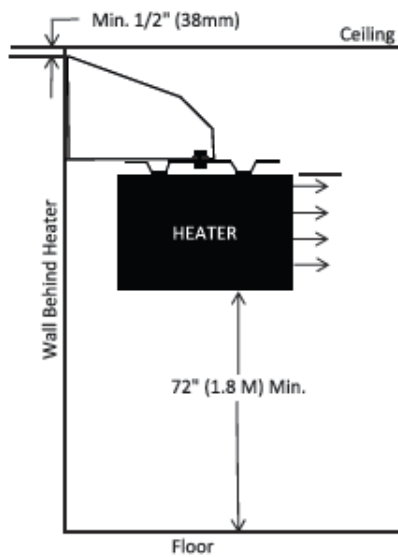

### CEILING MOUNTING

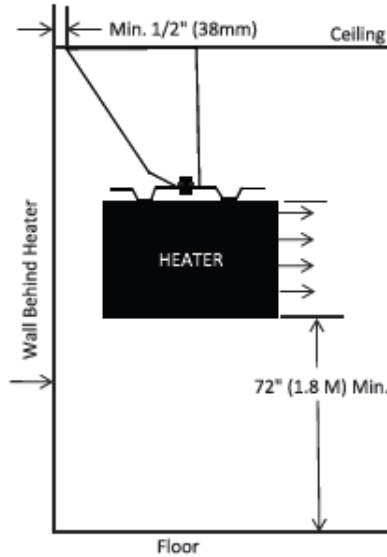

### CEILING MOUNTING TILTED TO 30°

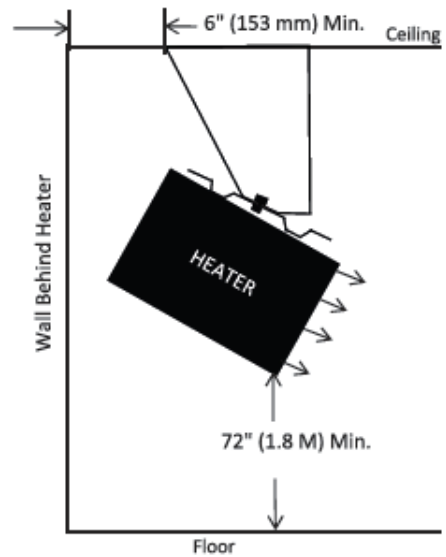

## FEATURES

- ▶ 240V – 4800 watt / 208V – 3600 watt Garage / Utility Heater
- ▶ Hardwired to provide easy installation and clean aesthetic look
- ▶ Remote Control included for easy operations (batteries not included)
- ▶ Digital LED Interface
- ▶ Optional timer feature up to nine hours with automatic shut off
- ▶ Thermostat ranges from 45° F – 99° F
- ▶ Built-In Fan Delay to prolong element life
- ▶ Power Indicator Light
- ▶ Stainless Steel tubular heating element
- ▶ Includes mounting bracket for wall or ceiling installation
- ▶ 1 year warranty