

**Water Resistant Thermometer**  
**Model**  
**SWT2**



**Sealed  
for field  
use**

- Water resistant
- MAX/MIN
- °C/°F
- Pocket clip
- Protective sheath

# Water Resistant Thermometer

Model  
SWT2



The SWT2 Water Resistant Digital Pocket Thermometer has been designed to last long in field use. It is fully sealed to keep moisture out of the case and away from the sensitive electronics inside.

## Features

- Water resistant for field testing.
- Protective sheath doubles as an extension handle.
- Probe can be inserted through duct walls.
- Ergonomic shape and easy to read LCD.
- MAX/MIN function.
- Auto-off after 10 minutes.

## Specifications

Range:	-58°F to 392°F
Accuracy:	± 3.6°F (-58°F to -4°F) ± 1.8°F (-4°F to 302°F) ± 5.4°F (302°F to 392°F)
Resolution:	0.1°F
Battery:	LR44 1.5V (installed)


*Do not expose thermometer to temperatures over 122°F.*

## Operator's Guide

**MAX/MIN function-** Pressing MAX/MIN will cycle through maximum, minimum, and current readings. To reset memory, hold MAX/MIN for at least 3 seconds.

**Battery replacement-** Loosen screws of battery cover, pull out battery holder, and replace with same type.

**Protective sheath-** Remove protective sheath when taking temperatures. Snap it to the battery cover to create a comfortable handle. Always cover the probe when not being used. The sheath protects you from the probe and the probe from the toolbox.

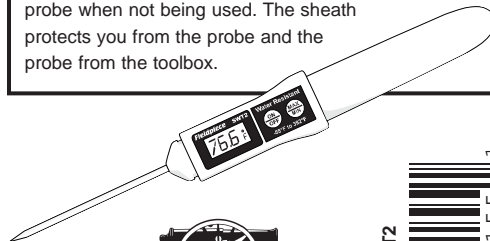

580 West Central Avenue Suite A  
Brea, California 92821  
Phone: (714) 257-9060  
Fax: (714) 257-9069

[www.fieldpiece.com](http://www.fieldpiece.com)

MADE IN CHINA

Model: SWT2

