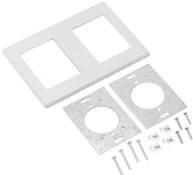
 


Table of Contents

PRODUCT	PAGE #
Sensors	
Mounting Devices/Kits	B-51
Replacement Parts	B-51 — B-52
Sun Shield	B-52
Well	B-52
Hygrostat	
Repair Kits	B-52

Accessories & Service Kits

Sensors

	Description	Product Group	Quantity	Part No.
	Single Adapter Base Kit.	T, RH & RH/T Sensors	1	544-782A
	• Beige		1	544-782B
	Double Adapter Base Kit.	T, RH & RH/T Sensors	1	544-783A
	• Beige		1	544-783B
	Extender Ring Kit.	T, RH & RH/T	1	544-785A
	• Beige		1	544-785B
	Non-Conduit Rough-in Kit.	T, RH & RH/T Sensors	1	544-784
	Metal Gym Guard (Desert Beige).	RT Sensors	1	182-621
	Electrical Box (2 x 4) Adapter Plate Kit.	T, RH & RH/T Sensors	Pkg. of 5	192-506
	Electrical Box (2 x 4) Adapter Base.	T, RH & RH/T Sensors	Pkg. of 5	192-507
	Adapter Base.	T, RH & RH/T Sensors	Pkg. of 5	192-307

B-50

Sensors



Sensors		Description	Product Group	Quantity	Part No.
		Adapter Frame.	RT Sensors	Pkg. of 5	192-308
		Mounting Strap. For mounting Room Sensor on standard light switch plate.	RT Sensors	1	536-666
		Adapter Plug. For plugging in Room Sensor & Portable Operator's Terminal into Controller.	RT Sensors	1	540-142
		Fixing Bracket for Remote Mounting. Made from die-cast Aluminum.	Q Series Pressure	1	AQB22.1
		Mounting Kit.	Q Series Pressure	1	AQB51.1
		Conduit Assembly Kit.	599 Series Diff. Pressure Sensors	1	590-500
		Replaceable Humidity Sensing Element (2% versions only).	Q Series Room Humidity	1	AQF3050
		Humidity Sensor Filter Cap.	Q Series Duct/ Outdoor Air Humidity	Pkg. of 3	AQF3101
		Replaceable 2% Humidity Sensor Tip.	Q Series Duct/ Outdoor Air Humidity	1	AQF3150
		Replaceable 2% Humidity Certified Sensor Tip.	Q Series Duct/ Outdoor Air Humidity	1	AQF4150

Accessories & Service Kits

		Description	Product Group	Quantity	Part No.
Sensors		Replacement Flange Kit.	Q Series Duct Humidity	1	74 662 0068 0
		Sun Shield.	Q Series Outdoor Air Humidity	1	AQF3100
		Stainless Steel Well. 0.26"D x 4"L (18 mm D x 102 mm L)	Pipe Temp. Sensors	1	184-120
186		Hygrostat Restrictor Repair Kit. Includes enough restrictor plates and upper and lower gaskets.	186	Material for 10 Hygrostats	180-893
		Membrane Element Kit. Replaces membrane element Contains one element assembly, screws, nuts, and lock washers.	186	1	186-062

B-52

Sensors

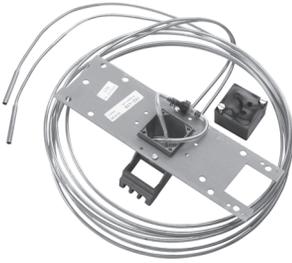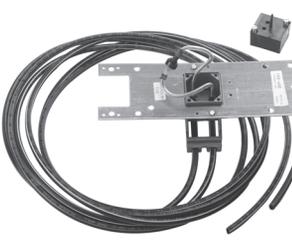186		Description	Product Group	Quantity	Part No.
		<p>Wall Box Rough-In. For 2-pipe dual 1/8" (3 mm) OD copper with plaster plate. 8' (2 m) long, belled to 3/16" (5 m) OD with thermostat chassis plug-in adapters for easy maintenance.</p>	186	1	192-478
	<p>3-pipe dual 1/8" (3 mm) OD copper with plaster plate. 8' (2 m) long, belled to 3/16" (5 m) OD with thermostat chassis plug-in adapters for easy maintenance.</p>	186	1	192-498	
	<p>Wall Box Rough-In. For 1- or 2-pipe dual 1/4" (6 mm) OD polyethylene with plaster plate. 10' (2 m) long. With thermostat chassis plug-in adapters for easy maintenance.</p>	186	1	192-480	
	<p>3-pipe dual 1/4" (6 mm) OD polyethylene with plaster plate. 8' (2.4 m) long. With thermostat chassis plug-in adapters for easy maintenance.</p>	186	1	192-499	
	<p>Mounting Clips, Spacer and Template for finished drywall.</p>	186	Package of 10	182-685	
	<p>Stud Mounting Bracket and Dual Copper Tubing, belled to 3/16" (5 mm) OD with plug-in adapters for easy maintenance.</p>	186	1	192-482	
	<p>Metal/Wood Stud Bracket. Drywall rough-in.</p>	186	Package of 5	182-683	
	<p>Dual 1/8" (3 mm) OD Copper Tubing with plug-in adapters. For 1- or 2-pipe. Split for 3-pipe.</p>	186	1	192-479	
	<p>Plug-in Adapter with Tee 20 scim restrictor for 1-pipe.</p>	186	Package of 10	192-875	

