


Solid State Lighting

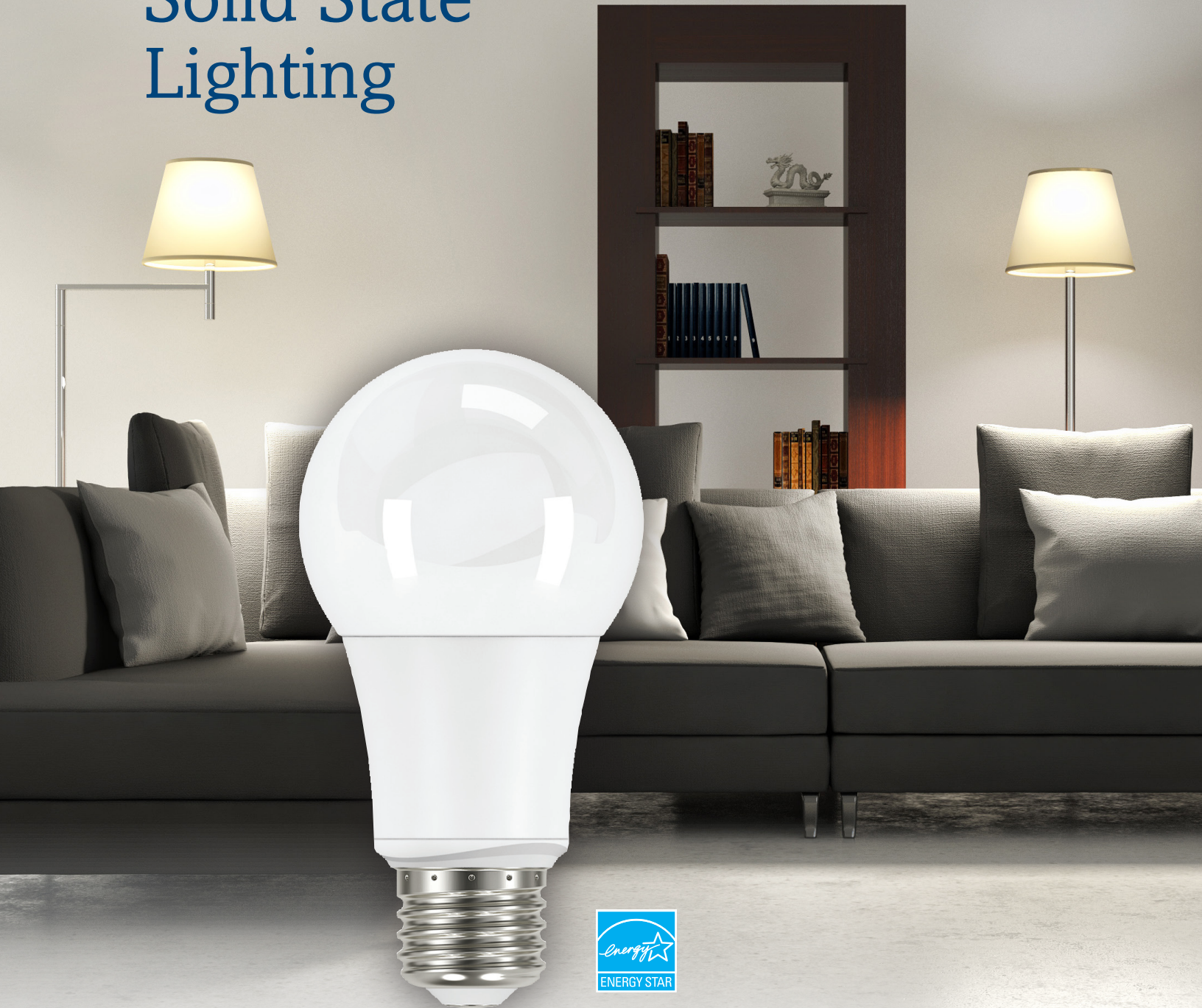

NEW ITEMS! LED A-Shape Omni-Directional Lamps

Topaz welcomes Energy Star qualified 6W, 10W and 12W LED Omni-Directional Style into its series of A-Shape lamps. This style meets the rigorous V1.1 requirements emitting 300° even distribution of light, and can be used for direct replacement of 40W, 60W and 75W incandescent / halogens. LED A-Shape lamps are ideal for both residential and commercial settings including down lights, wall sconces, ceiling fans, and table and floor lamps. Dimmable down to 10% for additional energy savings and ambiance control.



Solid State Lighting

LED A-Shape Omni-Directional Lamps

Features

- Up to 75% energy savings over incandescent lamps
- Long life – up to 10X longer than traditional incandescents
- Dimmable
- Energy Star on select models
- Rated for totally enclosed fixtures

Markets

- Residential, hospitality, retail, restaurants, commercial

Applications

- Fan lights
- Decorative lighting
- Recessed downlighting
- Task lighting



Order info

Item #	Code	Watts	Volts	Base	CRI	CCT (Kelvin)	Initial Lumens	Avg. Rated Life (L70)	MOL In.	Equiv Wattage	Energy Star
LA19/6/827/D	75810	6	120	E26	80	2700	450	25,000	4.3"	40	Y
LA19/6/830/D	75812	6	120	E26	80	3000	470	25,000	4.3"	40	Y
LA19/6/840/D	75814	6	120	E26	80	4000	490	25,000	4.3"	40	-
LA19/6/850/D	75816	6	120	E26	80	5000	510	25,000	4.3"	40	-
LA19/10/827/D	75818	10	120	E26	80	2700	800	25,000	4.3"	60	Y
LA19/10/830/D	75820	10	120	E26	80	3000	830	25,000	4.3"	60	Y
LA19/10/840/D	75822	10	120	E26	80	4000	860	25,000	4.3"	60	-
LA19/10/850/D	75824	10	120	E26	80	5000	900	25,000	4.3"	60	-
LA19/12/827/D	79735	12	120	E26	80	2700	1,100	25,000	4.7"	75	**
LA19/12/830/D	79737	12	120	E26	80	3000	1,140	25,000	4.7"	75	**
LA19/12/840/D	79739	12	120	E26	80	4000	1,190	25,000	4.7"	75	-
LA19/12/850/D	79741	12	120	E26	80	5000	1,230	25,000	4.7"	75	-

Energy Savings Comparison

- Based on 5 hours/day and .11/kwhr

Item #	LED Watts	Incandescent Watts	Energy Savings, Watts	Yearly Cost Savings	5 Year Cost Savings
LA19/6/8XX/D	6	40	34	\$6.83	\$34.13
LA19/10/8XX/D	10	60	50	\$10.04	\$50.19
LA19/12/8XX/D	12	75	63	\$12.65	\$63.24

* Dimming - This lamp is designed to be compatible with most leading edge or incandescent style rotary or slide type dimmers. (Dimming range 100% - 10%) Performance may vary depending on dimmer Specifications subject to change without notice.

** Energy Star Pending in August

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation. Lamp may not be compatible with all dimmers. Visit www.topaz-usa.com for up-to-date dimmer compatibility information.

FIVE (5) YEAR LIMITED WARRANTY: TOPAZ LIGHTING CORP. warrants to the original purchaser that all TOPAZ CXL LED lamps shall be free from defects of material and workmanship for a period of five (5) years from the date of purchase. TOPAZ LIGHTING CORP. will, at its option, repair or replace without charge a defective LED lamp that has not been misused, carelessly handled or improperly installed. Repair or replacement, as stated above, shall constitute the purchaser's exclusive warranty, which does not extend to transportation, installation, labor or any other consequential charges. www.topaz-usa.com

This device is not intended for use with emergency exits. Specifications subject to change without notice.



www.topaz-usa.com

NY Headquarters
925 Waverly Avenue
Holtville, NY 11742
800.666.2852 | Fax: 631.758.8026

CA Office
225 Parkside Drive
San Fernando, CA 91340
888.551.2852 | Fax: 888.690.2852

FL Office
2020 West 26th Street
Jacksonville, FL 32209
800.338.2852 | Fax: 772.778.5386

www.topaz-usa.com

A-Shape LED

LA19/10/827/D

10 Watt Omnidirectional A19

- Dimmable down to 10%*
- True omnidirectional light distribution
- 80% energy savings compared to 60W incandescent



Item #	LA19/10/827/D-46
Product Code	75818
UPC	751338062351
Watts	10
Volts	120
Lamp Shape	A19
Base	E26 Medium
CRI	80
Color Temp	2700K
Initial Lumens	800
Average Rated Life	25,000
Temp Range	-20°C to 40°C
MOL	4.33"
Equivalent Wattage	60
Warranty	5 years

Specifications are subject to change without prior notice.

*Compatible with most leading edge or incandescent style dimmers.

Suitable for totally enclosed fixtures.



Rated for damp locations



ENERGY STAR

