




Z101
HIGH CAPACITY 20 [508] DIAMETER MAIN ROOF DRAIN
LOW SILHOUETTE DOME

SPECIFICATION SHEET

TAG _____

Dimensional Data (inches and [mm]) are Subject to Manufacturing Tolerances and Change Without Notice

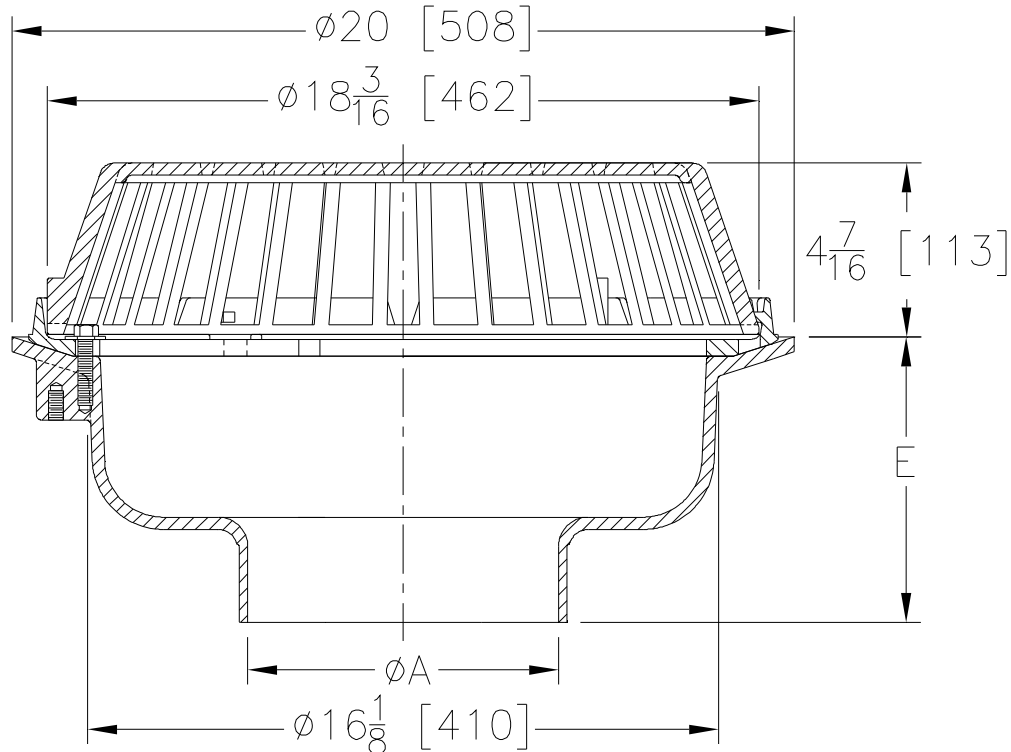

A- Pipe Size In.	Approx. Wt. Lbs. [kg]	Dome Open Area Sq. In. [cm ²]
8 [203]	77 [35]	216 [1394]
10 [245]	78 [35]	
12 [305]	79 [36]	

ENGINEERING SPECIFICATION: ZURN Z101
20 [508] Diameter roof drain. Dura-Coated cast iron body with combination membrane flashing clamp/gravel guard and low silhouette dome.

PIPE SIZE

8, 10, 12 [203, 254, 305]

(Specify size) **OUTLET**

_____ NH No-Hub

'E' BODY HT. DIM.

7-5/16 [185]

PREFIXES

_____ Z D.C.C.I. Body with Cast Iron Dome*

SUFFIXES

_____ -AR Acid Resistant Epoxy Coated
_____ -DP Top-Set® Roof Deck Plate (Replaces both the -C and -R)
_____ -E Static Extension 1 [25] thru 4 [102] (Specify Height)
_____ -EB Top-Set® Adjustable Extension Assembly
_____ -FG Flush Grate
_____ -G Galvanized Cast Iron
_____ -W2 2 [51] Internal Water Dam
_____ -W3 3 [76] Internal Water Dam
_____ -W4 4 [102] Internal Water Dam
_____ -89 2 [51] High External Water Dam

REV. F DATE: 10/20/10 C.N. NO. 111897

DWG. NO. 61557 PRODUCT NO. Z101

*REGULARLY FURNISHED UNLESS OTHERWISE SPECIFIED

ZURN INDUSTRIES, LLC. ♦ SPECIFICATION DRAINAGE OPERATION ♦ 1801 Pittsburgh Ave. ♦ Erie, PA 16514

Phone: 814/455-0921 ♦ Fax: 814/454-7929 ♦ World Wide Web: www.zurn.com

In Canada: ZURN INDUSTRIES LIMITED ♦ 3544 Nashua Drive ♦ Mississauga, Ontario L4V1L2 ♦ Phone: 905/405-8272 Fax: 905/405-1292